


KNOCKOUTS							
SYMBOL	A	B	C	D	E	F	G
IN	.50	.75	1.00	1.25	1.50	2.00	2.50
MM	13	19	25	32	38	51	64

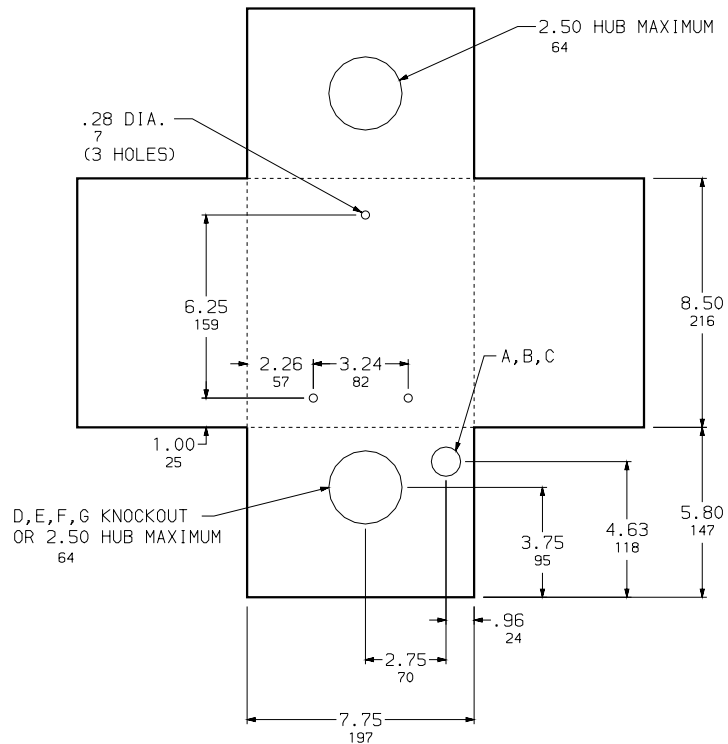

DUAL DIMENSIONS: INCHES
MILLIMETERS

POWER OUTLET CONFIGURATION	SERVICE	MAINS AMPERE RATING	CIRCUIT BREAKER (INCLUDED)	RECEPTACLES (INCLUDED) *	CATALOG NUMBER	MAIN WIRE SIZE (AWG ▲)			
						PHASE AND NEUTRAL		EQUIPMENT GROUND	
						CU	AL	CU	AL
	120VAC 1Ø 2W	40	(1) Q0120GF1	(1) 20A 125V 2W AND GROUND DUPLX NEMA 5-20R	PAK10CT6	(2) #14-6	(2) #12-6	(2) #14 OR 12	(2) #12 OR 10
	120VAC 1Ø 2W	40	(2) Q0120GF1	(2) 20A 125V 2W AND GROUND DUPLX NEMA 5-20R	PAK11CT6	(2) #14-6	(2) #12-6	(2) #14 OR 12	(2) #12 OR 10
	120VAC 1Ø 2W	50	(1) Q0120GF1 (1) Q0130	(1) 30A 125V 2W AND GRD. (1) 20A 125V 2W AND GRD. DUPLX NEMA 5-20R	PAK41CT6	(2) #14-6	(2) #12-6	(2) #14 OR 12	(2) #12 OR 10
	120VAC 1Ø 2W	50	(1) Q0120GF1 (1) Q0130GF1	(1) 30A 125V 2W AND GRD. (1) 20A 125V 2W AND GRD. DUPLX NEMA 5-20R	PAK41CTGF1	(2) #14-6	(2) #12-6	(2) #14 OR 12	(2) #12 OR 10

NOTES:
 FINISH - GRAY BAKED ENAMEL ELECTRODEPOSITED OVER CLEANED PHOSPATIZED STEEL.
 UL LISTED - FILE E-53303
 NEUTRAL - NO BONDING PROVISIONS.
 SUITABLE FOR USE AS RECREATIONAL VEHICLE SITE SERVICE ENTRANCE EQUIPMENT.
 * 20 AMPERE RECEPTACLES PROTECTED BY 20 AMPERE GFI BREAKER.
 ▲ TWO WIRES EACH PER PHASE NEUTRAL, AND EQUIPMENT GROUND - FOR LOOP-FEED.

SERVICEPAK® POWER OUTLET PANELS
 RAINPROOF NEMA TYPE 3R ENCLOSURE
 OUTDOOR

SQUARE D COMPANY

DWG. NO. 3057