
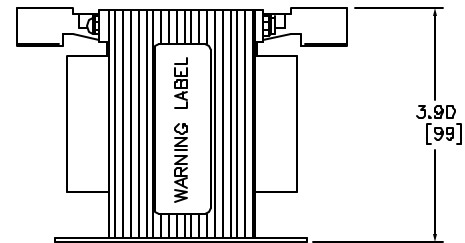


CATALOG NUMBER	PRIMARY VOLTAGE	SECONDARY VOLTAGE	50/60 Hz 1 PHASE		APPROXIMATE WEIGHT (Lbs/Kg)
			UL/eUL/CSA/NDM RATINGS (VA)	CE RATINGS (VA)	
9070T50001	220/440 230/460 240/480	110 115 120	500	300	11.9 / 5.3
9070T50002	240/480	24	500	300	11.9 / 5.3
9070T50003	208	120	500	300	12.0 / 5.4
9070T50004	277	120	500	300	11.8 / 5.3
9070T50005	550 575 600	110 115 120	500	300	11.9 / 5.3
9070T500012	440 460 480	220 230 240	500	300	11.9 / 5.3
9070T500013	120	12/24	500	300	11.9 / 5.3
9070T500014	208	24	500	300	11.7 / 5.3
9070T500015	240/480	24/120	500	300	11.9 / 5.3
9070T500022	480	277	500	300	11.8 / 5.3
9070T500023	120/240	24	500	300	11.9 / 5.3
9070T500024	110 115 120	110 115 120	500	300	11.9 / 5.3
9070T500025	277	24	500	300	12.1 / 5.4
9070T500031	220/440 230/460 240/480	110/220 115/230 120/240	500	300	11.6 / 5.2
9070T500033	380/400/415	115/230	500	300	11.7 / 5.3
9070T500036	600	12/24	500	300	11.6 / 5.2
9070T500037	550 575 600	110/220 115/230 120/240	500	300	11.1 / 5.0
9070T500052	380/400/415	12/24	500	300	12.1 / 5.4
9070T500054	120/240	12/24	500	300	12.0 / 5.4
9070T500055	110/220 115/230 120/240	110/220 115/230 120/240	500	300	11.5 / 5.2
9070T500059	240/480	12/24	500	300	12.0 / 5.4
9070T500060	277	120/240	500	300	11.8 / 5.3
9070T500062	600	240	500	300	11.9 / 5.3

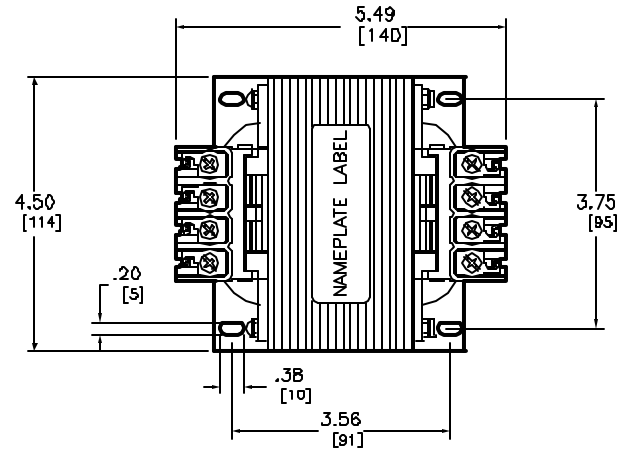

FILES/STANDARDS:

UL/eUL FILE: E81236
 CSA FILE: LR37055
 CE: TUV CERTIFIED TO 61058
 NCM 117

500VA-CONTROL POWER TRANSFORMER
 9070 TYPE T
 CATALOG NUMBERS: FROM CHART



DWG# 5900
 ND.