
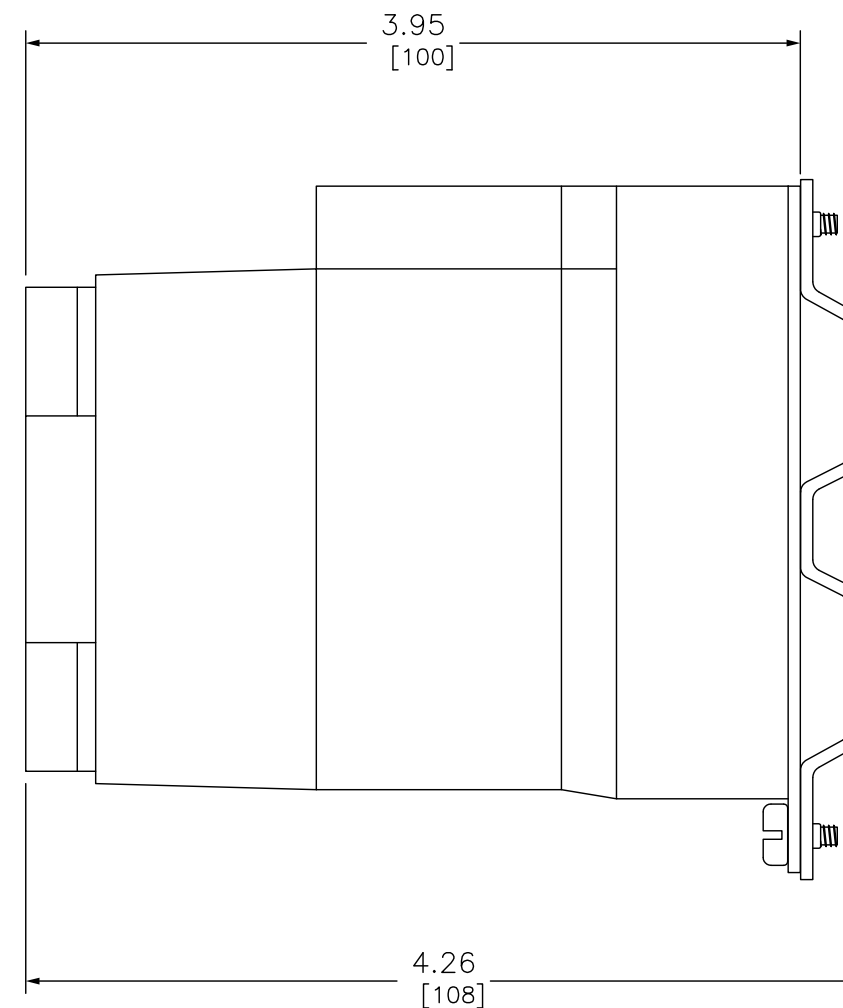


CONVERTIBLE INSTANTANEOUS CONTACTS

TYPE CODE (1)	1 NO, 1 NC
00	0
20	2
30	3
40	4

VOLTAGE CODES

VOLTAGE CODE (2)	AC VOLTAGES
V11	12VAC - 60HZ
V01	24VAC - 60HZ
V12	24VAC - 50HZ
V18	48VAC - 60HZ
V16	48VAC - 50HZ
V02	110/120VAC - 50/60HZ
V08	208VAC - 60HZ
V03	220/240VAC - 50/60HZ
V04	277VAC - 60HZ
V06	440/480VAC - 50/60HZ
V07	550/600VAC - 50/60HZ

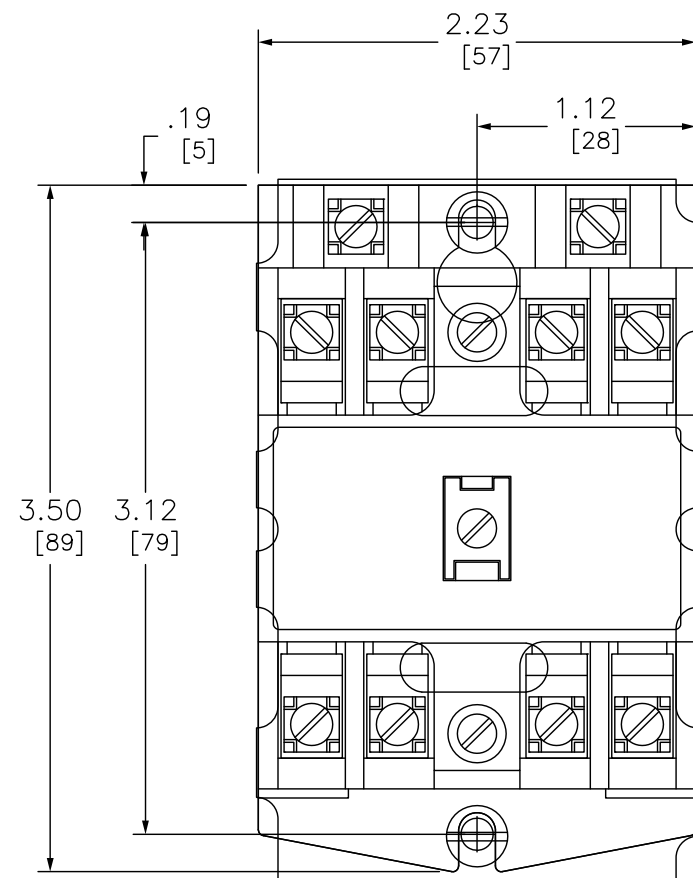

TYPE X MOUNTING TRACK

Catalog Number: 8501-XO(1)(2)  
 Ratings: 600V, 10A  
 UL File/CCN: E78403/NKCR  
 CSA File/Class: LR60905/3211 03  
 Meets Standards: -  
 Weight: 2 lbs  
 Wire Size: #12-#18 AWG  
 Terminal torque: 9-11 LB/IN  
 Mounting Hwd.: (2) #8-32 SCREWS, TYPE X MOUNTING TRACK

DUAL DIMENSIONS: INCHES  
 MILLIMETERS

8501X022V02  
 AC CONTROL RELAY (4 POLE)  
 CLASS 8501 TYPE XO(1)(2)



DWG# 8501X022V02  
 NO.