



NEMA SIZE 1 REVERSING CONTACTOR  
 3-POLE POLYPHASE - 600 VAC, 50-60 HZ

COIL VOLTAGE CODE (1)	VOLTAGE	
	60 HZ	50 HZ
V01	24	-
V02	120	110
V08	208	-
V03	240	220
V06	480	440
V07	600	550
V99	SPECIFY	SPECIFY

ELECTRICAL CLEARANCE/WIRE BENDING SPACE

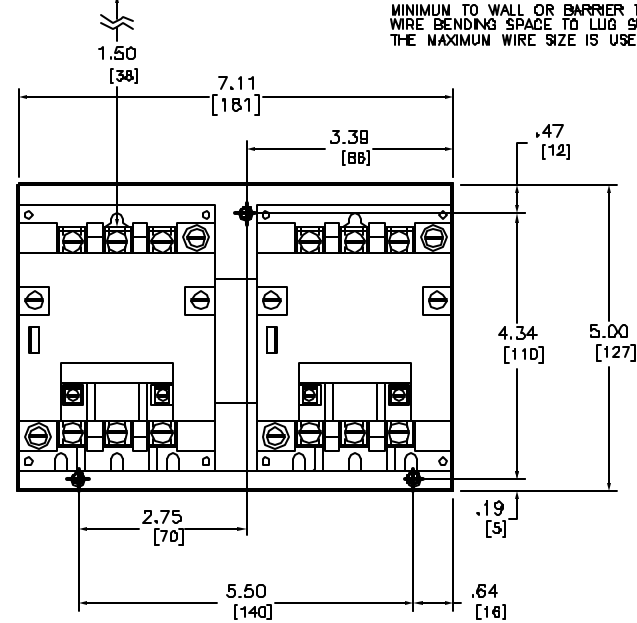

MINIMUM TO WALL OR BARRIER TO INSURE ADEQUATE  
 WIRE BENDING SPACE TO LUG SURFACE WHEN  
 THE MAXIMUM WIRE SIZE IS USED, REF. NEC 430-10

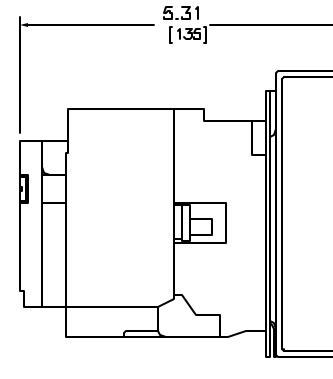

Catalog Number: 8702-SC08(1)  
 Ratings: SEE CHART  
 UL File/CCN: E78351/NLDX  
 CSA File/Class: LR60905/3211 0  
 Meets Standards: -  
 Weight: 12 lbs  
 Wire Size: POWER - #14-#8, CONTROL - #18-#12  
 Terminal torque: 20 LB/IN  
 Mounting Hwd.: (3) #10 screws

DUAL DIMENSIONS: INCHES  
 MILLIMETERS

NEMA SIZE 1 REVERSING CONTACTOR  
 CLASS 8702 TYPE SC08(1)



DWG# E0301201-01  
 NO.