
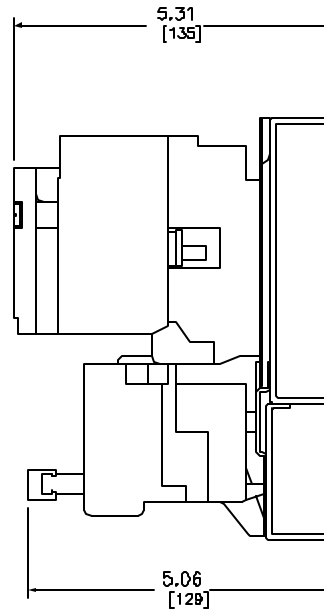


NEMA SIZE 1 REVERSING STARTER
3-POLE POLYPHASE - 600 VAC, 50-60 HZ

COIL VOLTAGE CODE (1)	VOLTAGE	
	60 HZ	50 HZ
V01	24	-
V02	120	110
V08	208	-
V03	240	220
V06	480	440
V07	600	550
V99	SPECIFY	SPECIFY

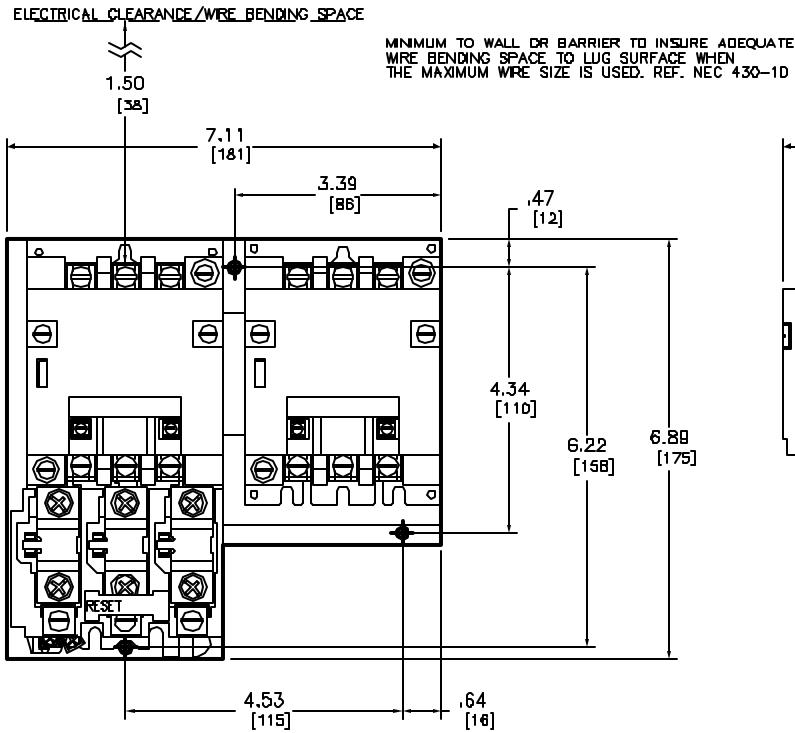

Catalog Number: 8736-SC08(1)
 Ratings: SEE CHART
 UL File/CCN: E78361/NLDX
 CSA File/Class: LR60905/3211 0
 Meets Standards: -
 Weight: 13 lbs
 Wire Size: POWER - #14-#8, CONTROL - #16-#12
 Terminal torque: 20 LB/IN
 Mounting Hwd.: {3} #10 screws

DUAL DIMENSIONS: INCHES
MILLIMETERS

NEMA SIZE 1 REVERSING STARTER
CLASS 8736 TYPE SC08(1)



DWG# E0302101-01
NO.