



NEMA SIZE 1 STARTER  
 3-POLE POLYPHASE - 600 VAC, 50-60 HZ

COIL VOLTAGE CODE (1)	VOLTAGE	
	60 HZ	50 HZ
V01	24	-
V02	120	110
V08	208	-
V03	240	220
V06	480	440
V07	600	550
V99	SPECIFY	SPECIFY

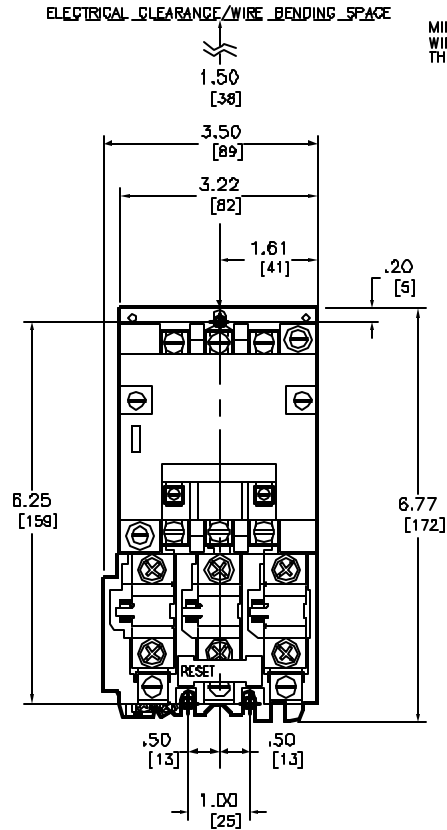

MINIMUM TO WALL OR BARRIER TO INSURE ADEQUATE WIRE BENDING SPACE TO LUG SURFACE WHEN THE MAXIMUM WIRE SIZE IS USED. REF. NEC 43D-10

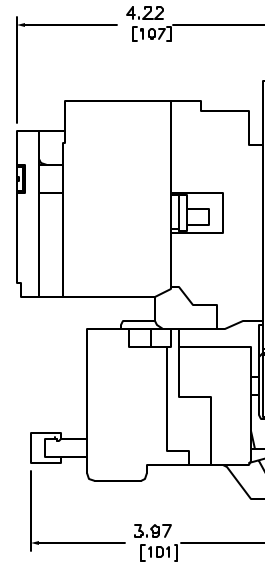

Catalog Number: 8536-SC03(1)  
 Ratings: SEE CHART  
 UL File/CCN: E78351/NLDX  
 CSA File/Class: LR60906/3211 0  
 Meets Standards: -  
 Weight: 5 LB  
 Wire Size: POWER - #14-#8, CONTROL - #18-#12  
 Terminal torque: 20 LB/IN  
 Mounting Hwd.: (3) #10 screws

DUAL DIMENSIONS: INCHES  
 MILLIMETERS

NEMA SIZE STARTER  
 CLASS 8536 TYPE SC03(1)



DWG# E0303001-01  
 NO.