
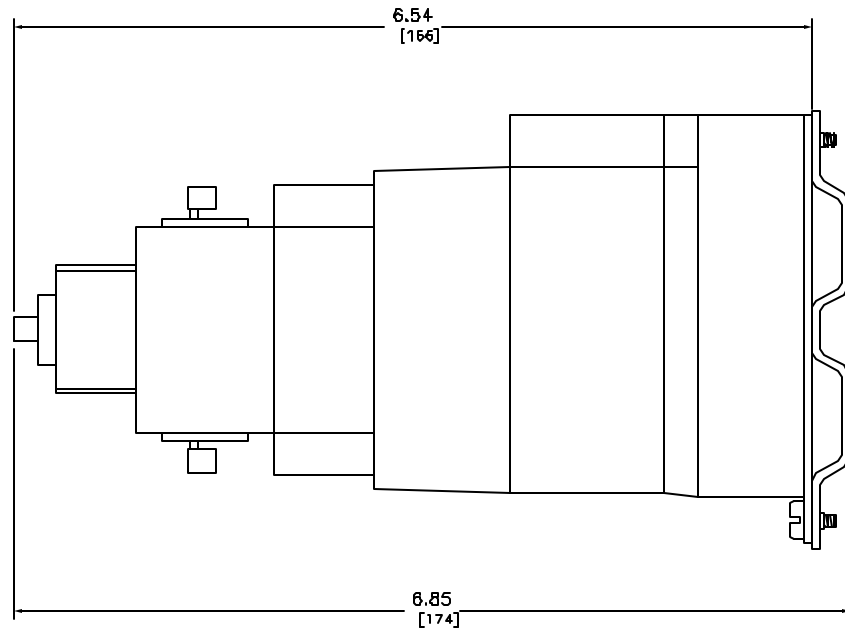


CONVERTIBLE INSTANTANEOUS CONTACTS

TYPE CODE (1)	1 N.O., 1N.C.
2D	2
3D	3
4D	4

VOLTAGE CODES

VOLTAGE CODE (2)	AC VOLTAGES
V11	12VAC - 60HZ
V01	24VAC - 60HZ
V12	24VAC - 50HZ
V18	48VAC - 60HZ
V1B	48VAC - 50HZ
V02	110/120VAC - 50/60HZ
V0B	208VAC - 60HZ
V03	220/240VAC - 50/60HZ
V04	277VAC - 60HZ
V0B	440/480VAC - 50/60HZ
V07	500/600VAC - 50/60HZ

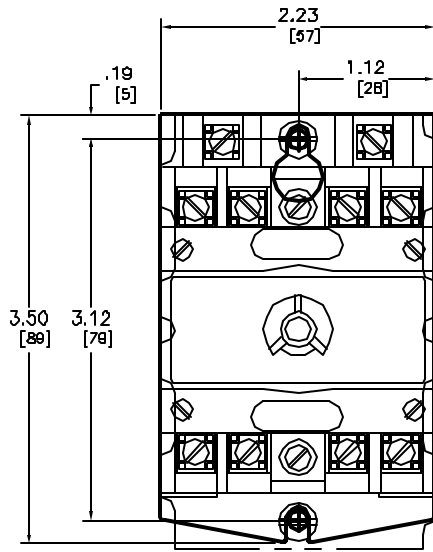

TYPE X MOUNTING TRACK

Catalog Number: B501-X0(1)XL(2)
 Ratings: 600V, 10A
 UL File/CCN: E78403/NKCR
 CSA File/Class: LR80905/3211 03
 Meet Standards: -
 Weight: 2.8 lbs
 Wire Size: #12-#18 AWG
 Terminal torque: 9-11 LB/IN
 Mounting Hwd.: (2) #8-32 SCREWS, TYPE X MOUNTING TRACK

DUAL DIMENSIONS: INCHES
 MILLIMETERS

AC LATCHING RELAY (4 POLE)
 CLASS B501 TYPE XX(1) XL(2)



DWG# E0700901-01
 NO.