



TOP POWER ENTRY 90mm DIA

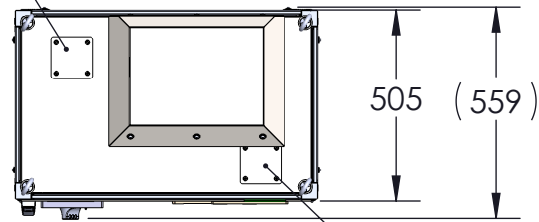

TOP COMMUNICATIONS & CT's 50x50mm OPENING ENTRY

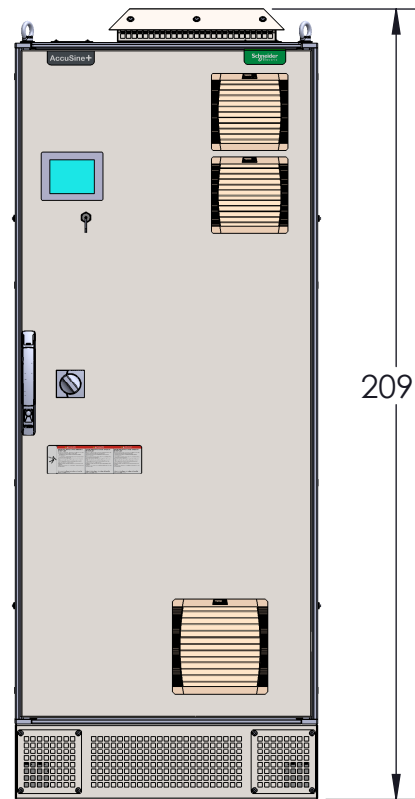


800

2091

NHA5990300 SMALL ENCLOSURE 480V IP54/N12		
PCSP060D5N12	AccuSine PCS+ 60A, 380-480 VAC N12	HRB37644
EVCP060D5N12	AccuSine PFV+ 60A, 380-480 VAC N12	HRB37645
PCSP060D5IP54	AccuSine PCS+ 60A, 380-480 VAC IP54	HRB37646
EVCP060D5IP54	AccuSine PFV+ 60A, 380-480 VAC IP54	HRB37647
PCSP120D5N12	AccuSine PCS+ 120A, 380-480 VAC N12	HRB44081
EVCP120D5N12	AccuSine PFV+ 120A, 380-480 VAC N12	HRB44082
PCSP120D5IP54	AccuSine PCS+ 120A, 380-480 VAC IP54	HRB44068
EVCP120D5IP54	AccuSine PFV+ 120A, 380-480 VAC IP54	HRB44086

BOTTOM ENTRY COMMUNICATIONS 50X50mm OPENING

Ø 90 BOTTOM POWER ENTRY

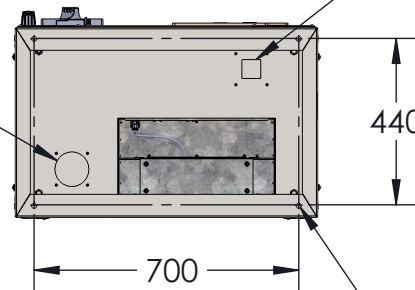

440

700

Ø 13 FLOOR ANCHOR

	Scale: N/A	Tolerancing Standard: ISO8015	Units of Measure: mm
SMALL ENCLOSURE 480V IP54/N12 SMALL ENCLOSURE 480V IP54/N12			

All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.

State:

Released for Manufacturing
Printed on 2015/07/09