



TOP POWER ENTRY 90mm DIA

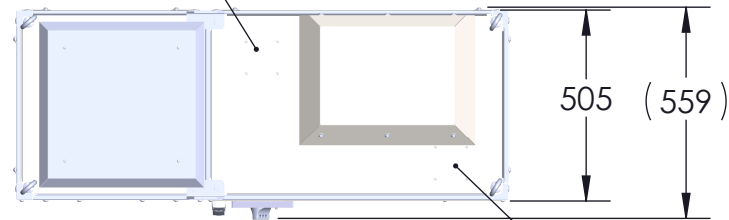


TOP COMMUNICATIONS & CT's 50x50mm OPENING ENTRY

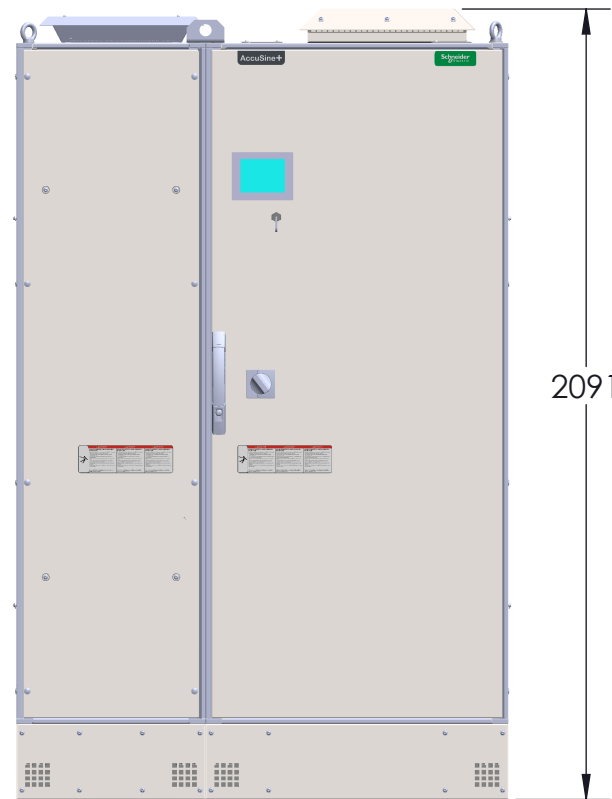

NHA5990400 SMALL ENCLOSURE 600-690V IP31/N2		
PCSP047D6N2	AccuSine PCS+ 47A, 600 VAC N2	HRB37651
EVCP047D6N2	AccuSine PFV+ 47A, 600 VAC N2	HRB37652
PCSP047D6IP31	AccuSine PCS+ 47A, 600 VAC IP31	HRB37653
EVCP047D6IP31	AccuSine PFV+ 47A, 600 VAC IP31	HRB37654
PCSP094D6N2	AccuSine PCS+ 94A, 600 VAC N2	HRB49231
EVCP094D6N2	AccuSine PFV+ 94A, 600 VAC N2	HRB49232
PCSP094D6IP31	AccuSine PCS+ 94A, 600 VAC IP31	HRB49234
EVCP094D6IP31	AccuSine PFV+ 94A, 600 VAC IP31	HRB49235
PCSP040D7N2	AccuSine PCS+ 40A, 690 VAC N2	HRB37673
PCSP040D7IP31	AccuSine PCS+ 40A, 690 VAC IP31	HRB37674
EVCP040D7N2	AccuSine PFV+ 40A, 690 VAC N2	HRB37677
EVCP040D7IP31	AccuSine PFV+ 40A, 690 VAC IP31	HRB37678
PCSP080D7N2	AccuSine PCS+ 80A, 690 VAC N2	HRB49248
PCSP080D7IP31	AccuSine PCS+ 80A, 690 VAC IP31	HRB49251
EVCP080D7N2	AccuSine PFV+ 80A, 690 VAC N2	HRB49252
EVCP080D7IP31	AccuSine PFV+ 80A, 690 VAC IP31	HRB49254

Ø 90 BOTTOM POWER ENTRY

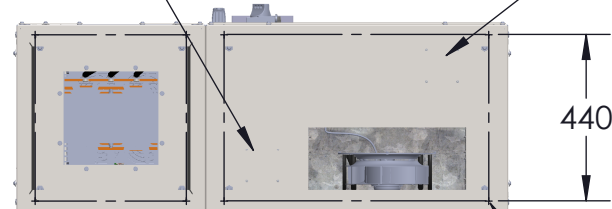

BOTTOM ENTRY COMMUNICATIONS 50X50mm OPENING

Ø 13 FLOOR ANCHOR

	Scale: N/A	Tolerancing Standard: ISO8015	Units of Measure: mm
<b>SMALL ENCLOSURE 600-690V IP31/N2</b> SMALL ENCLOSURE 600-690V IP31/N2			

All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.

State: