



TOP POWER ENTRY 150x175mm OPENING

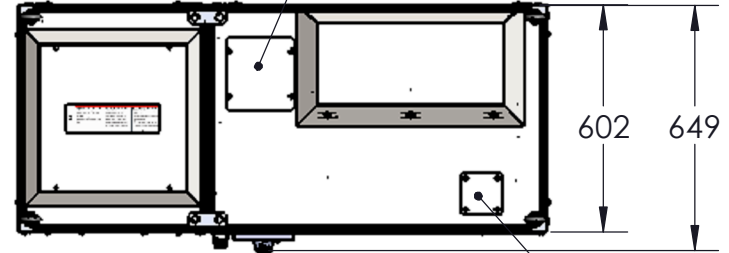

TOP ENTRY COMMUNICATIONS & CT's 50x50mm OPENING

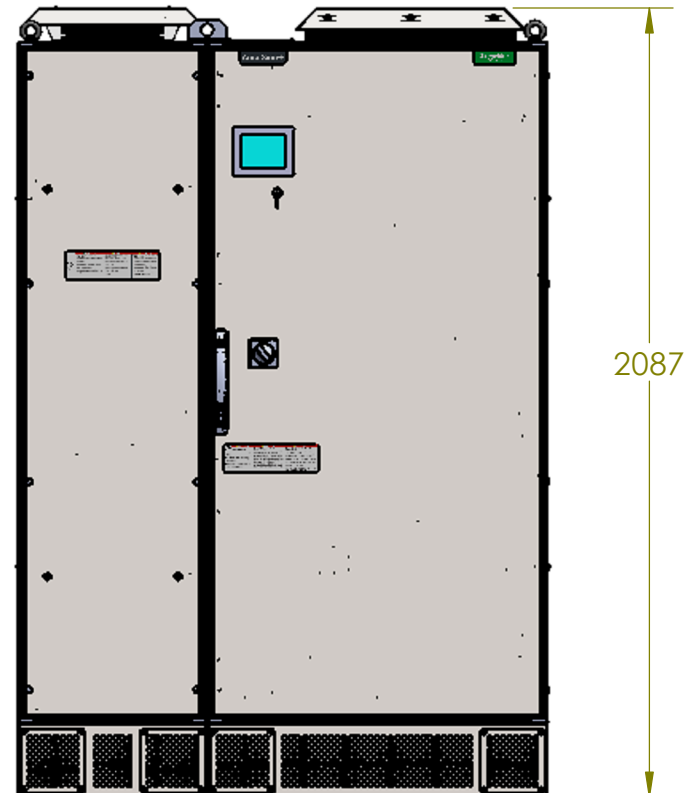


NHA5990800 LARGE ENCLOSURE 600-690V IP31/N2		
PCSP157D6N2	AccuSine PCS+ 157A, 600 VAC N2	HRB49240
EVCP157D6N2	AccuSine PFV+ 157A, 600 VAC N2	HRB49241
PCSP157D6IP31	AccuSine PCS+ 157A, 600 VAC IP31	HRB49242
EVCP157D6IP31	AccuSine PFV+ 157A, 600 VAC IP31	HRB49243
PCSP235D6N2	AccuSine PCS+ 235A, 600 VAC N2	HRB18256
EVCP235D6N2	AccuSine PFV+ 235A, 600 VAC N2	HRB18257
PCSP235D6IP31	AccuSine PCS+ 235A, 600 VAC IP31	HRB18258
EVCP235D6IP31	AccuSine PFV+ 235A, 600 VAC IP31	HRB18259
PCSP133D7N2	AccuSine PCS+ 133A, 690 VAC N2	HRB49790
PCSP133D7IP31	AccuSine PCS+ 133A, 690 VAC IP31	HRB49791
EVCP133D7N2	AccuSine PFV+ 133A, 690 VAC N2	HRB49792
EVCP133D7IP31	AccuSine PFV+ 133A, 690 VAC IP31	HRB49793
PCSP200D7N2	AccuSine PCS+ 200A, 690 VAC N2	HRB18264
PCSP200D7IP31	AccuSine PCS+ 200A, 690 VAC IP31	HRB18265
EVCP200D7N2	AccuSine PFV+ 200A, 690 VAC N2	HRB18268
EVCP200D7IP31	AccuSine PFV+ 200A, 690 VAC IP31	HRB18269

1400

BOTTOM ENTRY COMMUNICATIONS & CT'S 50x50mm OPENING

BOTTOM POWER ENTRY 150x175mm OPENING

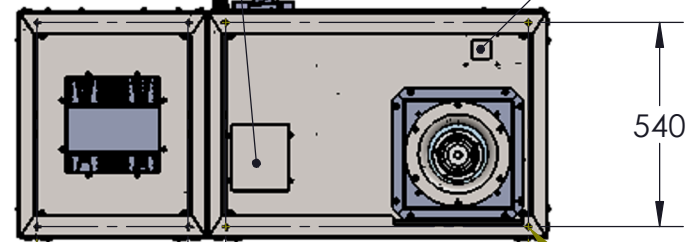

Ø13 FLOOR ANCHOR HOLES

	Scale: N/A	Tolerancing Standard: ISO8015	Units of Measure: mm
LARGE ENCLOSURE 600-690V IP31/N2 LARGE ENCLOSURE 600-690V IP31/N2			
All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.		State:	Released for Manufacturing Printed on 2015/07/09