



KNOCKOUTS							
SYMBOLS	A	B	C	D	E	F	G
IN	.50	.75	1.00	1.25	1.50	2.00	2.50
MM	13	19	25	32	38	51	64

QWIK GRIP SPACES CAPABILITY							
CABLE TYPE	10-3 FLAT	10-3 ROUND	10-2	12-3	12-2	14-3	14-2
W1	X	Y	X	X	X	X	X
W2	Y	X	Y	Y	X	Y	X
W3	X	X	Y	Y	X	Y	X
S1	X	X	X	X	Y	X	Y
S2	X	X	X	X	X	X	Y

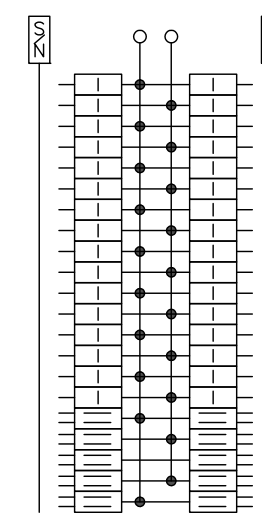

QO142L225PQG

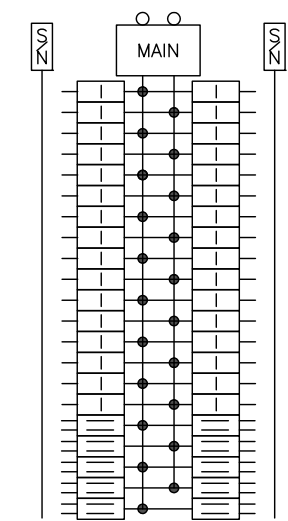

QO142M200PQ
QO142M200PQCVP

DUAL DIMENSIONS: INCHES
MILLIMETERS

CATALOG NUMBERS	MAXIMUM SYSTEM VOLTAGE	MAINS AMPERE RATING	SPACES	MAXIMUM NUMBER OF SINGLE POLE CIRCUITS	MAIN WIRE SIZE AWG
					AL/CU
QO142L225PQG	120/240 VAC 1Ø 3W	225	42	52	#4 -300
QO142M200PQ		200			
QO142M200PQCVP		200			

NOTES:
 FINISH - GRAY BAKED ENAMEL ELECTRODEPOSITED OVER CLEANED PHOSPHATIZED STEEL.
 UL LISTED - FILE E-6294
 NEUTRALS - INSULATED GROUNDABLE.
 LOAD CENTERS WITH "G" IN CATALOG NUMBER INCLUDE A FIELD INSTALLABLE EQUIPMENT GROUND BAR KIT.
 LOAD CENTERS WITH "P" IN CATALOG NUMBER INCLUDE EXTENDED NEUTRALS FOR PLUG ON NEUTRAL READY INTERIORS.
 LOAD CENTERS WITH "Q" IN CATALOG NUMBER INCLUDE QWIK-GRIP CAPABILITIES.
 LOAD CENTERS WITH "VP" IN CATALOG NUMBER INCLUDE SOME CIRCUIT BREAKERS IN PACKAGE.

QO QWIK GRIP LOAD CENTER GENERAL PURPOSE
 NEMA TYPE 1 ENCLOSURE INDOOR



DWG# PWFDS-SYRS-0149
 NO.