



KNOCKOUTS							
SYMBOLS	A	B	C	D	E	F	G
IN	.50	.75	1.00	1.25	1.50	2.00	2.50
MM	13	19	25	32	38	51	64

QWIK GRIP SPACES CAPABILITY							
CABLE TYPE	10-3 FLAT	10-3 ROUND	10-2	12-3	12-2	14-3	14-2
W1	X	Y	X	X	X	X	X
W2	Y	X	Y	Y	X	Y	X
W3	X	X	Y	Y	X	Y	X
S1	X	X	X	X	Y	X	Y
S2	X	X	X	X	X	X	Y

TANDEM BREAKERS - ANY 10 POSITIONS (MAX)

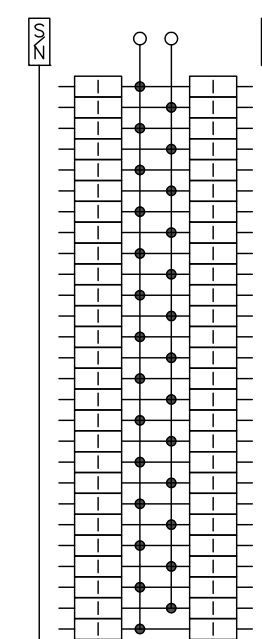

QO154L225PQG

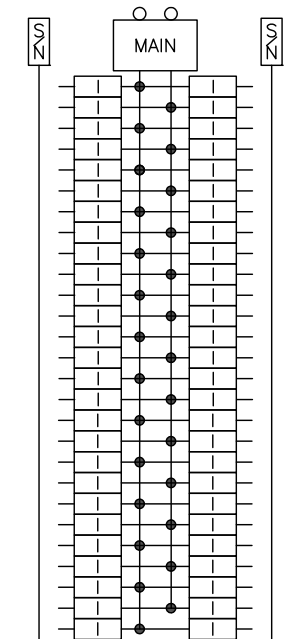

QO154M200PQ

DUAL DIMENSIONS: INCHES
MILLIMETERS

CATALOG NUMBERS	MAXIMUM SYSTEM VOLTAGE	MAINS AMPERE RATING	SPACES	MAXIMUM NUMBER OF SINGLE POLE CIRCUITS	MAIN WIRE SIZE AWG AL/CU
QO154M200PQ	120/240 VAC	200	54	64	#4-250
QO154L225PQG	1Ø 3W	225			#6-300

NOTES:
 FINISH - GRAY BAKED ENAMEL ELECTRODEPOSITED OVER CLEANED PHOSPHATIZED STEEL.
 UL LISTED - FILE E-6294
 NEUTRALS - INSULATED GROUNDABLE.
 LOAD CENTERS WITH "G" IN CATALOG NUMBER INCLUDE A FIELD INSTALLABLE EQUIPMENT GROUND BAR KIT.
 LOAD CENTERS WITH "P" IN CATALOG NUMBER INCLUDE EXTENDED NEUTRALS FOR PLUG ON NEUTRAL READY INTERIORS.
 LOAD CENTERS WITH "Q" IN CATALOG NUMBER INCLUDE QWIK-GRIP CAPABILITIES.
 LOAD CENTERS WITH "VP" IN CATALOG NUMBER INCLUDE SOME CIRCUIT BREAKERS IN PACKAGE.

QO QWIK GRIP LOAD CENTER GENERAL PURPOSE
 NEMA TYPE 1 ENCLOSURE INDOOR



DWG# PWFDS-SYRS-0224
 NO.