


Stepped Shank Thermowells

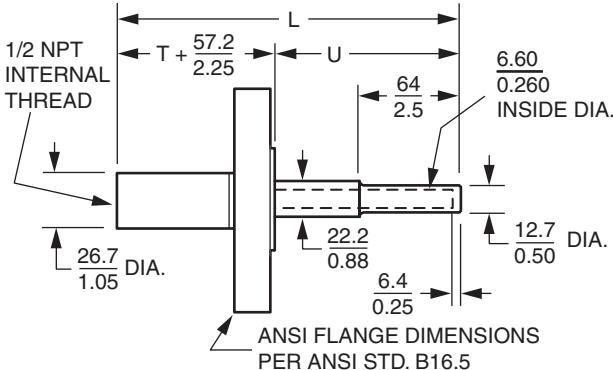


INSERTION LENGTH "U" = _____

OVERALL LENGTH "L" = _____

LAGGING EXTENSION "T" = _____

NOTE: "u" can be from 2 to 36 inches (5 to 914 mm) in 0.5 inch (12.7 mm) increments.
"T" can be from 0 to 4 inches (0 to 102 mm) in 0.5 inch (12.7 mm) increments

Tapered Shank Thermowells

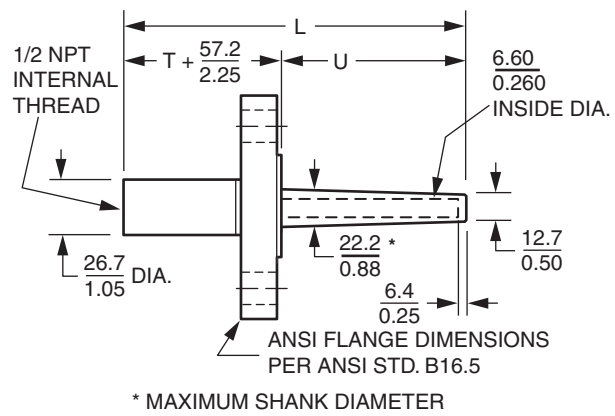

INSERTION LENGTH "U" = _____

OVERALL LENGTH "L" = _____

LAGGING EXTENSION "T" = _____

NOTE: "u" can be from 2 to 36 inches (5 to 914 mm) in 0.5 inch (12.7 mm) increments.
"T" can be from 0 to 4 inches (0 to 102 mm) in 0.5 inch (12.7 mm) increments



Invensys Systems, Inc.
38 Neponset Avenue
Foxboro, MA 02035
United States of America
<http://www.fielddevices.foxboro.com>

Global Customer Support
Inside U.S.: 1-866-746-6477
Outside U.S.: 1-508-549-2424
Website: <http://support.ips.invensys.com>

Copyright 2005-2016 Invensys Systems, Inc.
All rights reserved.

Invensys and Foxboro are trademarks of Invensys Limited, its subsidiaries, and affiliates. All other trademarks are the property of their respective owners.

Invensys is now part of Schneider Electric.