


# TT Series Threaded Thermowells

## Straight Shank Thermowells

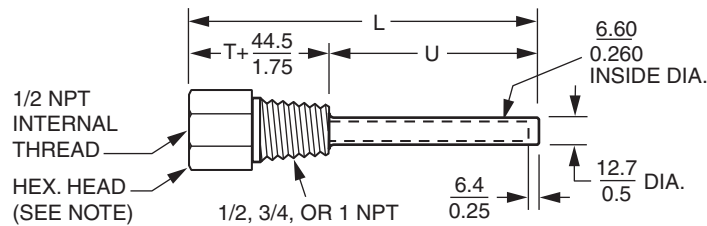

NOTE: HEX SIZE ACROSS FLATS VARIES WITH PROCESS CONNECTION THREAD SIZE

1/2 NPT - 1 1/8 INCH HEX

3/4 NPT - 1 1/8 INCH HEX

1 NPT - 1 3/8 INCH HEX

INSERTION LENGTH "U" = \_\_\_\_\_

 
OVERALL LENGTH "L" = \_\_\_\_\_

LAGGING EXTENSION "T" = \_\_\_\_\_

NOTE: "u" can be from 2 to 36 inches (5 to 914 mm) in 0.5 inch (12.7 mm) increments.

"T" can be from 0 to 4 inches (0 to 102 mm) in 0.5 inch (12.7 mm) increments


For dimensional information specific to your sales order, contact your sales representative to order a Certified Dimensional Print (CDP).



**Foxboro**®

by **Schneider** Electric

## Stepped Shank Thermowells

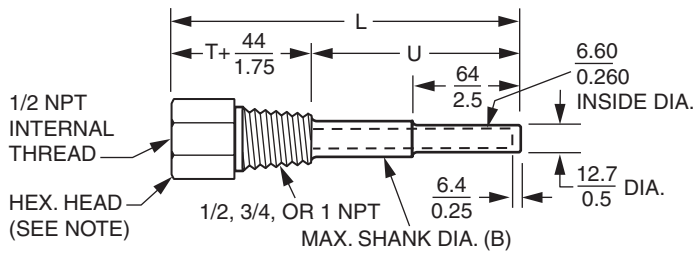

NOTE: HEX SIZE ACROSS FLATS VARIES WITH PROCESS CONNECTION THREAD SIZE

1/2 NPT - 1 1/8 INCH HEX

3/4 NPT - 1 1/8 INCH HEX

1 NPT - 1 3/8 INCH HEX

U Length	Process Connection	Max. Shank Diameter (B)
2.0 (51 mm) through 2.5 in (64 mm)	1/2 NPT 3/4 NPT 1 NPT	0.50 in (15.9 mm)
3.0 in (76 mm) through 36 in (914 mm)	1/2 NPT 3/4 NPT 1 NPT	0.63 in (15.9 mm) 0.75 in (19.1 mm) 0.88 in (22.2 mm)

INSERTION LENGTH "U" = \_\_\_\_\_


OVERALL LENGTH "L" = \_\_\_\_\_

LAGGING EXTENSION "T" = \_\_\_\_\_

NOTE: "u" can be from 2 to 36 inches (5 to 914 mm) in 0.5 inch (12.7 mm) increments.

"T" can be from 0 to 4 inches (0 to 102 mm) in 0.5 inch (12.7 mm) increments

## Tapered Shank Thermowells

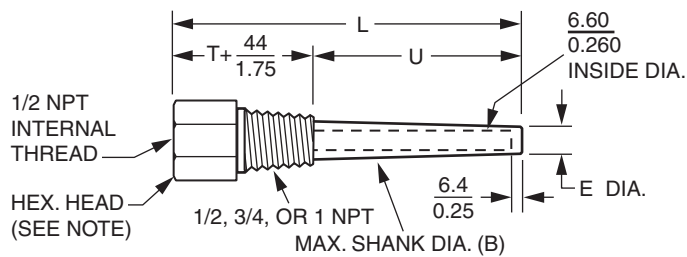

NOTE: HEX SIZE ACROSS FLATS VARIES WITH PROCESS CONNECTION THREAD SIZE

1/2 NPT - 1 1/8 INCH HEX

3/4 NPT - 1 1/8 INCH HEX

1 NPT - 1 3/8 INCH HEX

Process Connection	Dimensions	
	B	E
1/2 NPT	0.63 in (15.9 mm)	0.50 in (12.7 mm)
3/4 or 1 NPT	0.88 in (22.2 mm)	0.63 in (15.9 mm)

INSERTION LENGTH "U" = \_\_\_\_\_

OVERALL LENGTH "L" = \_\_\_\_\_

LAGGING EXTENSION "T" = \_\_\_\_\_

NOTE: "u" can be from 2 to 36 inches (5 to 914 mm) in 0.5 inch (12.7 mm) increments.

"T" can be from 0 to 4 inches (0 to 102 mm) in 0.5 inch (12.7 mm) increments



Invensys Systems, Inc.  
38 Neponset Avenue  
Foxboro, MA 02035  
United States of America  
<http://www.fielddevices.foxboro.com>

Global Customer Support  
Inside U.S.: 1-866-746-6477  
Outside U.S.: 1-508-549-2424  
Website: <http://support.ips.invensys.com>

Copyright 2005-2016 Invensys Systems, Inc.  
All rights reserved.

Invensys and Foxboro are trademarks of Invensys Limited, its subsidiaries, and affiliates. All other trademarks are the property of their respective owners.

Invensys is now part of Schneider Electric.