


NetShelter™ SX Grey Cabinets

APC by Schneider Electric expands its NetShelter SX Premium Data Center IT cabinets to include grey cabinets in multiple heights, widths, & depths for server and networking applications.

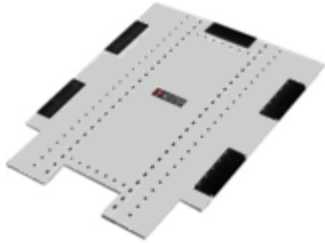

CABLE ACCESS ROOF

- > Five access holes with brush strips for cable passthrough, 3 without for PDU cable routing
- > Two spring loaded pins allow for easy roof removal and installation with cables in place



EASILY ADJUSTABLE VERTICAL MOUNTING RAILS

- > Quickly in 1/4in increments and align adjusted rails with easy alignment feature
- > Simple screw and cam engagement with captive screws
- > Numbered U positions



REMOVABLE SIDE PANELS AND FRONT/REAR DOORS

- > Half height side panels for easy and safe handling
- > Quick release latch on side panels
- > Lockable – same key for doors/side panels
- > Cabinet width the same with or without sides installed
- > Perforated front and rear doors



VERTICAL 0U ACCESSORY CHANNEL

- > Toollessly mount cable management accessories or directly fasten cable bundles
- > Toollessly mount zero U rack power distribution options and save valuable rackmount space



- > *Static Load Capacity 1363 KG*
- > *Doors, sides, roof, and rails are bonded to frame*



Wide / Server
AR3180G



Wide / Deep
Networking
AR3340G

Description	Part
42U 600mm Wide x 1070mm Deep Enclosure with Sides Grey	AR3100G
48U 600mm Wide x 1070mm Deep Enclosure with Sides Grey	AR3107G
42U 750mm Wide x 1070mm Deep Networking Enclosure with Sides Grey	AR3140G
42U 800mm Wide x 1070mm Deep Enclosure with Sides Grey	AR3180G
42U 600mm Wide x 1200mm Deep Enclosure with Sides Grey	AR3300G
42U 750mm Wide x 1200mm Deep Networking Enclosure with Sides Grey	AR3340G
42U 800mm Wide x 1200mm Deep Enclosure with Sides Grey	AR3380G

APC by Schneider Electric offers a range of accessories that, when combined with the NetShelter SX Premium Data Center IT cabinets, creates a whole solutions for its customers.



AR8621

AR8621
Hook-and-loop cable managers, qty 10

- Secure and bundle cables with hook and loop ties
- Mount toollessly on the vertical 0U accessory channel

AR7721,22,23
Low-profile vertical cable managers, 0U

- Supports 38 Cat 6A or 251 fiber cables
- Mount toollessly on the vertical 0U accessory channel



AR7721



AR8842

AR8442
Vertical Cable Organizer, 8 cable rings, 0U

- Supports 385 to 55 Cat 6/CAT 6A data cables
- Mount toollessly on the vertical 0U accessory channel

AR7710
Cable containment brackets with rPDU mounting

- Low profile vertical cable management
- Support 60 to 90 CAT 6/CAT data cables
- Mount toollessly on the vertical PDU accessory channel



AR7710



AR8843A

AR8443A
Vertical fiber organizer

- Installs toollessly
- Takes up one bay of channel
- Mount up to 4 DOC cable heads,

Airflow Management Accessories	APC Part Number
1U Toolless Snap-in Blanking Panel, Qty 10/200pk	AR8136BLK/AR8136BLK200
Air Recirculation Prevention Kit	AR7708
Integral Raised Floor Grommet, Qty 10	AR7720
Surface Mount Raised Floor Grommet, Qty 10	AR7730
Extended Raised Floor Grommet, 24" length, Qty 10	AR7740
Environmental Sensors	
APC Temperature\Temp Hum Sensor	AP9335T or AP9335TH
Smoke Sensor	NBES0307