

Cable ends


Selection Guide



Conforming to NF C 63-023

Standard insulated cable ends in plastic bags

Conductor		Tube				References		References	
c.s.a		mm	Length						
mm ²	AWG	mm		References				References	
0,25	26	8,2		DZ5-CE002				DZ5-CA002	
		6,2		DZ5-CE002L6					
0,34	24	8,2		DZ5-CE003				DZ5-CA003	
		6,2		DZ5-CE003L6					
0,5	22	8,2		DZ5-CE005				DZ5-CA005	
		6,2		DZ5-CE005L6					
		12		DZ5-CE005L12					
0,75	20	8,2		DZ5-CE007				DZ5-CA007	
		6,2		DZ5-CE007L6					
1	18	8,2		DZ5-CE010				DZ5-CA010	
		6,2		DZ5-CE010L6					
		12		DZ5-CE010L12					
1,5	16	8,2		DZ5-CE015				DZ5-CA015	
		6,2		DZ5-CE015L6					
		17,7		DZ5-CE0153					
2	14	8,2		DZ5-CE020					
2,5	14	8,2		DZ5-CE025				DZ5-CA025	
		17,7		DZ5-CE0253					
4	12	9,8		DZ5-CE042		DZ5-CA042			
		17,5		DZ5-CE043		DZ5-CA043			
6	10	11,5		DZ5-CE062		DZ5-CA062			
		17,5		DZ5-CE063		DZ5-CA063			
10	8	12				DZ5-CA0102			
		17,5				DZ5-CA0103			
16	6	12				DZ5-CA0162			
		17,5				DZ5-CA0163			
25	4	17,5				DZ5-CA0253			
35	2	16				DZ5-CA0352			
		25				DZ5-CA0353			
50	1	20				DZ5-CA0502			
		25				DZ5-CA0503			

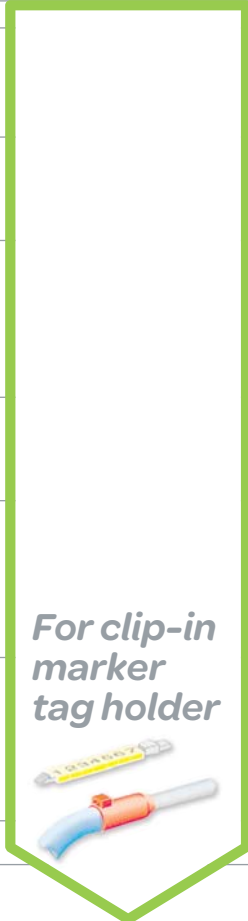

Cable ends in dispensers



Standard insulated cable ends

AZ5-CE005	
AZ5-CE007	
AZ5-CE010	
AZ5-CE015	
AZ5-CE025	



cable ends for 2 conductors

AZ5-DE007	
AZ5-DE010	
AZ5-DE015	
AZ5-DE025	

Accessories for fitting markers and cabling



AR1-SC03



AR1-M•••



AT1-PA7



AT1-HB2



AT1-PA2



AB1-TV•

Clip-on marker holder - for 1 to 1.5 mm ² (1)		AR1-SC02	
Clip-in marker tag holder (1)		AR1-SC03	
Wallets of 200 markers	Letters A ... Z (200 of each)	AR1-MB01	
for DZ5-CA cable ends or clip-on marker holders (2)	Numbers 0 ... 9 (200 of each)	AR1-MA01	
Markers conforming to NF C 93-011 colour coding (3)		AR1-MC01•	
Number	1 2 3 4 5 6 7 8 9 0		
Colour	Brown Red Orange Yellow Green Blue Violet Grey White Black		
Tools for quick positioning of AR1-M•01 markers		AT1-PA1	
Automatic wire stripping tool	Strips cable from 0.08 to 4 mm ² cuts conductors until 6 mm ²	AT1-PA7	
Cable end stripping tool storage case	Comprises : -13 compartments for cable ends - 1 compartment for AT1-PA7	AT1-HB2	
Cable end crimping tools	For cables 0.5 to 16 mm ²	AT1-PA2	
	For cables 10 to 35 mm ²	AT1-PA4	
Insulated screwdriver for slotted head screws	Shank length (mm)	Blade dimensions (mm)	
	100	0.5 x 3.5	AB1-TV3
	150	0.8 x 5.5	AB1-TV2
	150	1 x 6.5	AB1-TV1

(1) For rapid clip-on mounting of up to 7 reference markers AR1-M••••.

(2) Each set also includes 400 earth markers (200 green and 200 yellow), 200 "+" symbols, 200 "-" symbols, 200 and a marker positioning tool.

(3) Complete the reference with the number indicating the colour required.

Conforming to DIN 46228

Standard insulated cable ends in plastic bags

Cable ends in dispensers

Conductor c.s.a		Tube Length	References		References
mm ²	AWG	mm			
0,5	22	8,2	DZ5-CE005D		AZ5-CE005D
		6,2	DZ5-CE005L6D		
		12	DZ5-CE005L12D		
0,75	20	8,2	DZ5-CE007D		AZ5-CE007D AZ5-DE007D
		6,2	DZ5-CE007L6D		
1	18	8,2	DZ5-CE010D		AZ5-CE010D AZ5-DE010D
		6,2	DZ5-CE010L6D		
		12	DZ5-CE010L12D		
1,5	16	8,2	DZ5-CE015D		AZ5-CE015D AZ5-DE015D
		6,2	DZ5-CE015L6D		
		17,7	DZ5-CE0153D		
2,5	14	8,2	DZ5-CE025D		AZ5-CE025D AZ5-DE025D
		17,7	DZ5-CE0253D		
4	12	9,8	DZ5-CE042D		
		17,5	DZ5-CE043D		
6	10	11,5	DZ5-CE062D		
		17,5	DZ5-CE063D		
10	8	12	DZ5-CA102D		
		17,5	DZ5-CA103D		
16	6	12	DZ5-CA162D		
		17,5	DZ5-CA163D		
25	4	17,5	DZ5-CA253D		
35	2	16	DZ5-CA352D		
		25	DZ5-CA353D		
50	1	20	DZ5-CA502D		
		25	DZ5-CA503D		

 
For clip-in marker tag holder

Non Markable

Standard insulated cable ends

cable ends for 2 conductors

NEW



For more information visit our website at: www.schneider-electric.co.in
 Schneider Electric India Pvt. Ltd. (A 100% subsidiary of Schneider Electric Industries SAS)
 Corporate office : A-29, Mohan Co-operative Industrial Estate, New Delhi-110044. Tel: 011-39404000. Fax: 41678010/11
 Customer Care Centre: Toll Free: 1800 111 341 (BSNL/MTNL), 1800 103 0011 (Airtel)
 Phone: +91 11 4168 2434/35, email: in-care@in.schneider-electric.com