
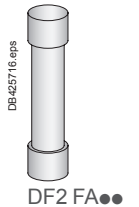
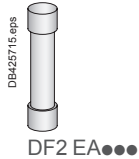





Fupact protection components

Cartridge fuses type aM

For protection of equipment with current peaks

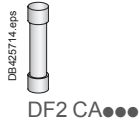

Fuse type	Maximum rated voltage	Rating	Sold in lots of	Fuses without striker		Fuses with striker	
				Unit reference	Weight	Unit reference	Weight
	V	A			kg		kg
Cylindrical 10 x 38	~ 400	20	10	DF2 CA20	0.010	-	-
		25	10	DF2 CA25	0.010	-	-
		32	10	DF2 CA32	0.010	-	-
Cylindrical 14 x 51	~ 500	20	10	DF2 EA20	0.020	DF3 EA20	0.020
		25	10	DF2 EA25	0.020	DF3 EA25	0.020
		32	10	DF2 EA32	0.020	DF3 EA32	0.020
		40	10	DF2 EA40	0.020	DF3 EA40	0.020
		~ 400	50	10	DF2 EA50	0.020	DF3 EA50
Cylindrical 22 x 58	~ 690	20	10	DF2 FA20	0.045	DF3 FA20	0.045
		25	10	DF2 FA25	0.045	DF3 FA25	0.045
		32	10	DF2 FA32	0.045	DF3 FA32	0.045
	~ 500	40	10	DF2 FA40	0.045	DF3 FA40	0.045
		50	10	DF2 FA50	0.045	DF3 FA50	0.045
		63	10	DF2 FA63	0.045	DF3 FA63	0.045
	~ 400	80	10	DF2 FA80	0.045	DF3 FA80	0.045
		100	10	DF2 FA100	0.045	DF3 FA100	0.045
		125	10	DF2 FA125	0.045	DF3 FA125	0.045

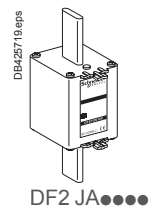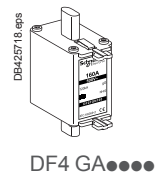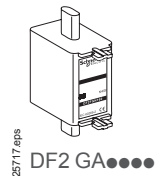




Fuse type	Maximum rated voltage	Rating	Sold in lots of	Fuses without striker		Fuses with striker	
				Unit reference	Weight	Unit reference	Weight
	V	A			kg		kg
Blade NH 000	~ 690	25	3	DF2 FGA25	0.160	-	-
		32	3	DF2 FGA32	0.160	-	-
		40	3	DF2 FGA40	0.160	-	-
		50	3	DF2 FGA50	0.160	-	-
		63	3	DF2 FGA63	0.160	-	-
Blade NH 00	~ 690	80	3	DF2 FGA80	0.160	-	-
		100	3	DF2 FGA100	0.160	-	-
		125	3	DF2 FGA125	0.160	-	-
Blade NH 0	~ 690	50	3	DF2 GA1051	0.230	-	-
		63	3	DF2 GA1061	0.230	-	-
		80	3	DF2 GA1081	0.230	-	-
	~ 500	100	3	DF2 GA1101	0.230	-	-
		125	3	DF2 GA1121	0.230	DF4 GA1121	0.230
		160	3	DF2 GA1161	0.230	DF4 GA1161	0.230
Blade NH 1	~ 690	200	3	DF2 GA1201	0.230	DF4 GA1201	0.230
		160	3	DF2 HA1161	0.400	-	-
	~ 500	200	3	DF2 HA1201	0.400	DF4 HA1201	0.400
		250	3	DF2 HA1251	0.400	DF4 HA1251	0.400
Blade NH 2	~ 690	315	3	DF2 HA1311	0.400	DF4 HA1311	0.400
		250	3	DF2 JA1251	0.560	-	-
	~ 500	315	3	DF2 JA1311	0.560	DF4 JA1311	0.560
400		3	DF2 JA1401	0.560	DF4 JA1401	0.560	
500		3	DF2 JA1501	0.560	DF4 JA1501	0.560	
Blade NH 3	~ 500	630	1	DF2 KA1631	0.850	-	-
		630	3	DF4 KA1631	0.850	-	-
	~ 690	400	1	DF2 KA1401	0.850	-	-
500		1	DF2 KA1501	0.850	DF4 KA1501 [1]	0.850	

[1] Lots of 3.




Fupact protection components

Cartridge fuses type gG

For protection of circuit without significant current peaks

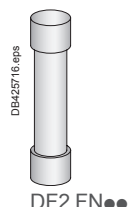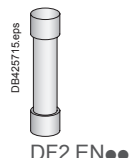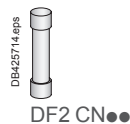

Fuse type	Maximum rated voltage	Rating	Sold in lots of	Fuses without striker		Fuses with striker	
				Unit reference	Weight	Unit reference	Weight
	V	A			kg		kg
Cylindrical 10 x 38	~ 400	20	10	DF2 CN20	0.010	-	-
		25	10	DF2 CN25	0.010	-	-
		32	10	DF2 CN32	0.010	-	-
Cylindrical 14 x 51	~ 500	20	10	DF2 EN20	0.020	DF3 EN20	0.020
		25	10	DF2 EN25	0.020	DF3 EN25	0.020
		32	10	DF2 EN32	0.020	DF3 EN32	0.020
		40	10	DF2 EN40	0.020	DF3 EN40	0.020
		50	10	DF2 EN50	0.020	-	-
Cylindrical 22 x 58	~ 690	20	10	DF2 FN20	0.045	DF3 FN20	0.045
		25	10	DF2 FN25	0.045	DF3 FN25	0.045
		32	10	DF2 FN32	0.045	DF3 FN32	0.045
		40	10	DF2 FN40	0.045	DF3 FN40	0.045
		50	10	DF2 FN50	0.045	DF3 FN50	0.045
		63	10	DF2 FN63	0.045	DF3 FN63	0.045
		80	10	DF2 FN80	0.045	DF3 FN80	0.045
100	10	DF2 FN100	0.045	DF3 FN100	0.045		

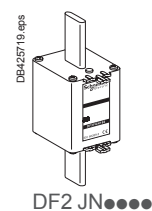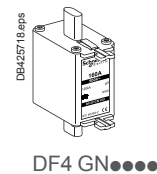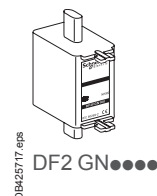

Fuse type	Maximum rated voltage	Rating	Sold in lots of	Fuses without striker		Fuses with striker	
				Unit reference	Weight	Unit reference	Weight
	V	A			kg		kg
Blade NH 000	~ 690	25	3	DF2 FGN25	0.160	-	-
		32	3	DF2 FGN32	0.160	-	-
		40	3	DF2 FGN40	0.160	-	-
		50	3	DF2 FGN50	0.160	-	-
		63	3	DF2 FGN63	0.160	-	-
		80	3	DF2 FGN80	0.160	-	-
	> 500	100	9	DF2 FGN100	0.160	-	-
Blade NH 00	~ 690	125	3	DF2 FGN125	0.160	-	-
	~ 500	160	3	DF2 FGN160	0.160	-	-
Blade NH 0	~ 690	50	3	DF2 GN1051	0.230	-	-
		63	3	DF2 GN1061	0.230	-	-
		80	3	DF2 GN1081	0.230	-	-
		100	3	DF2 GN1101	0.230	-	-
		125	3	DF2 GN1121	0.230	-	-
		160	3	DF2 GN1161	0.230	-	-
	~ 500	125	3	-	-	DF4 GN1121	0.230
		160	3	-	-	DF4 GN1161	0.230
Blade NH 1	~ 690	160	1	DF2 HN1161	0.400	-	-
		200	1	DF2 HN1201	0.400	DF4 HN1201 [1]	0.400
	~ 500	250	3	DF2 HN1251	0.400	DF4 HN1251	0.400
Blade NH 2	~ 690	250	3	DF2 JN1251	0.560	-	-
		315	3	DF2 JN1311	0.560	DF4 JN1311	0.560
	~ 500	400	3	DF2 JN1401	0.560	DF4 JN1401	0.560
Blade NH 3	~ 690	500	3	-	-	DF4 KN1501	0.850
	~ 500	500	1	DF2 KN1501	0.850	-	-
		630	1	DF2 KN1631	0.850	DF4 KN1631 [1]	0.850

[1] Lots of 3.