


Flush mounting Mini Pragma (offer C)

1 row, 4 to 12 modules

2 and 3 rows, 12 modules per row



056130HD-45

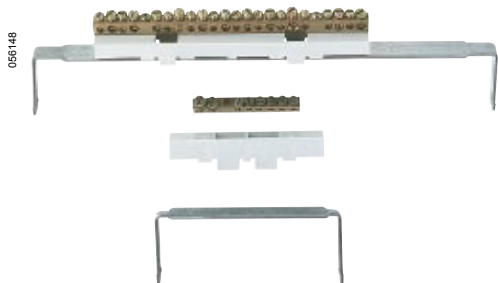

056148

Connection assembly



056145-40

Hollow partition flush mounting kit



056097MD-40

13334



056080MD-40

13562

Function

Mini Pragma is a distribution or subdistribution enclosure up to 63 A. It is used indoors, in housing or the service sector, for new installations or renovation work.

Description

Technical data

- Equipped with an opaque or transparent, curved door:
 - 1 row: wicket door opens 90° upwards
 - 2 and 3 rows: door opens 180° to the right and to the left.
- Rated current of the enclosure:
 - 4 modules: 50 A
 - 6 to 36 modules: 63 A.
- Material:
 - colour: white RAL 9003.
- Compliance with standards:
 - complies with IEC 439.3 (EN 60-439-3).
- Degree of protection:
 - as in IEC 529: IP40 (protection against solids and liquids)
 - as in EN 50-102: IK07 (protection against mechanical impacts)
 - class 2 protection against indirect contact.
- Fire and excessive heat withstand capacity as in IEC 695-2-1:
 - base: 850°C/30 s
 - front panel: 750°C/5 s
 - complies with BOP regulations in France (buildings open to the public).

Composition

Flush mounting Mini Pragma is composed of:

- a symmetrical base:
 - robust
 - of a depth adapted to walls with a low thickness
 - with punch-outs for tube insertion on the 4 sides
- 1 to 3 symmetrical rails with adjustment of verticality:
 - 1 row: adjustable symmetrical rail depth
 - 2 and 3 rows: one-piece chassis enabling wiring outside the base
- a rigid, reversible front panel:
 - with a curved wicket door or curved door
 - equipped with blanking plates which can be punched-out.

Accessories delivered with the enclosure

Flush mounting Mini Pragma is delivered equipped with:

- a circuit identification strip per row: to be glued onto the front panel
- a hollow partition flush mounting kit
- a connection assembly:
 - 1 terminal block
 - 1 terminal block support
- terminal block details:

Number of holes	Composition	
	10 [□]	16 [□]
4	2	2
8	4	4
16	8	8
20	10	10
32	16	16

Flush mounting Mini Pragma (offer C)

1 row, 4 to 12 modules

2 and 3 rows, 12 modules per row (cont.)

Catalogue numbers

Enclosure with door					
Number of rows	Capacity in modules		Terminal blocks delivered (no. x no. holes)	Cat. no.	
	9 mm	18 mm		Opaque	Transparent
1	8	4	1 x 4	13331	13336
1	12	6	1 x 4	13332	13337
1	16	8	1 x 8	13333	13338
1	24	12	1 x 8	13334	13339
2	48	24	1 x 16	13552	13562
3	72	36	1 x 20	13553	13563