



## Surface mounting Mini Pragma L

### 1 row 8 modules

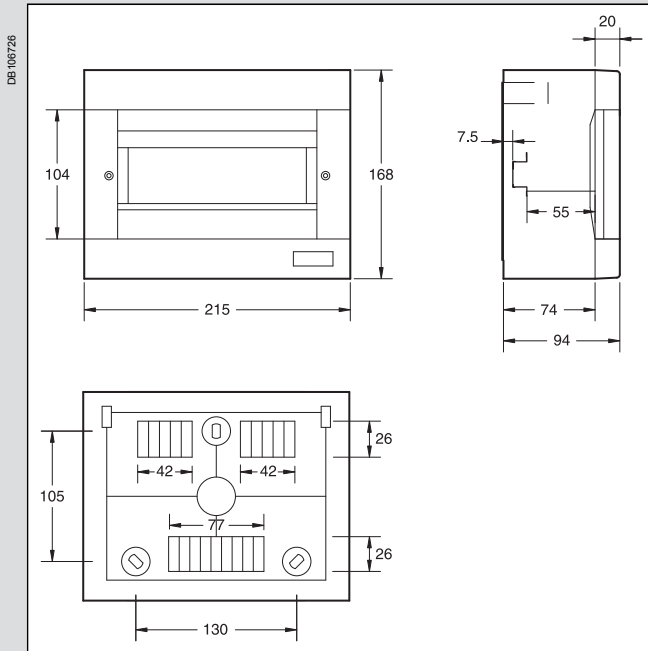


### 1 row 12+1 modules

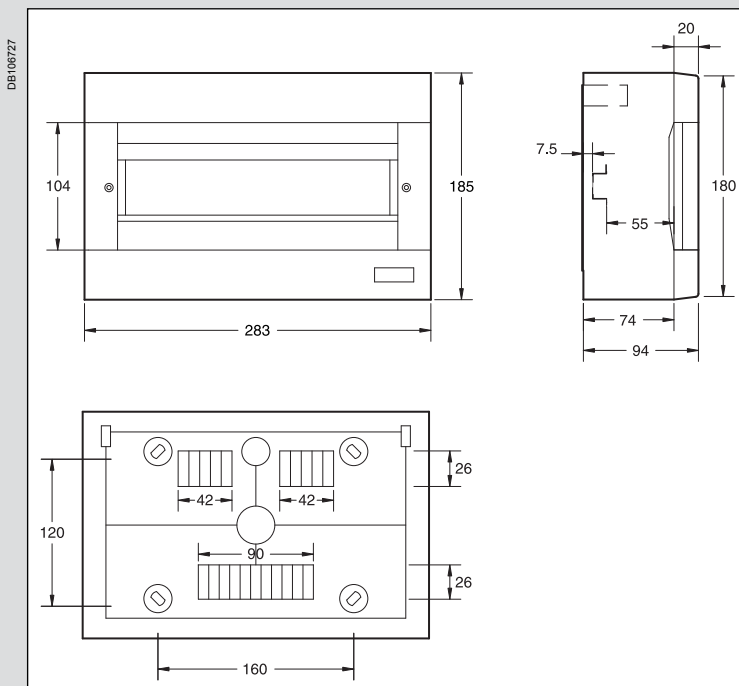


## Surface mounting Mini Pragma L (cont.)

### 2 rows 24 modules

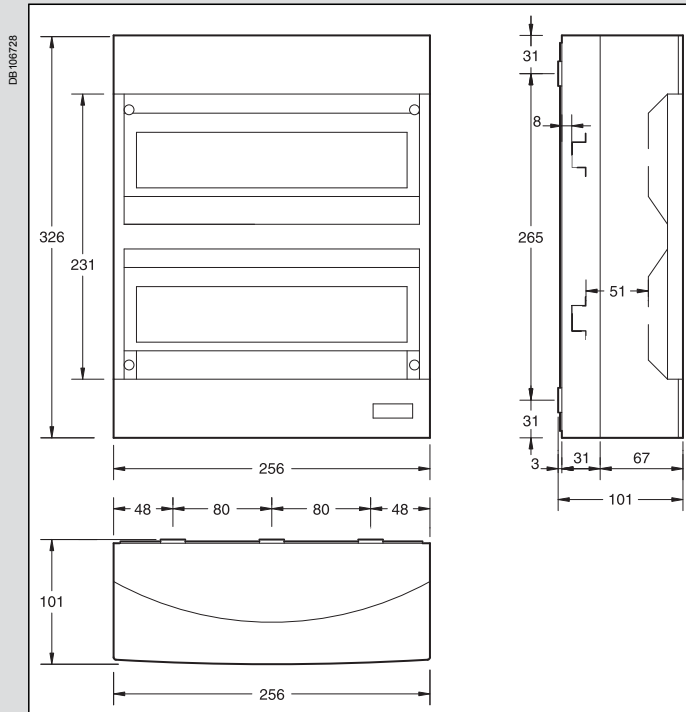


### 3 rows 36 modules

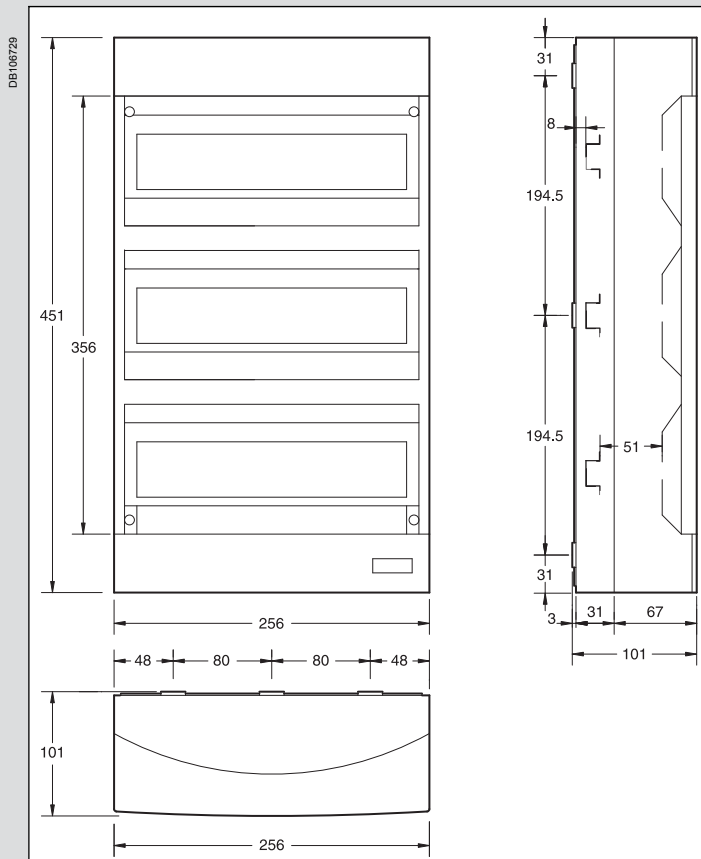


## Flush mounting Mini Pragma L

### 1 row 8 modules

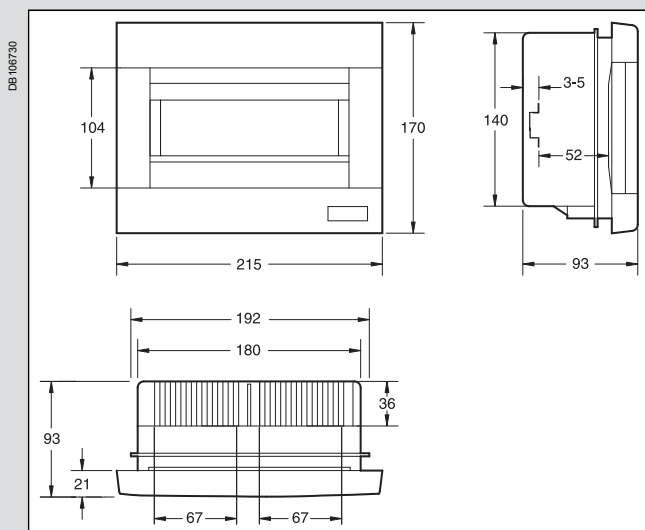


### 1 row 12+1 modules

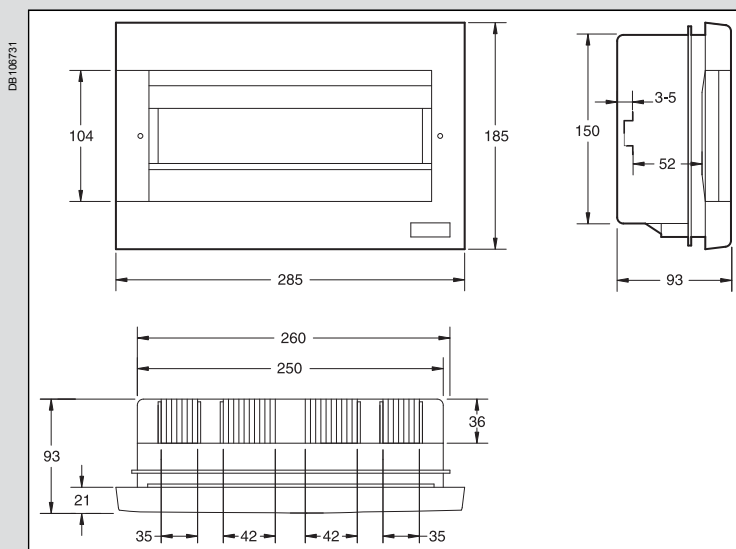


## Flush mounting Mini Pragma L (cont.)

2 rows 24 modules

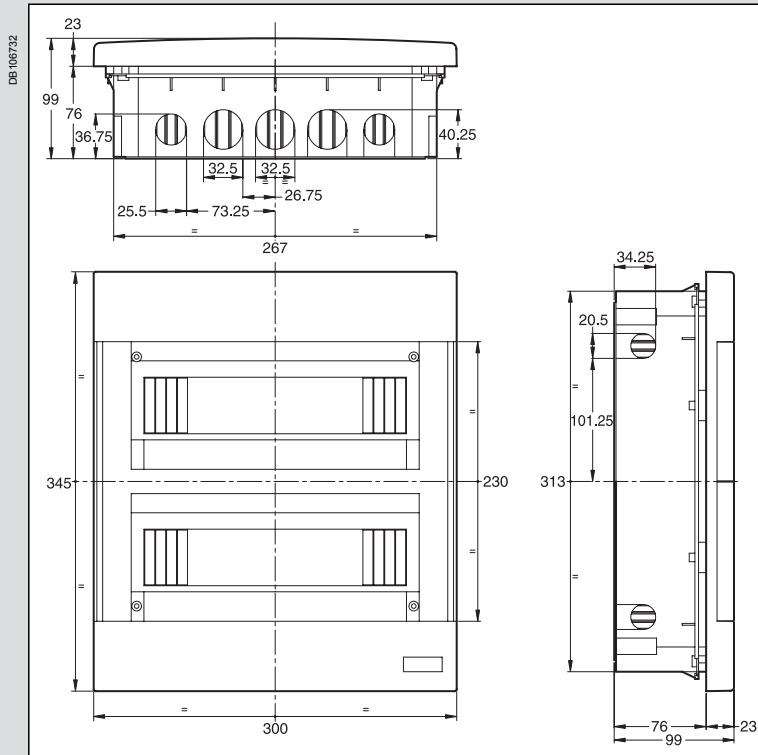


3 rows 36 modules

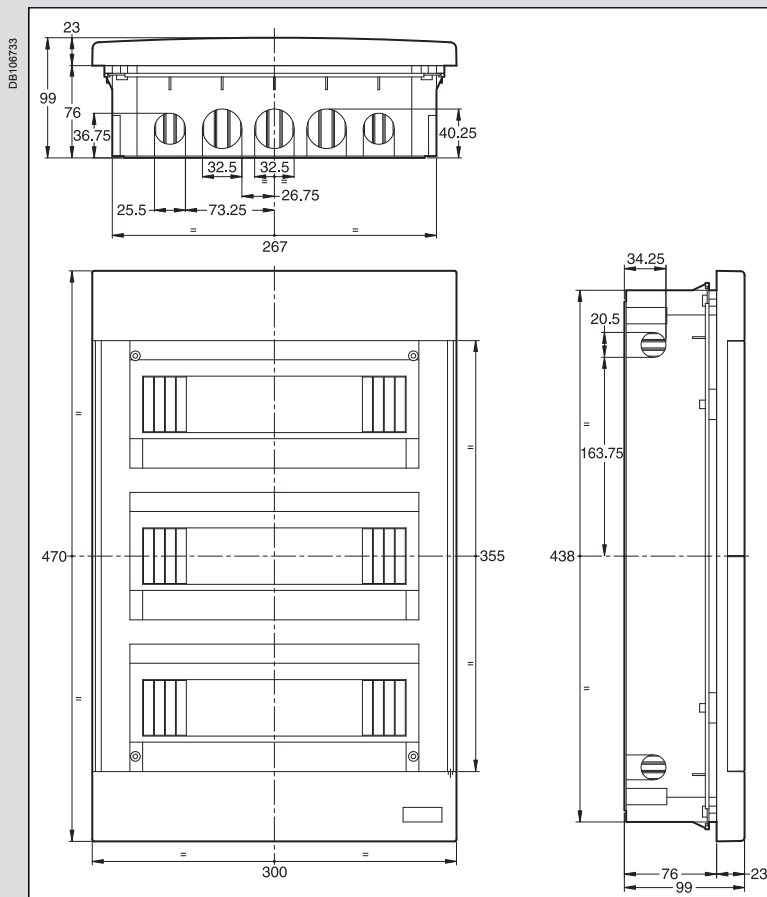


## Flush mounting Mini Pragma

Side view

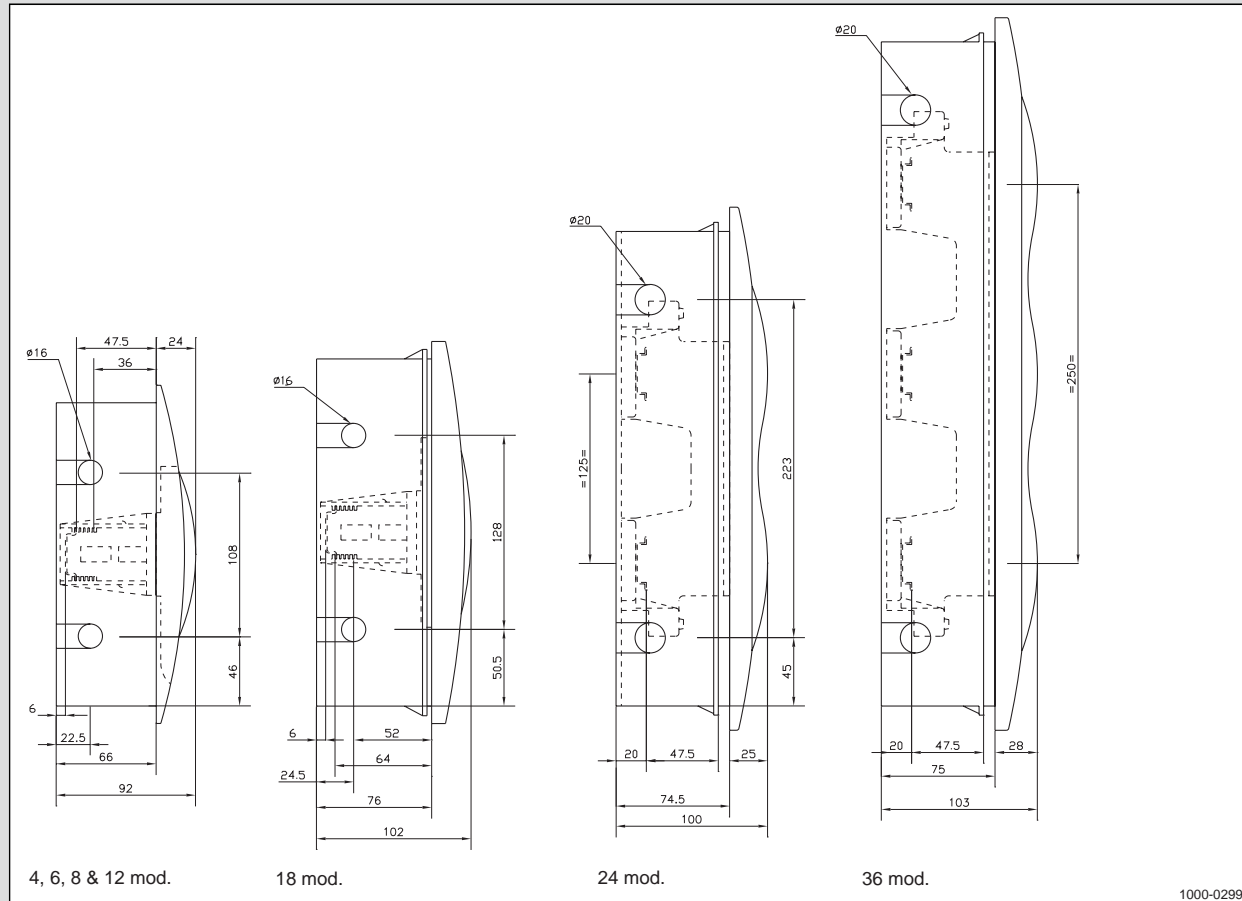

1000-0299

## Flush mounting

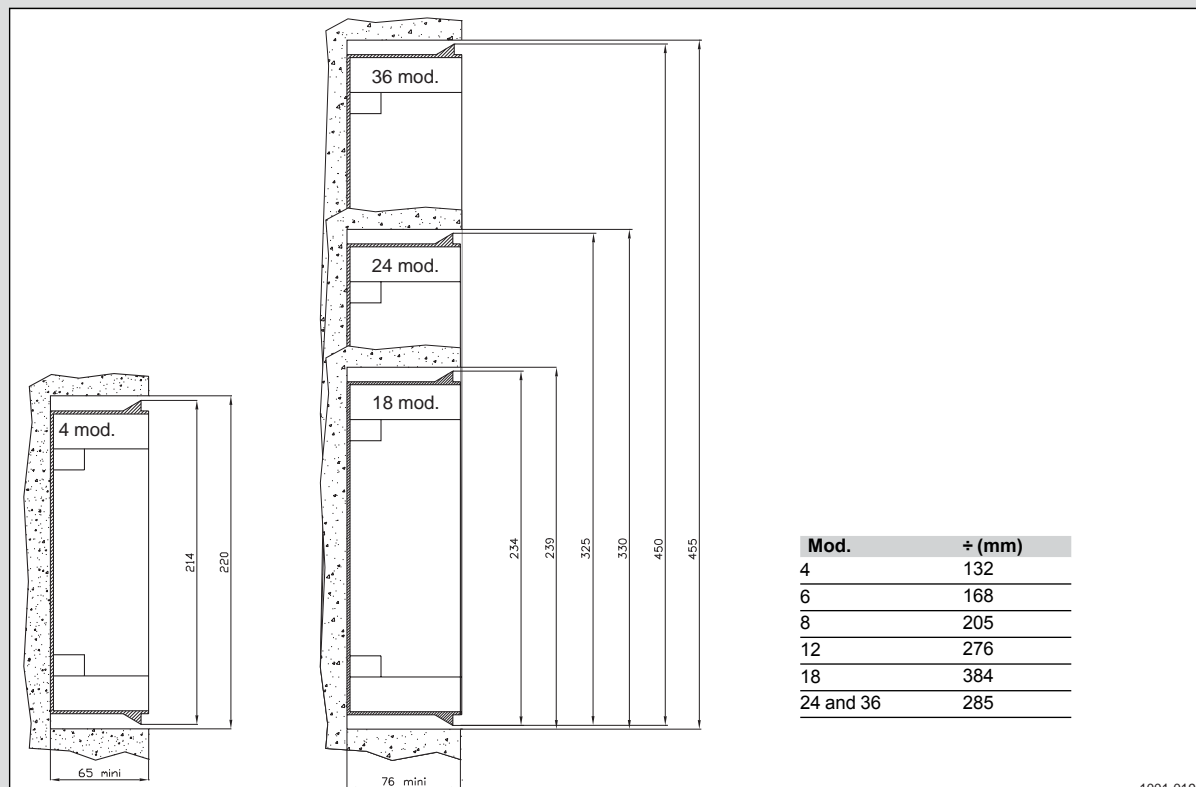


Mod.	÷ (mm)
4	132
6	168
8	205
12	276
18	384
24 and 36	285


1001-0199

## Flush mounting Mini Pragma (cont.)

### Top view

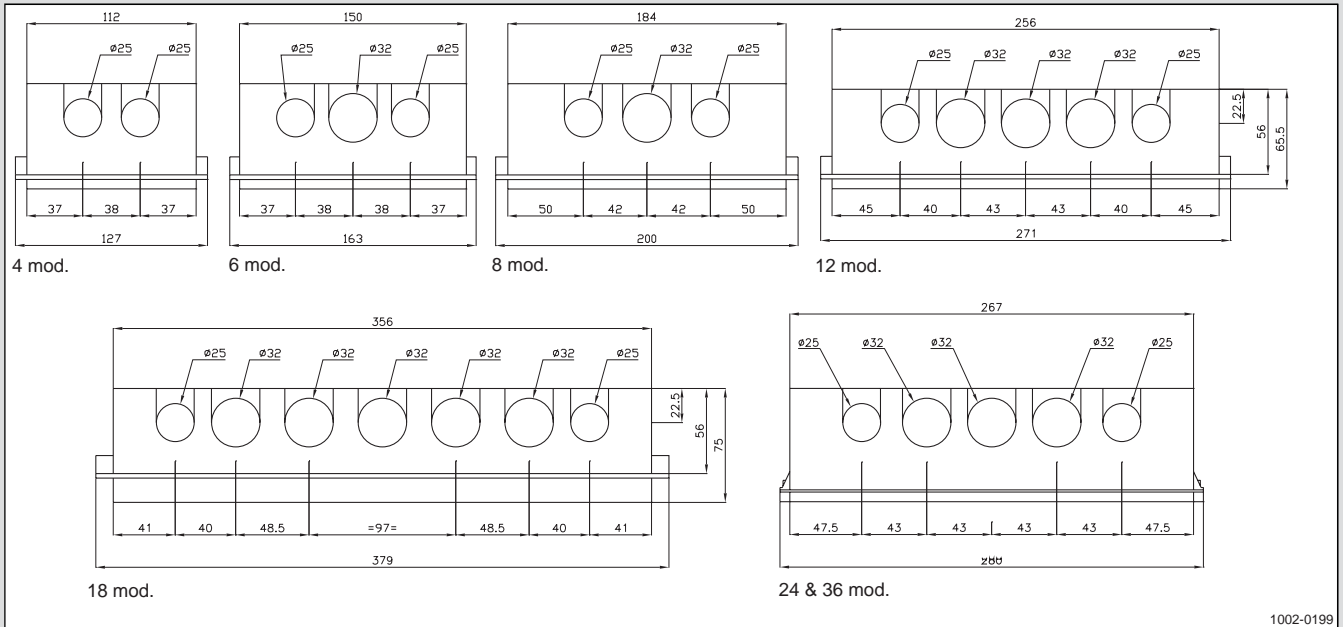


### Front view

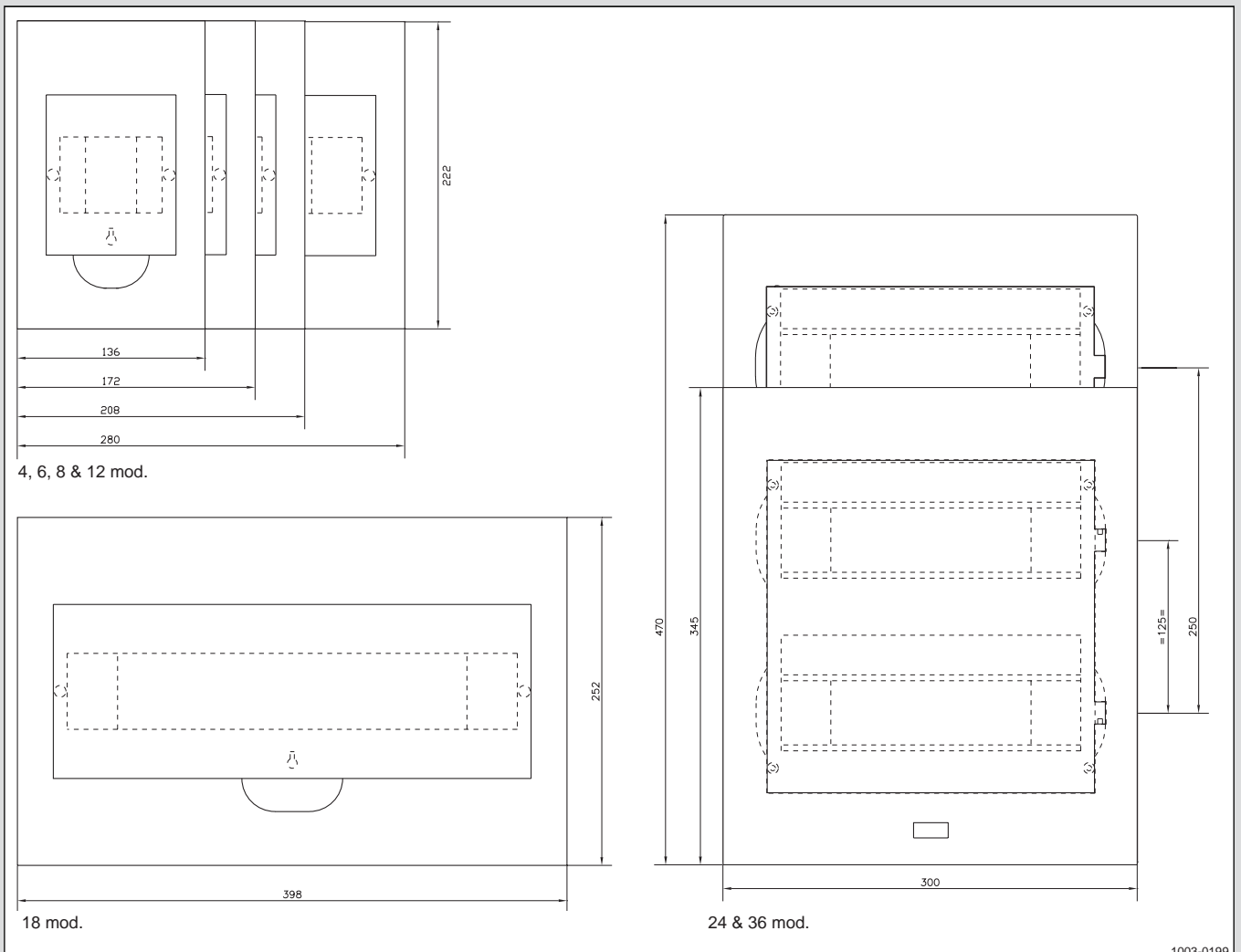


## Surface mounting Mini Pragma

### Side view

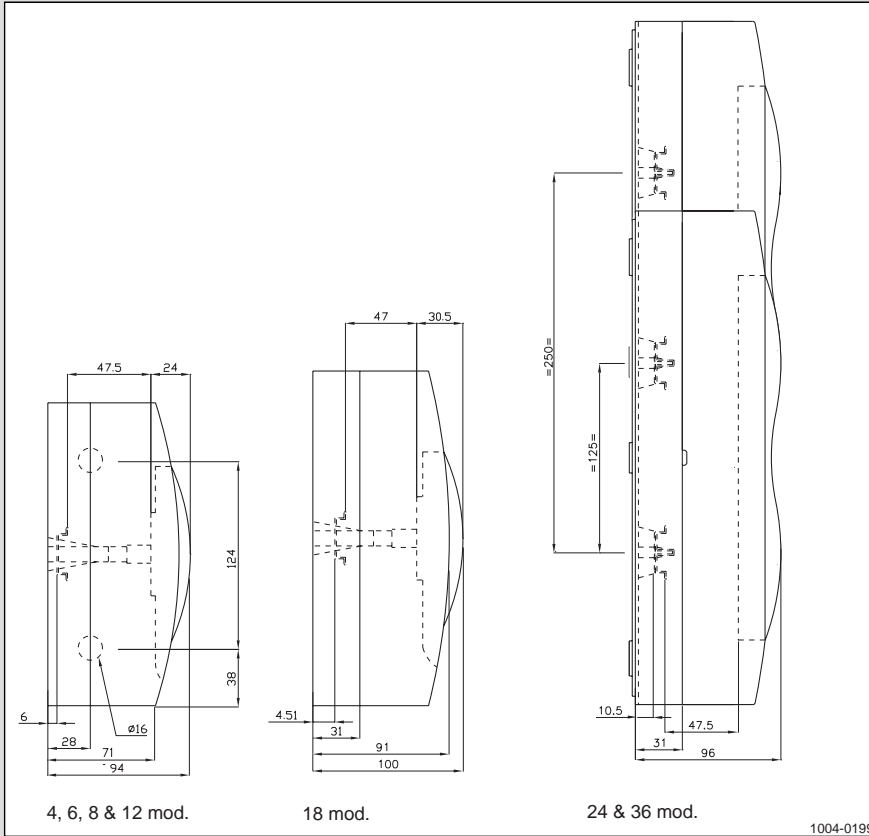


### Front view

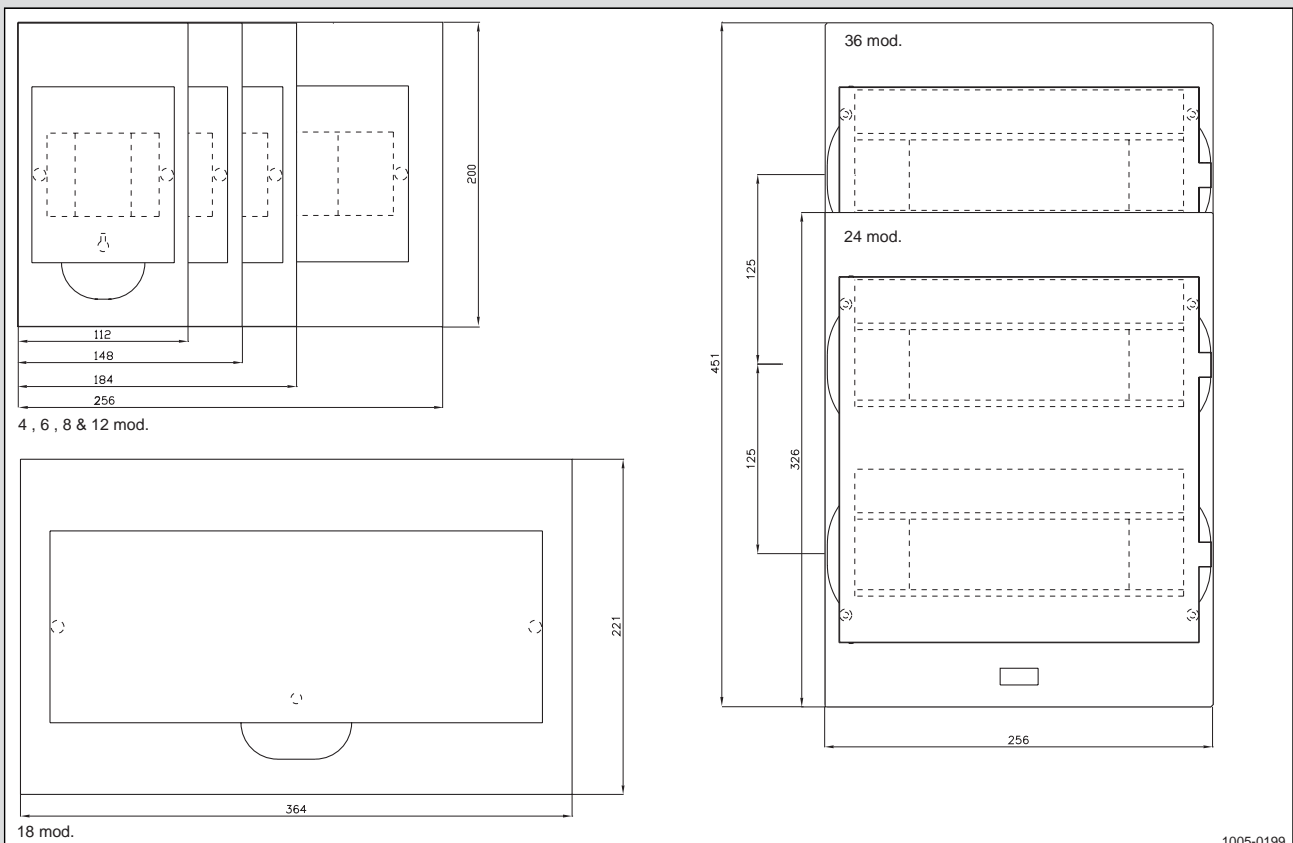

## Surface mounting Mini Pragma (cont.)

### Top view

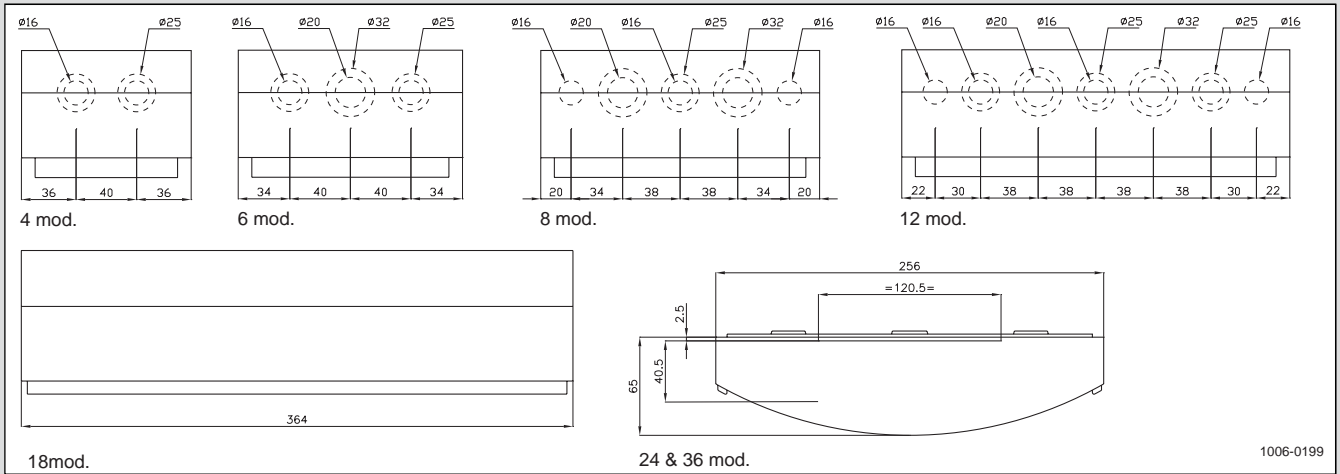

### Back view

