

CERTIFICATE FI/40826

Our Ref. HEL-CERT200900434-01



Product Installation switch
Type 21409, 21405, 22148, 21410, 21406, 22149, 26041, 26040, 26506, BBV41619

Trademark  or 

Certificate Holder Schneider Electric Industries SAS
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

Technical information 1 A, 250 V~, IP20, IP44

Other information Installation switches and light indicators (E10 Lamp) for flush or Surface mounting.

The product is certified according to the following standard(s) EN 60669-1:2018
EN 62094-1:2003 + A11:2003

Validity This certificate is valid until 2025-09-28 provided that the Conditions for FI certification are met. This certificate includes the right to use the FI mark under the condition that changes (if any) will be checked at SGS Fimko before the product is brought onto market and that the conditions for FI certification are met.


Date of issue 2020-09-28

SGS Fimko Ltd

Signature



Matti Huttunen
Certification Engineer

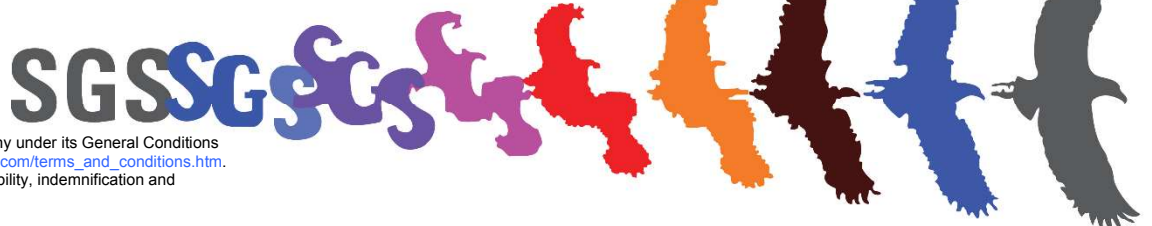

Manufacturer

Schneider Electric Industries SAS
35 Rue Joseph Monier, 92500, Rueil-Malmaison, France

Manufacturing site

1. Schneider Electric Danmark A/S
Tinvej 1- 5, 4100, Ringsted, Denmark
2. Elda-Eltra Elektrotechnika S.A
Bugno 1, 78-400, Szczecinek, Poland

Directive information

The certified product(s) fulfils requirements of mentioned standard(s) which are harmonised under the Low Voltage Directive (2014/35/EU) at the date of issue of the certificate.

Additional information

The product has certificate SE-S-2002240 issued by Intertek Semko AB in accordance with the Nordic Certification Service system.

| Type reference | Insert type | Terminals | IP-class | Brand | Design range | Mount |
|----------------|-------------|-----------|----------|---|-----------------------|---------|
| 21409 | PPB | screwless | IP20 |  | Trend, Renova, Robust | Flush |
| 21405 | PPB | screwless | IP20 |  | Quick-Rot | Surface |
| 22148 | PPB | screw | IP44 |  | Aqua-Stark/Artic | Surface |
| BBV41619 | PPB | screwless | IP20 |  | Exxact | Flush |

| Type reference | Insert type | Terminals | IP-class | Brand | Design range | Mount |
|----------------|-------------|-----------|----------|---|------------------|---------|
| 21410 | PPB + light | screwless | IP20 |  | Renova, Robust | Flush |
| 21406 | PPB + light | screwless | IP20 |  | Quick-Rot | Surface |
| 22149 | PPB + light | screw | IP44 |  | Aqua-Stark/Artic | Surface |
| BBV41619 | PPB + light | screwless | IP20 |  | Exxact | Flush |

| Type reference | Insert type | Terminals | IP-class | Brand | Design range | Mount |
|----------------|--------------|-----------|----------|---|------------------|---------|
| 26041 | Light signal | screwless | IP20 |  | Renova, Robust | Flush |
| 26040 | Light signal | screwless | IP20 |  | Quick-Rot | Surface |
| 26506 | Light signal | screw | IP44 |  | Aqua-Stark/Artic | Surface |
| BBV41619 | Light signal | screwless | IP20 |  | Exxact | Flush |

As shown in the Test Report(s) No(s): 2021556STO-001, 2021556STO-002