

Product	Socket outlets
Applicant	Schneider Electric Industries SAS 35, rue Joseph Monier, P.O Box 30323 FR 92506 Rueil-Malmaison Cedex France
Manufacturer	Schneider Electric Industries SAS 35, rue Joseph Monier, P.O Box 30323 FR 92506 Rueil-Malmaison Cedex France
Factory	Merten GmbH Fritz-Kotz-Strasse 8 DE-51674 Wiehl Germany
Ratings	16A 250V AC
Trade mark	Schneider Electric
Model / Type Ref.	270/**
Principal characteristics	IP 20, IP21, IP44, CEE 7/III. Flush-type socket-outlet 2P + E. Available with shutters and screw fixing.
A sample of the product was tested and found to be in conformity with	INST                    NEK 502:2016 IEC 60884-1:2002, IEC 60884-1:2002/AMD1:2006, IEC 60884-1:2002/AMD2:2013
Validity	This certificate documents conformity with the standards shown, and also applies as license for use of Nemkos name and certification mark. The certificate and license is valid as long as the applicable conditions are complied with, and provided that any changes to the product are notified to Nemko for acceptance prior to implementation. New standards or amendments to the standards may imply that the product design must be updated and/or that re-testing and re-certification is necessary.
Additional information	See attachment for model explanation  Socket-outlets with claw fixing are not certified for use in Norway. Socket-outlets without shutters are not certified for use in Norway.
Additional model(s)	No additional models

Date of issue 07-07-2017



Skule Moe

Certification Department

**Nemko AS**

Gaustadalléen 30, P.O. Box 73 Blindern, 0314 Oslo, Norway  
TEL +47 22 96 03 30 FAX +47 22 96 05 50 EMAIL info@nemko.com  
ENTERPRISE NUMBER NO974404532

# Attachment to certificate No. P17222158

## Socket-outlet type list:

### **System Basis** (Thermo/Duro)

270/2744, 270/2746, 270/2742, 270/2743, 270/2704, 270/2304

### **System M** (Thermo/Duro)

270/2371, 270/2373, 270/2376, 270/2374, 270/2300, 270/2301, 270/2309 with or without LED light module 2003, 270/2474, 270/2485, 270/2496, 270/2470, 270/2471, 270/2472, 270/2473, 270/2334 with **LED** light module 2334

### **System Design** (Thermo/Duro)

270/2375, 270/2377, 270/2372, 270/2379 with or without **LED** light module 2003, 270/2378, 270/2306, 270/2308, 270/2478, 270/2476, 270/2477

### **OctoColor**

270/2740, 270/2702, 270/2740

### **AQUADESIGN**

270/2330, 270/2335

### **Renova**

270/EAV54699

## Frame types:

### **System Basis** (Thermo+Duro)

#### **Atelier, MI:** (1 - 5 gang)

3971, 3972, 3973, 3974, 3975

### **System M** (Thermo+Duro)

#### **M-Smart:** (1 - 5 gang)

4841, 4842, 4843, 4844, 4845

#### **1M:** (1 - 5 gang)

3891, 3892, 3893, 3894, 3895

#### **M-Plan II:** (1 - 3 gang)

4881, 5124, 4882, 5125, 4883, 5126

#### **M-Plan:** (1 - 5 gang)

4861, 4862, 4863, 4864, 4865

#### **M-Plan Metall:** (1 - 5 gang)

4751, 4752, 4753, 4754, 4755

#### **M-Plan Echtglas:** (1 - 5 gang)

4891, 4892, 4893, 4894, 4895

#### **M-ARC:** (1 - 5 gang)

4851, 4852, 4853, 4854, 4855

#### **M-Star:** (1 - 5 gang)

4871, 4872, 4873, 4874, 4875

## Attachment to certificate No. P17222158

**Atelier-M:** (1 - 5 gang)  
3881, 3882, 3883, 3884, 3885

**System M - Elegance:** (1 - 5 gang)  
4021, 4022, 4023, 4024, 4025, 4031, 4032, 4033, 4034, 4035  
4041, 4042, 4043, 4044, 4045, 4051, 4052, 4053, 4054, 4055

**System M - Exxact (Thermo)**  
**Basic:** (1 - 5 gang)  
BBV49550, BBV49551, BBV49552, BBV49553, BBV49554

**Design:** (1 - 3 gang)  
BBV49558, BBV49559, BBV49561

**Solid:** (1 - 4 gang)  
BBV49558, BBV49559, BBV49561, BBV49589

**Solid Glass:** (1 - 4 gang)  
S1A45091, S1A45092, S1A45094, S1A45092

**Combi:** (1 - 5 gang)  
BBV49575, BBV49576, BBV49577, BBV49578, BBV49580

**Primo:** (1 - 6 gang)  
BBV49583, BBV49584, BBV49587, BBV49585, BBV49586, BBV54904,  
BBV54905

**Gasket for all 1P44 frames:** (1 - 3 gang)  
BBV49557, S1A33102, S1A33103

**System M - Creativ** (1 - 5 gang)  
4010-35, 4020-35, 4030-35, 4040- 4050-35, 4025-35, 4035-35,  
35,

**System Design** (Thermo + Duro)  
4811, 4812, 4813, 4814, 4831, 3981, 3982, 3983, 3984, 3985  
1815

**TRANCENT:** (1 - 4 gang)  
4821, 4822, 4823, 4824

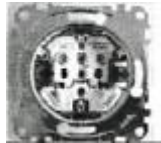


**OctoColor:** (1 - 5 gang)  
3991, 3992, 3993, 3994, 3999

**AQUADESIGN:** (1 - 4 gang)  
4011, 4012, 4013, 4014

**Renova**  
Glass frame: (1 - 3 gang)  
6BV28342, BBV28343, BBV28344  
Plastic frame: (1 - 5 gang)  
101370, 101371, 101372

## Attachment to certificate No. P17222158

Robust **Screw-Type (2701\*\*\*)** Socket Outlets, IK class IK09 (with shutter).

Insert	Center Cover	Center Cover Adapter
2701***	EAV54699	101599
		

Trend **Screw-Type (2701\*\*\*)** Socket Outlets

Insert	Center Cover (with Shutters)	Frames
270	NVE66783	100520 (1-gang) 100521 (2-gang) 100522 (3-gang) 100523 (4-gang) 101524 (5-gang)
