


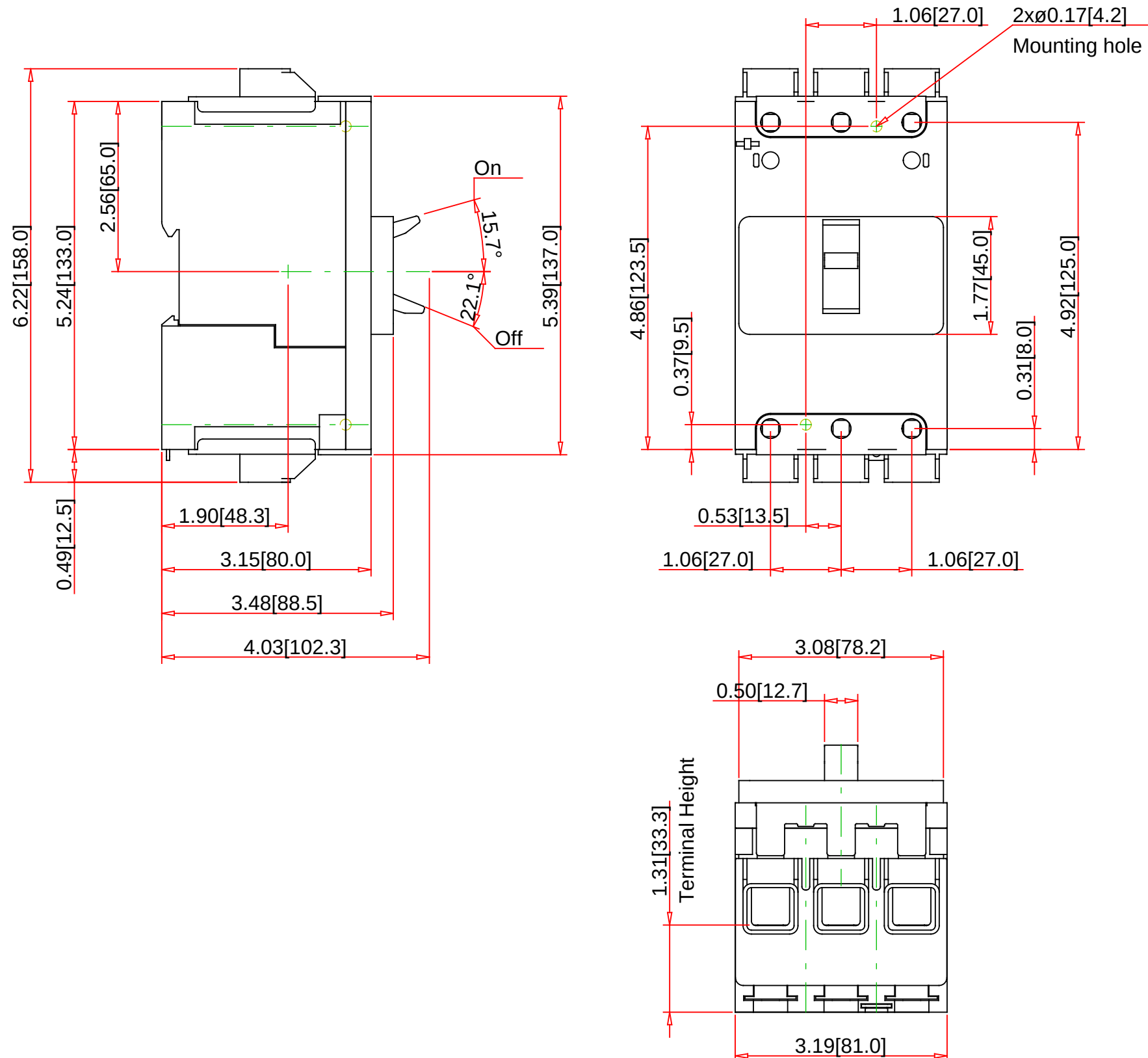

Note:
- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:
BDL36070

**SQUARE D**

by **Schneider Electric**

Schneider Electric United States
North American Division
Boston One Campus
800 Federal Street
Andover, MA 01810, USA
Phone: +1 877 342 5173
Email: CCC@us.schneider-electric.com

Technical Information:	
General Application:	Provides overload and short circuit protection
Approvals:	UL Listed - CSA Certified - IEC Rated
Mounting Type:	Unit Mount
Terminal Type:	ON end: EverLink Lugs / OFF end: EverLink Lugs
Weight:	3
Depth:	4.01
Height:	6.22
Width:	6.22
Mounting Height:	

Specification:	
Description:	PowerPact B-Frame Thermal Magnetic Circuit Breaker
Number of Poles:	3-Pole
Ampere Rating:	070
Voltage Rating:	600Y VAC
Interrupting Rating:	25kA at240VAC 18kA at480VAC 14kA at600Y/347VAC
Circuit Breaker Rating:	80% Rated
Fixed AC Magnetic Trip:	Hold: 640A - Trip: 960A