

Ultimate Polycarbonate Range

DUAL VOLTAGE SHAVER SUPPLY UNIT

This product is suitable for use in bathrooms for mains operated shavers only.

This shaver supply unit incorporates a safety overload cut out device, which if operated should automatically reset after a short delay.

Please check with manufacturers instructions for suitability with rechargeable shavers and toothbrushes.

IMPORTANT NOTICE WIRING COLOUR CHANGES

As from 1st April 2004 new installations could be wired using the new EU harmonised colours for the supply conductors of twin and earth cable:

New colours	Old colours
BROWN – LIVE	RED – LIVE
BLUE – NEUTRAL	BLACK – NEUTRAL

The old colours will cease to be used from 1st April 2006.

INSTALLATION AND WIRING INSTRUCTIONS

This shaver supply unit is suitable for mounting with either a 47mm deep 2 gang flush metal box or a 44mm deep 2 gang surface pattress box.

Please Note: Check orientation of box when fitting this shaver supply unit on a surface pattress box.

Some boxes will only accept this unit in one orientation and care should be taken when considering the required position for the supply cable entry.

1. Remove the clip-on front plate by holding the accessory in your hand with the front plate facing away from you. Place your thumbs over the two plastic lugs on the top edge and press outwards. The front plate should lift away from the body.
2. Remove suitable length of outer sheath from the supply cable. Remove 10mm from the live and neutral inner insulation to expose the conductor ends.
3. Insert Neutral conductor into the shaver supply unit terminal marked N and fully tighten the terminal screw.

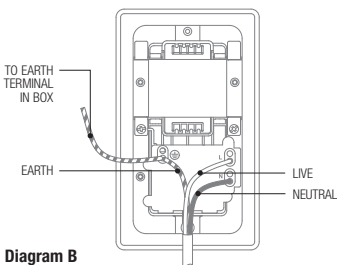


Diagram B

INSTRUCTIONS FOR USE

Select voltage required, 115 or 230V, by inserting shaver plug into the appropriate socket outlet; thereby energising the shaver supply unit transformer.

Any unauthorised reproduction of this booklet, in whole or part will be a breach of copyright and other intellectual property rights and infringement proceedings may be instituted to protect such intellectual property rights.

3. The product is not kept or used in areas of high humidity.
4. The product has not been misused or handled carelessly.
5. The product has not been tampered with.
6. The product has been properly installed in accordance with the relevant wiring regulations and installation practices.

SAFETY INSTRUCTIONS

All installation work should be undertaken by a competent person in accordance with the current edition of the IEE Wiring Regulations (BS 7671) and appropriate statutory regulations. In the Republic of Ireland the installation must be in accordance with the ETCI National Rules for Electrical Installations – ET101.

IF IN DOUBT, CONSULT A QUALIFIED ELECTRICIAN

Before starting any electrical work, ensure that the electricity supply is SWITCHED OFF at the mains. For additional safety, remove the fuse or switch off the circuit breaker at the fuse box or consumer unit.

Flexible cable colours remain unchanged:

BROWN – LIVE
BLUE – NEUTRAL

Eire conductor colours for twin and earth cable and flexible cable:

BROWN – LIVE
BLUE – NEUTRAL

For the best mounting results and visual appearance, it is recommended that prior to installation, the mounting surface beneath the accessory frontplate is first prepared to ensure that it is flat and all high spots have been removed.

4. Insert Live conductor into the terminal marked L and fully tighten the terminal screw (diagram B).
5. Before connecting the protective earth conductor, ensure that all bare earth conductors are sleeved with a length of Green/Yellow sleeving (not supplied).
6. Insert sleeved earth conductor into terminal marked \oplus .
7. Ensure that an additional sleeved earth conductor is also fitted between the shaver supply unit earth terminal and the earth terminal fitted in the mounting pattress or flush metal box.
8. Ensure all terminal screws are tight.
9. Fit the shaver supply unit onto the mounting box, taking care not to trap any cables.
10. Secure unit using the two fixing screws.
11. Hold the front plate over the accessory body and push together. As the front plate fits it will click into place.
12. Refit the supply fuse (if removed) and switch on mains supply.

After use, unplug shaver to switch off supply. The shaver supply unit designed to accept the following types of 2-pin plug:

1. British
2. European
3. Australian
4. American

GUARANTEE

This product is guaranteed for 25 years from the date of purchase against faulty materials or workmanship. During this period it will be repaired or replaced free of charge providing that:

1. The product is returned to GET via the electrical wholesaler from whom the product was originally purchased, together with proof of purchase.
2. The product has been used for its intended purpose and connected to a mass supply of 220-240 volts.

This Guarantee does not affect your statutory rights other than those expressly set out above and does not cover any claims for consequential loss or damage.



GET PLC, Key Point, 3-17 High Street, Potters Bar, Hertfordshire, EN6 5AJ
Helpline Telephone 0121 565 7770
www.getplc.com