

Pilot Lights (with LED lamp)

1. Select operator head type
2. Select pilot light lens type (plastic round dome or plastic fresnel)



Standard Pilot Light (with LED Lamp)			Pilot Light Lens Type	Pilot Light Lens Color	Catalog No.
Voltage	LED Lamp Color	Catalog No.			
24 VAC/DC	○ White	9001KP35LW	Plastic Dome Lens	○ White	9001W9
	● Green	9001KP35LG		● Green	9001G9
	● Red	9001KP35LR		● Red	9001R9
	● Yellow	9001KP35LY		● Yellow	9001Y9
	● Blue	9001KP35LL		● Blue	9001L9
	○ Clear	9001KP35LW		○ Clear	9001C9
	● Amber	9001KP35LY		● Amber	9001W9
120 VAC	○ White	9001KP38LW	Plastic Fresnel Lens	○ White	9001W31
	● Green	9001KP38LG		● Green	9001G31
	● Red	9001KP38LR		● Red	9001R31
	● Yellow	9001KP38LY		● Yellow	9001Y31
	● Blue	9001KP38LL		● Blue	9001L31
	○ Clear	9001KP38LW		○ Clear	9001C31
	● Amber	9001KP38LY		● Amber	9001A31

Push-to-Test Pilot Light (with LED Lamp)			Pilot Light Lens Type	Pilot Light Lens Color	Catalog No.
Voltage	LED Lamp Color	Catalog No.			
24 VAC/DC	○ White	9001KT38LW	Plastic Fresnel Lens	○ White	9001W31
	● Green	9001KT35LG		● Green	9001G31
	● Red	9001KT35LR		● Red	9001R31
	● Yellow	9001KT35LY		● Yellow	9001Y31
	● Blue	9001KT35LL		● Blue	9001L31
	○ Clear	9001KT35LW		○ Clear	9001C31
	● Amber	9001KT35LY		● Amber	9001A31
120 VAC	○ White	9001KT38LW	Plastic Fresnel Lens	○ White	9001W31
	● Green	9001KT38LG		● Green	9001G31
	● Red	9001KT38LR		● Red	9001R31
	● Yellow	9001KT38LY		● Yellow	9001Y31
	● Blue	9001KT38LL		● Blue	9001L31
	○ Clear	9001KT38LW		○ Clear	9001C31
	● Amber	9001KT38LY		● Amber	9001A31

Aluminum Legend Plates



Description	Catalog No.	Description	Catalog No.
Blank	9001KN200	Down	9001KN210
Start	9001KN201	Up	9001KN211
Stop	9001KN202	Fast	9001KN212
On	9001KN203	Slow	9001KN213
Off	9001KN204	Reset	9001KN223
Emergency Stop	9001KN205	Run	9001KN224
Forward	9001KN206	Off-On	9001KN244
Reverse	9001KN207	Stop-Start	9001KN255
Close	9001KN208	For-Off-Rev	9001KN259
Open	9001KN209	Hand-Off-Auto	9001KN260

Add-On Contact Blocks




Blocks	Catalog No.
1 N.O.+ 1 N.C.	9001KA1
1 N.O.	9001KA2
1 N.C.	9001KA3

Selling Points

- Heavy-duty push buttons, selector switches and pilot lights for industrial applications
- Rugged chrome-plated die-cast construction
- Oil tight, water tight and dust tight (rated for NEMA Types 4 and 13 environments without boots)
- Fingersafe® terminals on contact blocks
- Contact blocks feature double-break fine silver contacts with scrubbing action
- UL listed, CSA certified and CE marked

Simple Selector

30 mm Chrome Heavy-duty Push Buttons, Selector Switches and Pilot Lights

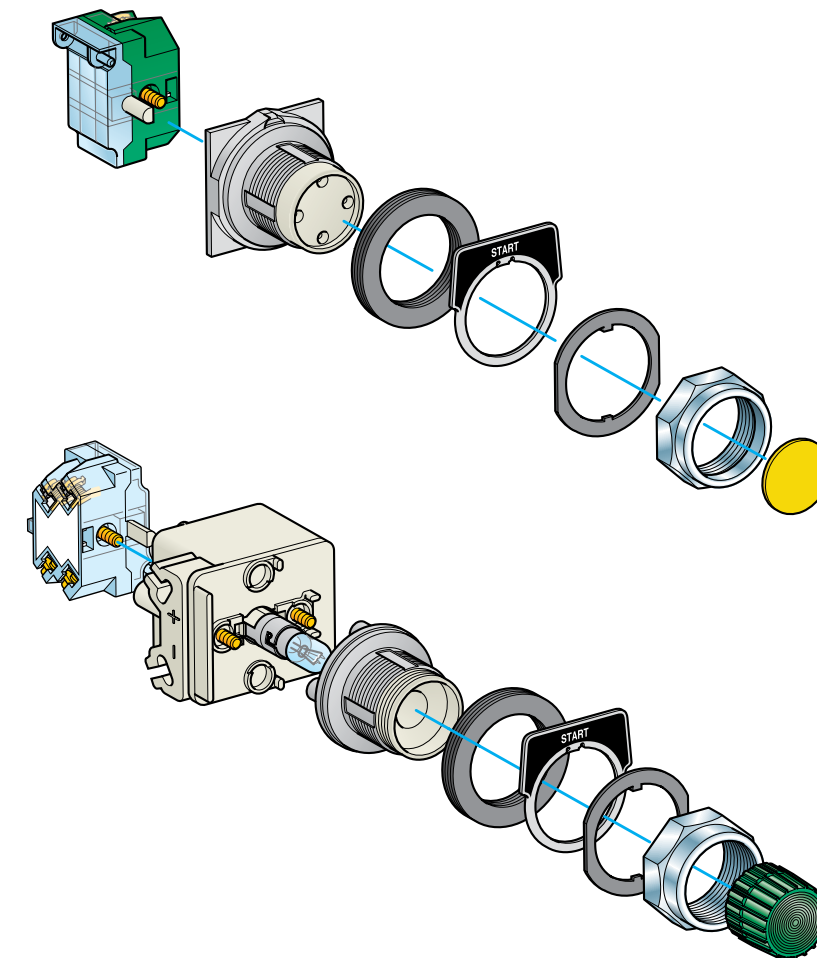

© 2010 Schneider Electric. All Rights Reserved.

Non-illuminated Push Button

1. Select operator head type
2. Select contact blocks



Operator Head Type	Action	Color	Catalog No.
Full Guard	Momentary	● Red	9001KR1R
		● Black	9001KR1B
		● Green	9001KR1G
Extended Guard	Momentary	● Red	9001KR2R
		● Black	9001KR2B
		● Green	9001KR2G
No Guard	Momentary	● Red	9001KR3R
		● Black	9001KR3B
		● Green	9001KR3G
2 Push Buttons (with interlocking mechanism)	Maintained	7-Colors	9001KR11U
Mushroom Head (screw-on) 1 3/8 in. (35 mm)	Momentary	● Red	9001KR4R
		● Black	9001KR4B
		● Green	9001KR4G
Mushroom Head (screw-on) 2 1/4 in. (57 mm)	Momentary	● Red	9001KR5R
		● Black	9001KR5B
		● Green	9001KR5G
Mushroom Head (snap-on) 1 3/8 in. (35 mm)	Momentary	● Red	9001KR4R
		● Black	9001KR4B
		● Green	9001KR4G
Mushroom Head (snap-In) 2 1/4 in.	Momentary	● Red	9001KR5R
		● Black	9001KR5B
		● Green	9001KR5G
2-Position Push-pull (screw-on) 1 3/8 in. (35 mm)	Maintained	● Red	9001KR8R
		● Green	9001KR8G
3-Position Push-pull (screw-on) 2 1/4 in. (57 mm)	Maintained	● Red	9001KR9R
		● Green	9001KR9G

Contact Block	Catalog No.
1 N.O. + 1 N.C.	9001KA1
1 N.O.	9001KA2
1 N.C.	9001KA3

Illuminated Push Buttons (with LED lamp)

1. Select operator head type
2. Select plastic fresnel lens
3. Select contact blocks



Operator Head Type	Voltage	Color	Catalog No.
Full Guard	24 VAC/DC	○ White	9001K1L35LW
		● Green	9001K1L35LG
		● Red	9001K1L35LR
		● Blue	9001K1L35LL
		○ Clear	9001K1L35LW
		● Amber	9001K1L35LY
	120 VAC	○ White	9001K1L38LW
		● Green	9001K1L38LG
		● Red	9001K1L38LR
		● Blue	9001K1L38LL
		○ Clear	9001K1L38LW
		● Amber	9001K1L38LY
No Guard	24 VAC/DC	○ White	9001K2L35LW
		● Green	9001K2L35LG
		● Red	9001K2L35LR
		● Blue	9001K2L35LL
		○ Clear	9001K2L35LW
		● Amber	9001K2L35LY
	120 VAC	○ White	9001K2L38LW
		● Green	9001K2L38LG
		● Red	9001K2L38LR
		● Blue	9001K2L38LL
		○ Clear	9001K2L38LW
		● Amber	9001K2L38LY

Plastic Fresnel Lens Color	Catalog No.
○ White	9001W31
● Green	9001G31
● Red	9001R31
● Blue	9001L31
○ Clear	9001C31
● Amber	9001A31

Contact Block	Catalog No.
1 N.O. + 1 N.C.	9001KA1
1 N.O.	9001KA2
1 N.C.	9001KA3

Non-illuminated Key Switches

1. Select operator head type
2. Select contact blocks



Operator Head Type			
Number of Positions	Key Returns to Position	Key Removes from Position	Catalog No.
2-Position	Maintained	Left	9001KS11K1
		Right	9001KS11K2
		All	9001KS11K3
3-Position	Maintained	All	9001KS42K10
		Center	9001KS42K5

Desired Contact Configuration			Contact Block Mounting Position	
Lever Position Left	Lever Position Center	Lever Position Right	Side 2 Catalog No.	Side 1 Catalog No.
Off	—	On	9001KA2	—
Off	Off	On	9001KA2	
On	On	Off	9001KA3	

Non-illuminated Selector Switch

1. Select operator head type
2. Select switch handle color
3. Select contact blocks



Operator Head Type		
Number of Positions	Lever Returns to	Operator Head Catalog No.
2-Positions	Maintained	9001KS11
3-Positions	Maintained	9001KS43

Handle Type	Handle Color	Catalog No.
Standard Length	● Black	9001B11
	● Green	9001G8
	● Red	9001R8
	● Yellow	9001Y8
	● Blue	9001B8
	○ White	9001W8
Extended Length	● Black	9001B25
	● Green	9001G24
	● Red	9001R24
	● Yellow	9001Y24
	● Blue	9001L24
	○ White	9001W24

Desired Contact Configuration			Contact Block Mounting Position	
Lever Position Left	Lever Position Center	Lever Position Right	Side 2 Catalog No.	Side 1 Catalog No.
Off	—	On	9001KA2	
Off	Off	On	9001KA2	
On	On	Off	9001KA3	



N.O. = Normally Open
N.C. = Normally Closed