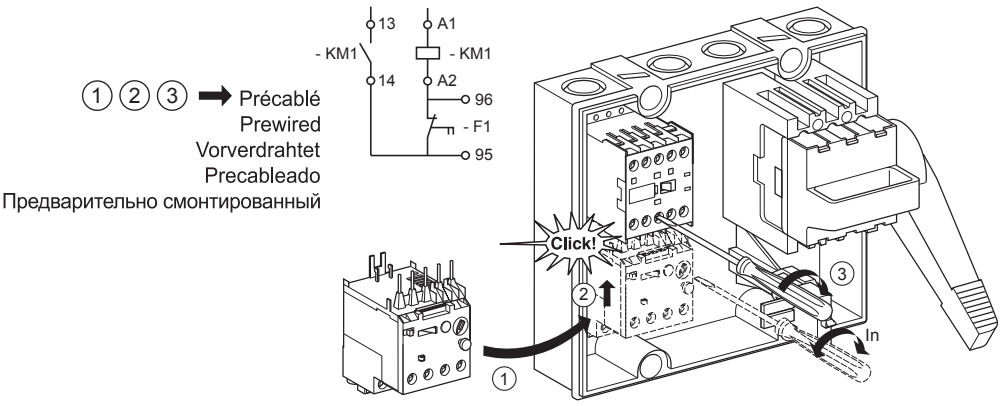
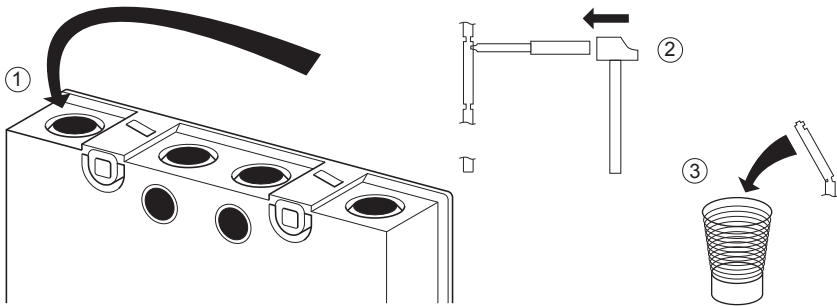
 
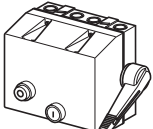
 

 


Raccordement mini ... maxi
 Wiring min ... max
 Anschlüsse min ... max
 Capacidad de conexión min ... max
 Проводка мин...макс

Philips N° 2						Ø 6 max					
[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm]	C	L	Ø	
[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm ²]	[mm]	[N.m]	[mm]	[mm]	
1 x 6,35 2 x 2,8	0,34 : 2,5	0,34...2,5 + 0,34...1,5	0,75 : 4	0,75...4 + 0,75...4	1,5 : 4	1,5...4 + 1,5...4	7	0,8	7	3	





							
kW (400 V)	In (A)			A	A	A	gl
0,37	1	LE4-K06	LR2-K0306	0,8...1,2	2	4	
0,55	1,5	LE4-K06	LR2-K0307	1,2...1,8	2	4	
0,75	1,9	LE4-K06	LR2-K0308	1,8...2,6	4	6	
1,1	2,5	LE4-K06	LR2-K0308	1,8...2,6	4	8	
1,5	3,4	LE4-K06	LR2-K0310	2,6...3,7	4	10	
2,2	4,8	LE4-K06	LR2-K0312	3,7...5,5	6	12	
3	6,3	LE4-K09	LR2-K0314	5,5...8	8	16	
4	8,1	LE4-K09	LR2-K0316	8...11,5	10	20	
Autres		LE4-K06	LR2-K0301	0,11...0,16	0,25	0,5	
Other		LE4-K06	LR2-K0302	0,16...0,23	0,25	0,5	
Anders		LE4-K06	LR2-K0303	0,23...0,36	0,5	1	
Otros		LE4-K06	LR2-K0304	0,36...0,54	1	1,6	
Другое		LE4-K06	LR2-K0305	0,54...0,8	1	2	

Schneider Electric Industries SAS

35, rue Joseph Monier
CS 30323
F - 92506 Rueil Malmaison Cedex

© 2015 Schneider Electric - All rights reserved.

Уполномоченный поставщик в РФ:

АО «Шнейдер Электрик»

Адрес: 127018, г. Москва, ул.
Двинцев, д.12, корп.1, тел. +7 (495)777 99 88,
факс: +7 (495)777 99 94, 8-800-200-6446
www.schneider-electric.ru

