

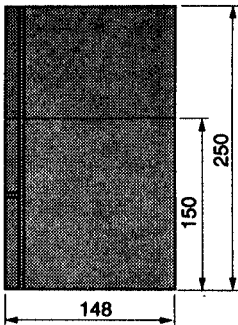



ABL-6RP●●●●

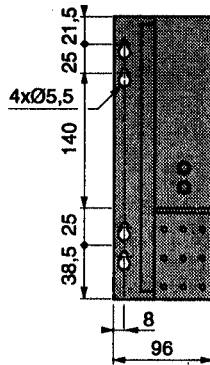

ABL-6RP1202
ABL-6RP2402
ABL-6RP2403

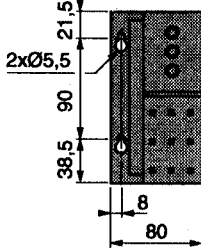


ABL-6RP2406
ABL-6RP2412
ABL-6RP4806

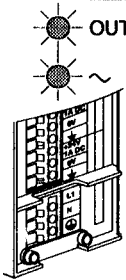

OUT (1-2)


OK

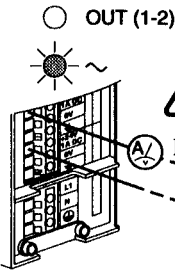

OUT (1-2)




$I > 1,15 I_n$

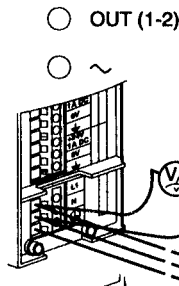


OUT (1-2)



$V < 90 V \sim$

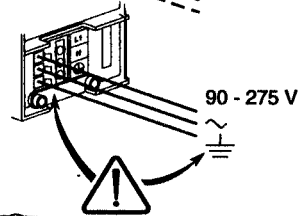

90 - 275 V

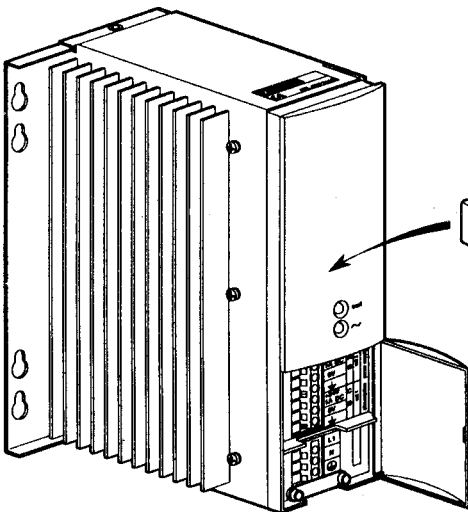

AR1-SB3

AB1Rø/Gø

mm ² / AWG		mm ² / AWG		C	(Nm)
0,2	24	0,2	24		
2,5	14	4	12	0,6	

Ø 3,5

ABL-6RP1202
 ABL-6RP2402

