

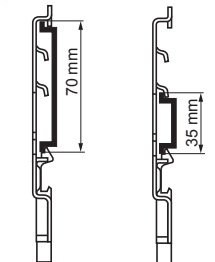
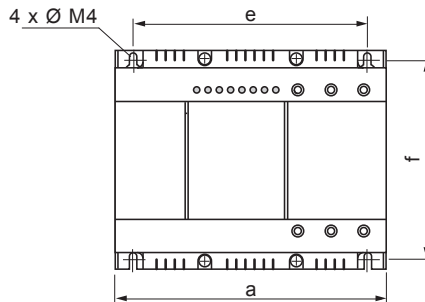


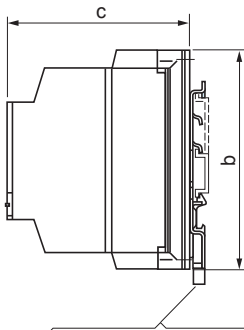


 
00162468713035

Altistart


ATS 01N2●●Q/LY

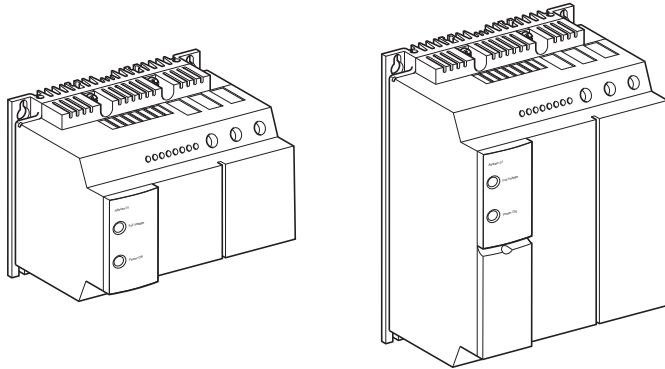


	a mm	b mm	c mm	e mm	f mm
ATS 01N230 LY ATS 01N244 LY ATS 01N244 Q	180	146	126	156	132
ATS 01N272 LY ATS 01N272 Q ATS 01N285 LY ATS 01N285 Q	180	254	126	156	242

				
	[mm ²]	AWG	Nm	lb/in
1/L1, 3/L2, 5/L3, 2/T1, 4/T2, 6/T3, $\frac{1}{2}$	≤ 25	≤ 2	5	45
00, 01, 02, 03, 04, 05, 06, 07	≤ 2,5	≤ 12	0,7	6


ATS 01N2●●LY

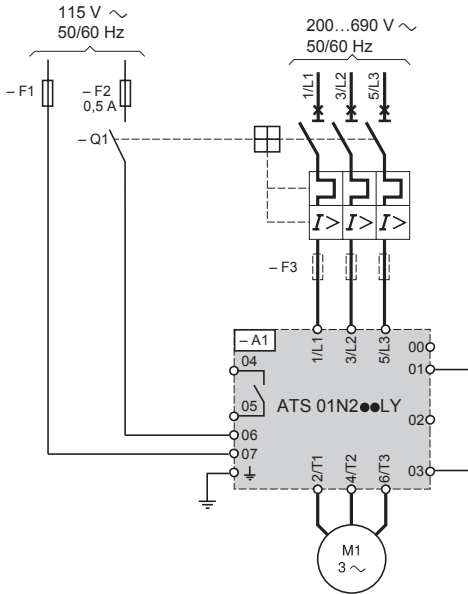


ATS 01N2●●Q

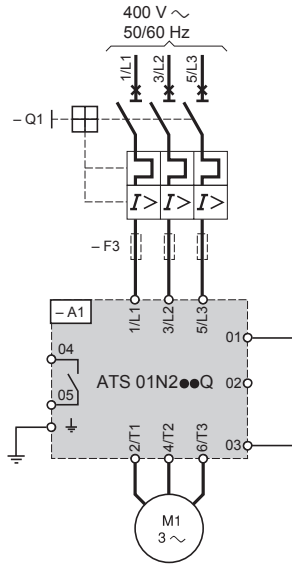


ATS 01N2●●LY

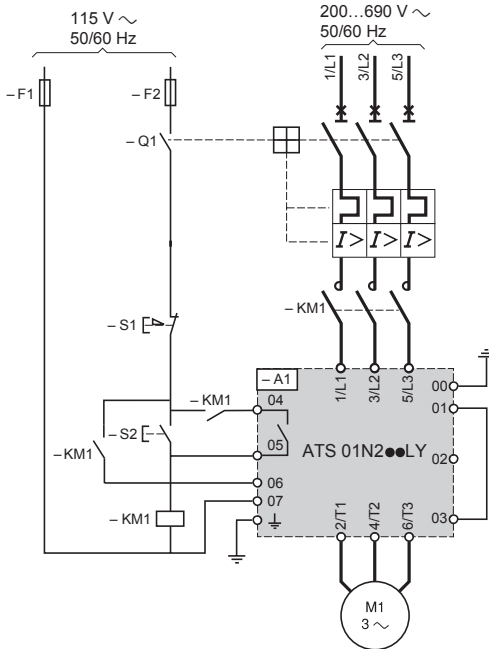


ATS 01N2●●Q

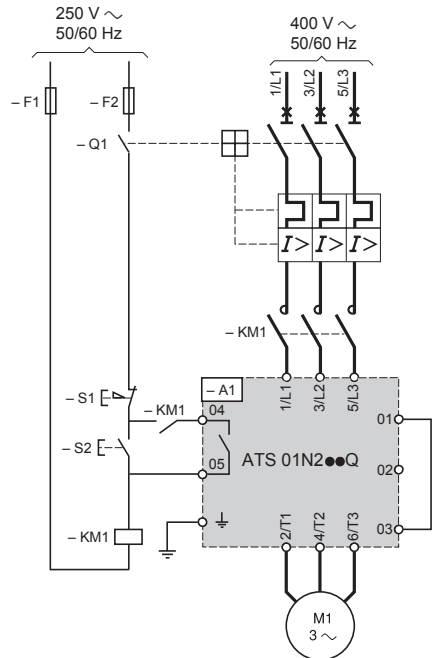


ATS 01N2●●LY

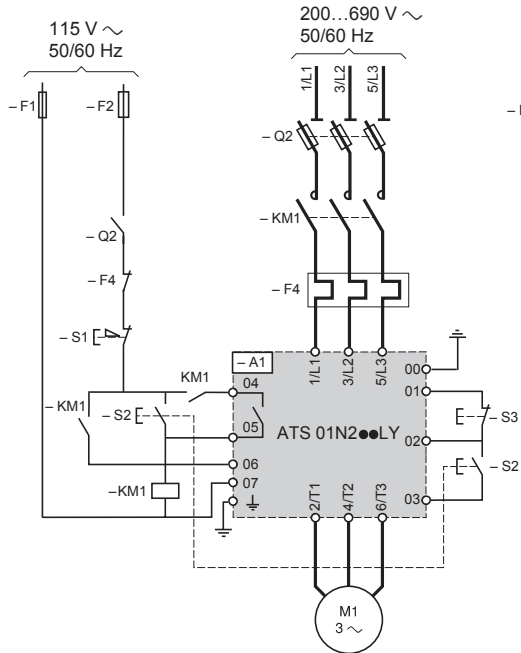

ATS 01N2●●Q

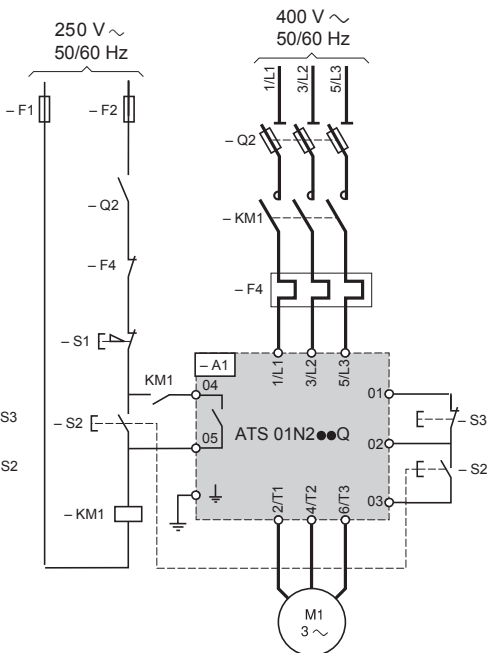

	UL  CLASS J
ATS 01N230●●	100 A
ATS 01N244●●	125 A
ATS 01N272●●	200 A
ATS 01N285●●	250 A

LAD8N11

