




00162474412021


Altistart

ATS 48●●●YS316


VW3 G48108

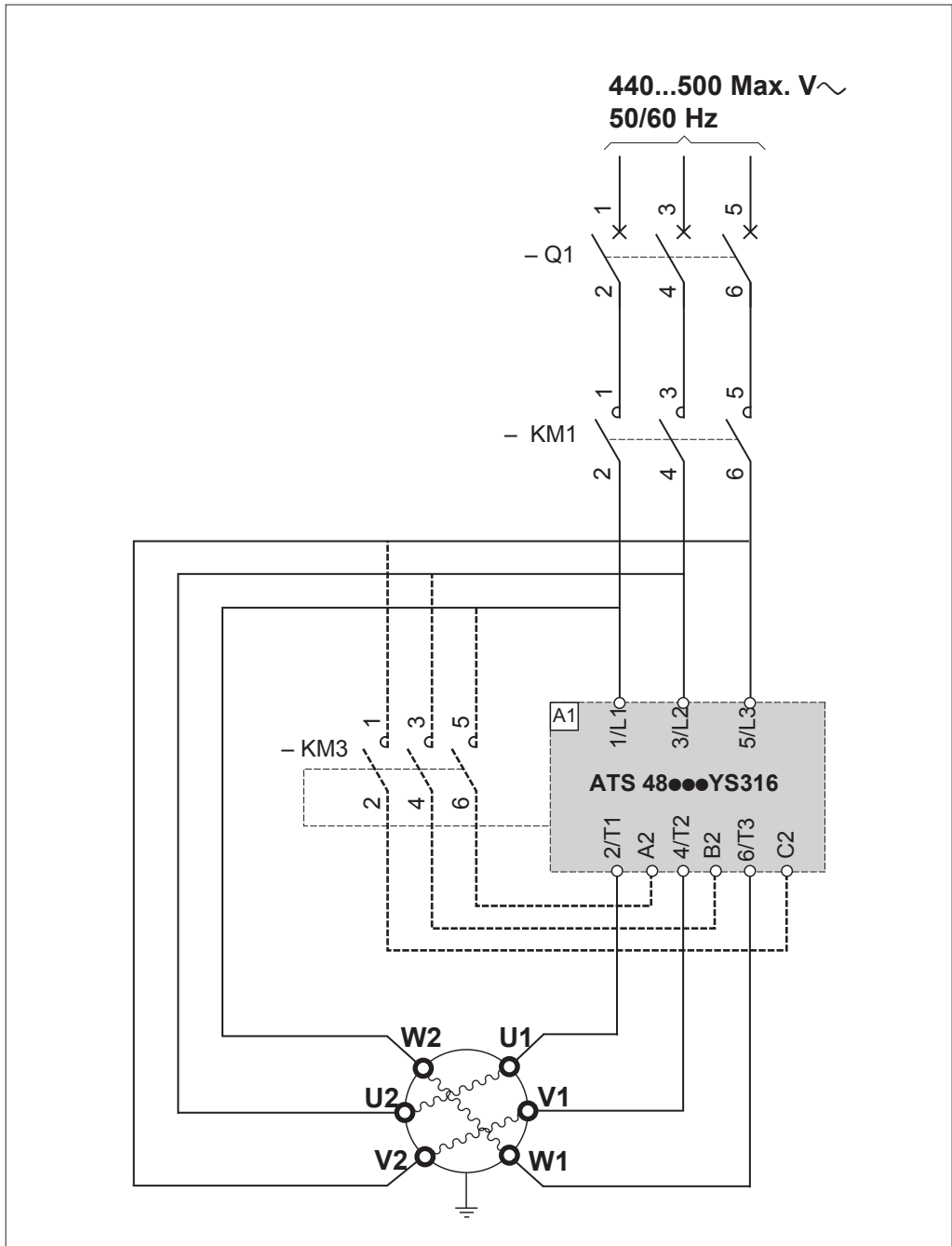

Application Standard
 Standard Application
 Standardanwendung
 Aplicación Estándar
 Applicazione in servizio Standard

			ATS48
440V	460 V	500 V	
kW	HP	kW	
15	20	18,5	ATS 48D17YS316
22	30	22	ATS 48D22YS316
30	40	37	ATS 48D32YS316
37	50	45	ATS 48D38YS316
45	60	55	ATS 48D47YS316
55	75	75	ATS 48D62YS316
75	100	90	ATS 48D75YS316
90	125	110	ATS 48D88YS316
110	150	132	ATS 48C11YS316
-	200	160	ATS 48C14YS316
200	250	200	ATS 48C17YS316
220	300	250	ATS 48C21YS316
250	350	315	ATS 48C25YS316
355	450	400	ATS 48C32YS316
500	600	500	ATS 48C41YS316
560	-	630	ATS 48C48YS316
710	-	710	ATS 48C59YS316
710	-	800	ATS 48C66YS316
900	-	900	ATS 48C79YS316
-	-	-	ATS 48M10YS316
-	-	-	ATS 48M12YS316

Application Sévère
 Severe Application
 Anwendung mit Schweranlauf
 Aplicación Severa
 Applicazione in servizio Severo

			ATS48
440V	460 V	500 V	
kW	HP	kW	
11	15	15	ATS 48D17YS316
15	20	18,5	ATS 48D22YS316
22	30	30	ATS 48D32YS316
30	40	37	ATS 48D38YS316
37	50	45	ATS 48D47YS316
45	60	55	ATS 48D62YS316
55	75	75	ATS 48D75YS316
75	100		ATS 48D88YS316
90	125	110	ATS 48C11YS316
110	150	132	ATS 48C14YS316
-	200	160	ATS 48C17YS316
160	250	200	ATS 48C21YS316
200	300	220	ATS 48C25YS316
250	350	315	ATS 48C32YS316
355	450	400	ATS 48C41YS316
400	500	500	ATS 48C48YS316
500	600	560	ATS 48C59YS316
560	-	630	ATS 48C66YS316
710	-	800	ATS 48C79YS316
900	-	900	ATS 48M10YS316
-	-	-	ATS 48M12YS316