



**Pumptrol[®] Pressure Switches,
Class 9013 Type FRG, Form H**


Complete Contact Replacement Kit
(includes new diaphragm)

Class 9998 Type PC290
All Form H devices


Important: The maximum allowable
pressure rating of this
switch is **300 psi.**

65013-005-99A

Wiring Diagram

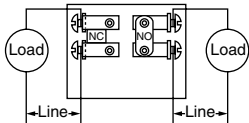

Adjustments

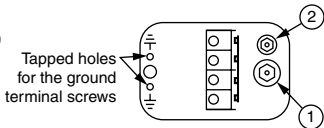

Adjust in the proper sequence:

1. Turn nut 1 down to raise the low operating point.
2. Turn nut 2 down to raise the high operating point.

CAUTION: To avoid damage, do not exceed the maximum allowable pressure. Check the switch operation after resetting.