



Option RFI 480/12-TN ... RFI 480/180-TN

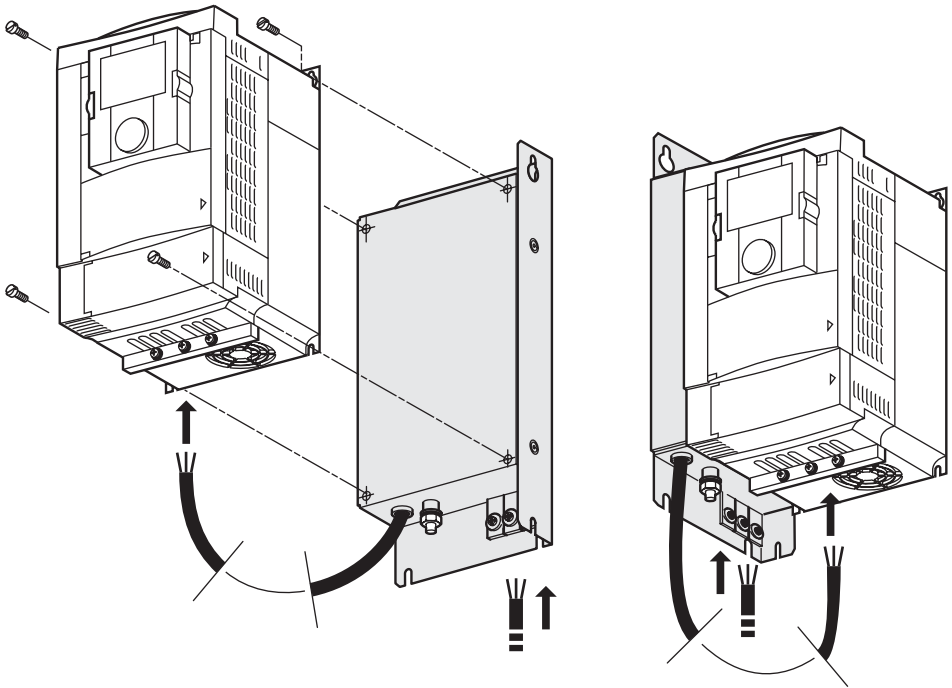

RFI 480/12-TN	8 P01 280 (VW3 A4 401)	M●4U07●●● ... M●4U22●●●
RFI 480/26-TN	8 P01 281 (VW3 A4 402)	M●4U30●●● ... M●4U40●●●
RFI 480/35-TN	8 P01 282 (VW3 A4 403)	M●4U55●●● ... M●4U75●●●
RFI 480/46-TN	8 P01 283 (VW3 A4 404)	M●4D11●●●
RFI 480/72-TN	8 P01 284 (VW3 A4 405)	M●4D15●●● ... M●4D18●●●
RFI 480/90-TN	8 P01 285 (VW3 A4 406)	M●4D22●●●
RFI 480/92-TN	8 P01 286 (VW3 A4 407)	M●4D30●●● ... M●4D37●●●
RFI 480/180-TN	8 P01 287 (VW3 A4 408)	M●4D45●●● ... M●4D75●●●




RFI 480/12-TN ... RFI 480/72-TN

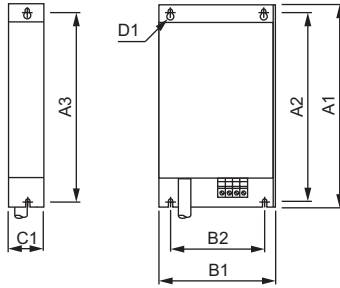

	A1	A2	A3	B1	B2	C1	D1
RFI 480/12-TN	290 mm	275 mm	275 mm	130 mm	105 mm	40 mm	4x Ø4,5 mm / 2x Ø4,5 mm
RFI 480/26-TN	325 mm	309 mm	309 mm	155 mm	130 mm	50 mm	4x Ø4,5 mm / 2x Ø4,5 mm
RFI 480/35-TN	370 mm	355 mm	355 mm	175 mm	150 mm	60 mm	4x Ø5,5 mm / 2x Ø5,5 mm
RFI 480/46-TN	380 mm	365 mm	365 mm	210 mm	190 mm	60 mm	4x Ø5,5 mm / 2x Ø5,5 mm
RFI 480/72-TN	500 mm	460 mm	480 mm	230 mm	190 mm	62 mm	4x Ø6,6 mm / 2x Ø6,6 mm

RFI 480/90-TN ... RFI 480/180-TN

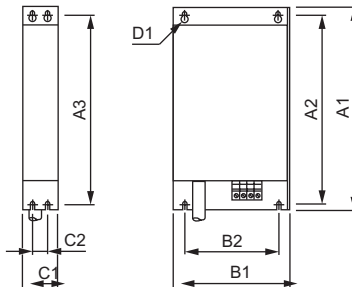

	A1	A2	A3	B1	B2	C1	C2	D1
RFI 480/90-TN	525 mm	502,5 mm	502,5 mm	240 mm	200 mm	79 mm	40 mm	4x Ø6,6 mm / 4x Ø6,6 mm
RFI 480/92-TN	650 mm	631 mm	631 mm	240 mm	200 mm	79 mm	40 mm	4x Ø6,6 mm / 4x Ø6,6 mm
RFI 480/180-TN	750 mm	725 mm	725 mm	320 mm	280 mm	119 mm	80 mm	4x Ø9 mm / 4x Ø9 mm

