

Thank you for choosing **Schneider Electric** Affle Plus series products. To ensure proper application of our product, please read through the following information before installation and use.

This application guide applies to the following products.

Cat. No.	Description
A3G30	1G Blank Plate
A3G30T	Twin Gang Blank Plate

SPECIFICATIONS

 

Mounting centre	: 60.3mm/120.6mm
Compliance	: BS5733, IEC 60670-1

IMPORTANT NOTE

1. The products must be installed by qualified electricians.
2. The wallbox depth should be $\geq 35\text{mm}$.
3. Please check your local wiring regulations before installation.
4. Safekeeping the surround to prevent damage during product installation.
5. Turn off the power supply when you clean the product. Use a soft, slightly-moistened cloth or tissue paper to wipe off the dust and dirt on the surface. Clean with much diluted detergent if necessary but avoid using corrosive chemicals.

MOUNTING INSTRUCTION

1. Screw the grid plate onto the wall box.
2. Snap the dolly and surround.

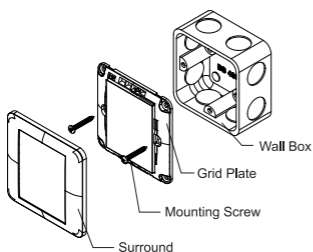

Insert a screwdriver into the clip lock, and twist the screwdriver to remove the surround and dolly .

感謝閣下選用 **Schneider Electric** 施耐德電氣 Affle Plus 系列產品。在安裝及使用本產品前，請仔細閱讀內文指示。

此手冊適用於以下產品型號：

型號	摘要
A3G30	單位空白掣面
A3G30T	兩位空白掣面

產品規格



安裝中心距	: 60.3mm/120.6mm
安全標準	: BS5733, IEC 60670-1

注意事項

1. 產品安裝須由符合資格的電工完成
2. 請用深度35mm以上的底箱
3. 安裝前請查核是否抵觸當地之有關布線規例
4. 產品安裝期間，請妥善放置與保管面蓋，以防壓傷損壞
5. 清潔時，切記先關上電源，再用輕微濕潤的軟性布料或紙巾抹拭表面的塵埃或贓物，必要時可用極為稀釋的清潔劑，但切忌使用帶有腐蝕性的化學溶液(如：堿性或酸性洗滌，稀釋劑，汽油，殺蟲劑等)，否則，可能會導致本產品表面開裂或其他故障

安裝指南

 1. 把內框固定於底箱;
2. 安裝邊框。

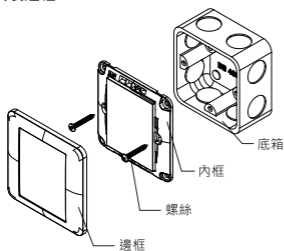

如需要拆下邊框，插入並扭轉螺絲批方可拆下。