

Thank you for choosing **Schneider Electric** Affle Plus series products. To ensure proper application of our product, please read through the following information before installation and use.

This application guide applies to the following products.

Cat. No.	Description
A3G31TB	25A 250V Connection Unit
A3G554	45A 250V Connection Unit


SPECIFICATIONS

Voltage	: 250V~
Mounting centre	: 60.3mm
Current	: 25A/45A
Compliance	: BS5733,MS1144

IMPORTANT NOTE


1. The products must be installed by qualified electricians.
2. The wallbox depth should be $\geq 35\text{mm}$.
3. Please check your local wiring regulations before installation.
4. Safekeeping the surround to prevent damage during product installation.
5. Turn off the power supply when you clean the product. Use a soft, slightly-moistened cloth or tissue paper to wipe off the dust and dirt on the surface. Clean with much diluted detergent if necessary but avoid using corrosive chemicals.

WIRING DIAGRAMS

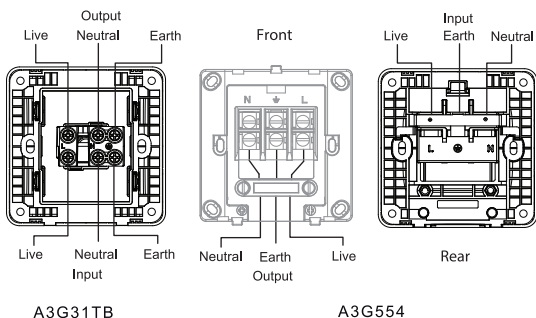

MOUNTING INSTRUCTION

1. Connect the wires to the terminals (recommend to leave 10-12mm bare metal wire) and tighten the terminal screws.
2. Screw the grid plate onto the wall box.
3. Snap the cover and surround.

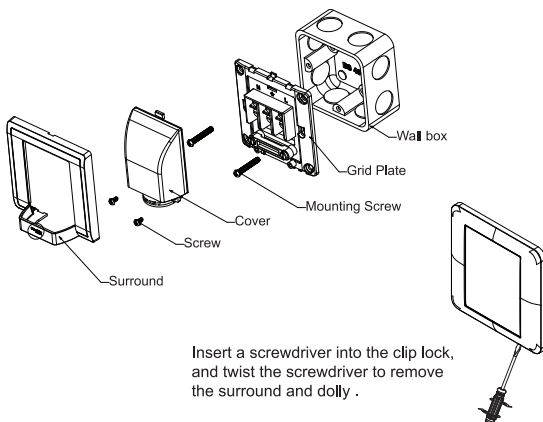

REV 01

感謝閣下選用 **Schneider Electric** 施耐德電氣Affle Plus系列產品。在安裝及使用本產品前，請仔細閱讀內文指示。

此手冊適用於以下產品型號：

型號	摘要
A3G31TB	25A 250V 單位接線蘇
A3G554	45A 250V 單位接線蘇


產品規格

工作電壓	: 250V~
安裝中心距	: 60.3mm
額定電流	: 25A/45A
安全標準	: BS5733,MS1144

注意事項

1. 產品安裝須由符合資格的電工完成
2. 請用深度35mm以上的底箱
3. 安裝前請查核是否抵觸當地之有關布線規例
4. 產品安裝期間，請妥善放置與保管面蓋，以防壓傷損壞
5. 清潔時，切記先關上電源，再用輕微濕潤的軟性布料或紙巾抹拭表面的塵埃或贓物，必要時可用極為稀釋的清潔劑，但切忌使用帶有腐蝕性的化學溶液(如：鹼性或酸性洗滌，稀釋劑，汽油，殺蟲劑等)，否則，可能會導致本產品表面開裂或其他故障

接線圖

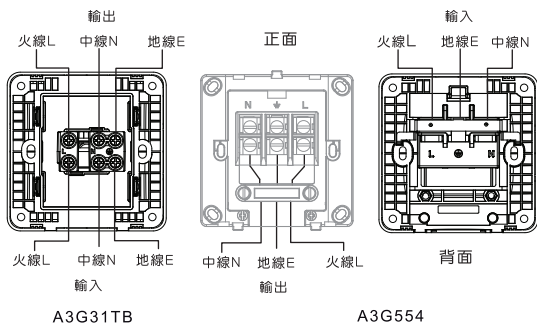

安裝指南

1. 把電線插入接線端子(建議剝線長度10-12mm)，然後鎖緊螺絲以固定位置;
2. 把內框固定於底箱;
3. 安裝面板與邊框。

