
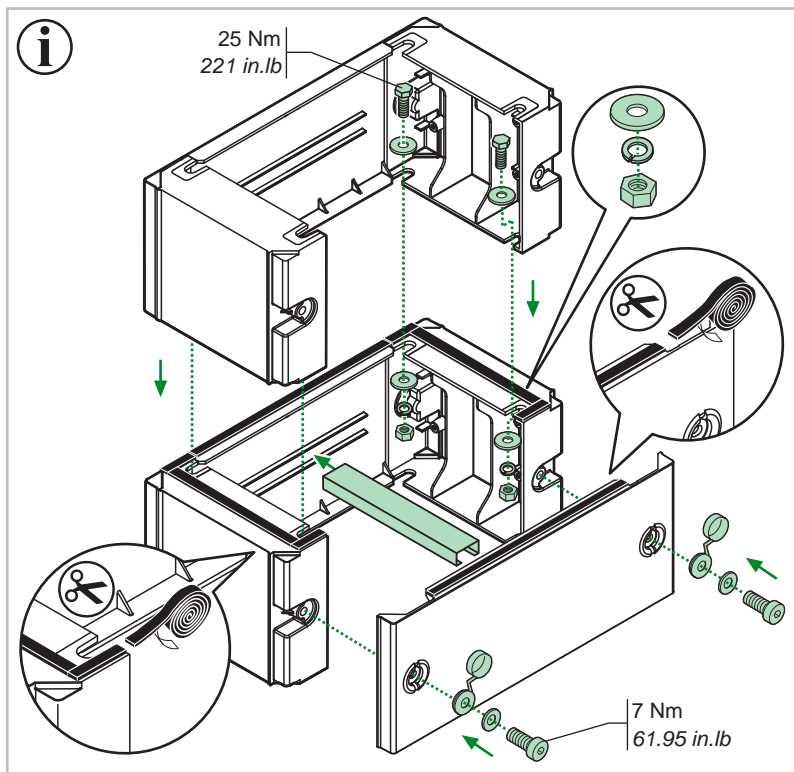
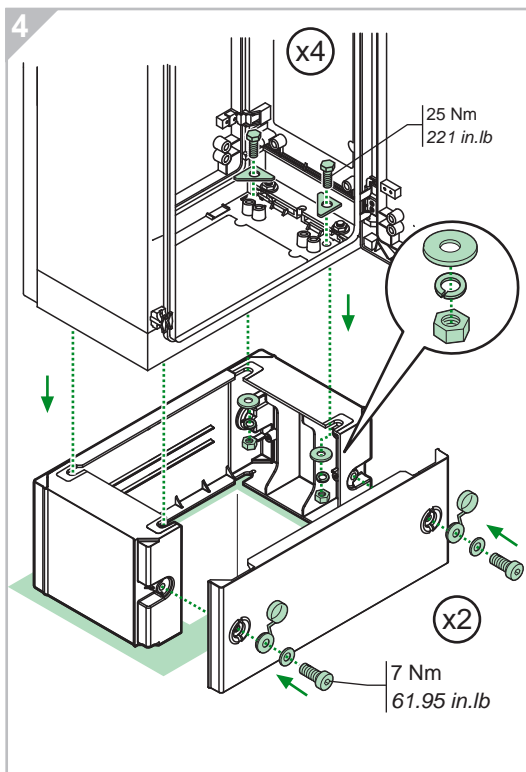
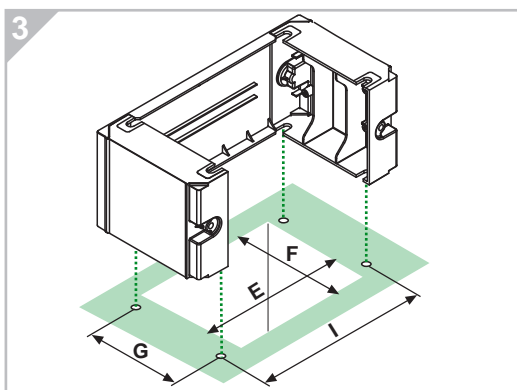
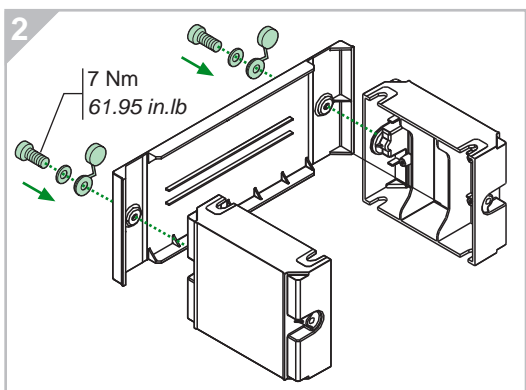


- x4 DIN7984 M8x20
- x4 DIN125 8,4
- x4 8,4
- x4 DIN934 M12
- x4 DIN7980 M12
- x4 DIN933 M12x35
- x8 DIN9021 13
- x4

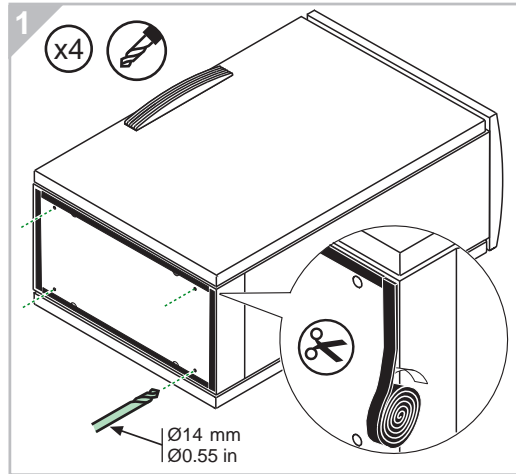

	<b>G</b>	<b>I</b>	<b>E max</b>	<b>F max</b>
<b>NSYZA253</b>	195 mm (7.67 in)	380 mm (14.96 in)	340 mm (13.38 in)	200 mm (7.87 in)
<b>NSYZA273</b>	195 mm (7.67 in)	630 mm (24.80 in)	590 mm (23.22 in)	200 mm (7.87 in)
<b>NSYZA2103</b>	195 mm (7.67 in)	880 mm (34.64 in)	840 mm (33.07 in)	200 mm (7.87 in)
<b>NSYZA2123</b>	195 mm (7.67 in)	1130 mm (44.48 in)	1090 mm (42.91 in)	200 mm (7.87 in)
<b>NSYZA254</b>	295 mm (11.61 in)	380 mm (14.96 in)	340 mm (13.38 in)	300 mm (11.81 in)
<b>NSYZA274</b>	295 mm (11.61 in)	630 mm (24.80 in)	590 mm (23.22 in)	300 mm (11.81 in)
<b>NSYZA2104</b>	295 mm (11.61 in)	880 mm (34.64 in)	840 mm (33.07 in)	300 mm (11.81 in)
<b>NSYZA2124</b>	295 mm (11.61 in)	1130 mm (44.48 in)	1090 mm (42.91 in)	300 mm (11.81 in)
<b>NSYZA276</b>	495 mm (19.49 in)	630 mm (24.80 in)	590 mm (23.22 in)	500 mm (19.68 in)
<b>NSYZA2126</b>	495 mm (19.49 in)	1130 mm (44.48 in)	1090 mm (42.91 in)	500 mm (19.68 in)