

Thank you for choosing **Schneider Electric** AvatarOn series products. To ensure proper application of our product, please read through the following information before installation and use.

This application guide applies to the following products.

(Notes: suffix_WE/WG/GH/LW/WD/ST_C5/G12 etc. mean the colors and sales areas)

Cat. No.	Description
E83T25ACUSB	13A Twin Gang Switched Socket with 21W 2 port Type A + Type C fast charging USB
E83T426ACUSB	13A Twin Gang Socket with 21W 2 port Type A + Type C fast charging USB

SPECIFICATIONS

USB rated input	: 100-250V~, 50/60Hz, 0.6A Max.
USB Output(Type A alone)	: 5V= 3A;9V= 2.3A;12V = 1.8A
USB Output(Type C alone)	: 5V= 3A;9V= 2.3A;12V = 1.8A
USB Output(Type A and Type C)	: 5V= 4.2A (2.4A Max for each port)
USB Protection	: Over heat,over current, over voltage,Short Circuit
Mounting centre	: 120.6mm
Operation Temperature	: 0-40°C
Socket Voltage/ Current	: 250V~ /13A

 
IMPORTANT NOTE

- The products must be installed by qualified electricians.
- Please check your local wiring regulations before installation.
- This permanently connected equipment does not contain internal disconnected device, a readily accessible disconnected device should be provided externally.
- Please install with a British Standard wall box of 47mm depth with 2 lugs to aid correct operation of the product. The product should be mounted on concrete or other non-combustible surfaces only.
- Please shield / mask the product before renovation to avoid contamination and degradation.
- Please keep the front cover safe in order to prevent damages before and during installation.
- If the product is not firmly fixed, it may cause electric shock.
- Turn off the power supply when cleaning the product. Use a piece of soft and dry cloth to wipe off the dirt and contamination on the surface. Do NOT use corrosive chemicals.
- Before charging with the product, please ensure the battery of your device is complied with Battery Charging Specification. Do not use multi-adaptors. Reserve charging is not allowed.
- The charging time depends on the supported charging protocol, power,

battery capacity, charging line quality and other factors decided by the charged device itself

- Some charging cables with electronic design might functions as charging device, connecting this kind of charging line may trigger the normal charging mode.
- Do not insert foreign objects (e.g. small metal wires, paper clips, liquids, etc.) into USB charger
- User will feel some heat at the product surface when charging is in progress
- Indoor use only


WIRING DIAGRAMS



MOUNTING INSTRUCTION

- Connect the wires to the terminals (recommend to leave 10-12mm bare metal wire) and tighten the terminal screws.
- Screw the grid plate onto the wall box.
- Snap the product cover.

Details

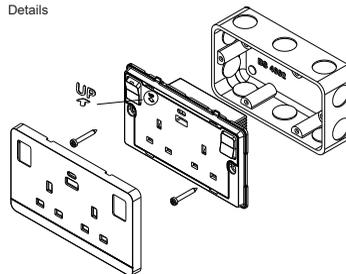

Insert a screwdriver into the clip lock, and twist the screwdriver to remove the cover.

