


	IP/IK								
		h	W	VA	230 V	mt	Kg		
OVA38072E	40/08	6 V 1,5 Ah Ni-Cd	1	6,5	11,5	20	30	60	4,30
OVA38073E	40/08	6 V 4 Ah Ni-Cd	3	6,5	11,5	20	30	60	4,75
OVA38074E	40/08	6 V 1,5 Ah Ni-Cd	1	7,5	11,5	20	30	80	5,15
OVA38075E	40/08	6 V 4 Ah Ni-Cd	3	7,5	11,5	20	30	80	5,60




MAXISLIM IP40

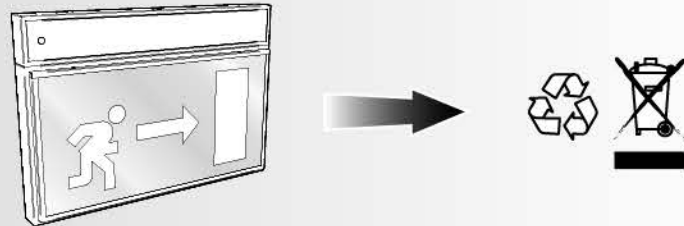


OVA38072E
OVA38073E
OVA38074E
OVA38075E

	x 4	Ø 4 mm		x 2	Ø 4 mm
	x 2			x 2	Ø 6 mm
	x 4	Ø 5 mm			
	x 2				
	x 2				
	x 1				
	x 1				

Schneider
Electric

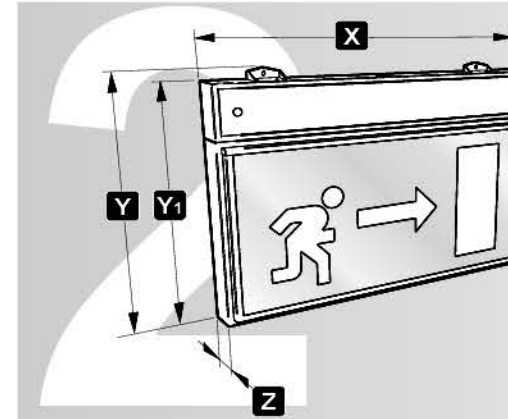

	X	Y	Y ₁	Z
OVA38072E/OVA38073E	644	469	443	80
OVA38074E/OVA38075E	804	549	523	80

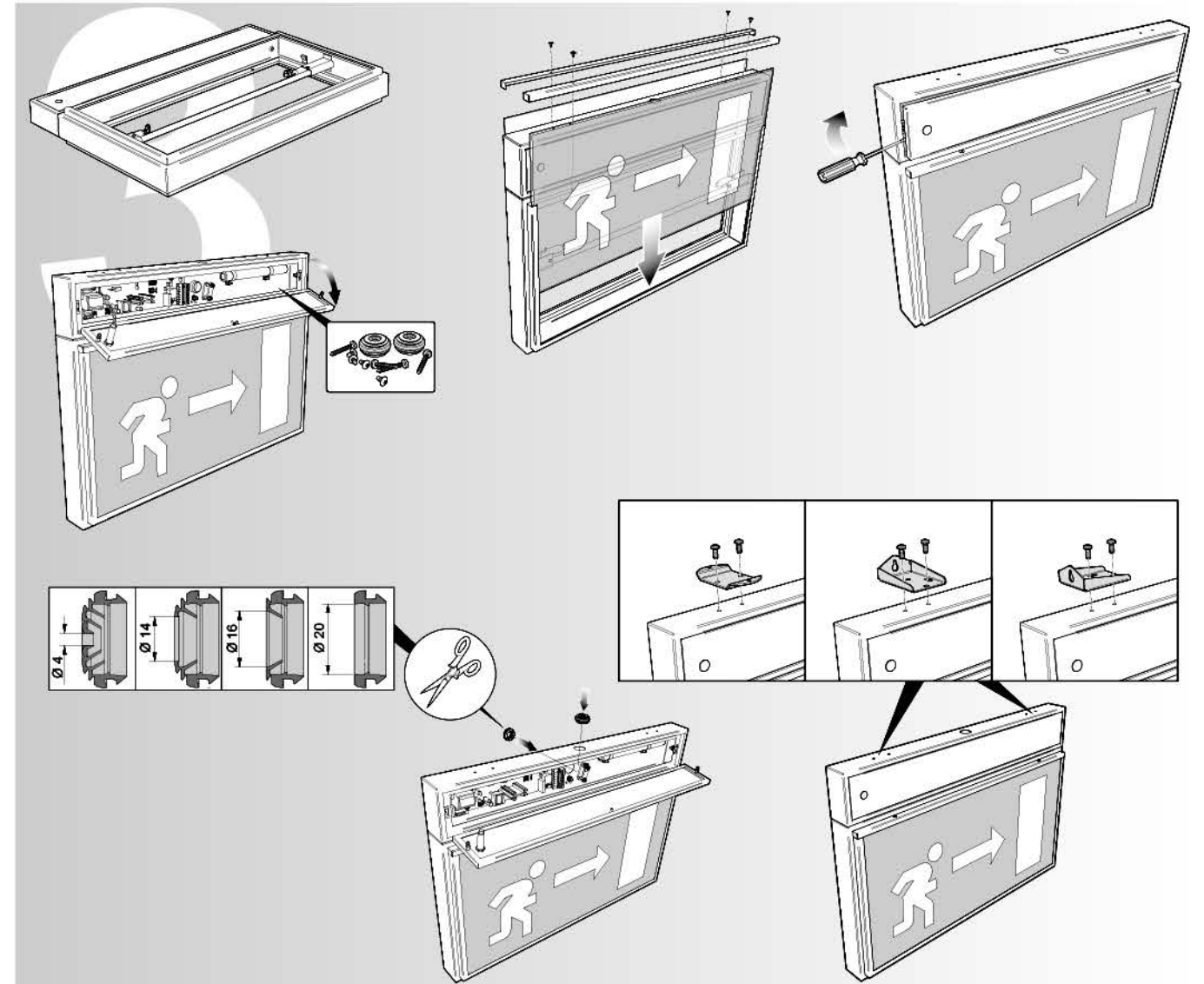

134136251-Ed.00-03/2009

