




by Schneider Electric

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 629.00 USD

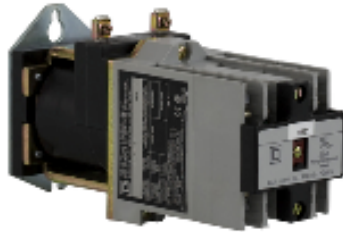


Main

Range of product	8501X
Relay type	Latching
Product or component type	Relay
[In] rated current	10 A AC 5 A DC
Contacts type and composition	8 NO 8 standard contact cartridges
Poles description	8P
[Uc] control circuit voltage	230/250 V DC
Maximum switching voltage	250 V DC
Mounting support	Panel
Ambient air temperature for operation	-40...160 °F
Electrical connection	Screw clamp terminals
Product certifications	CE CSA UL listed
Operating time	37 ms pick-up 45 ms drop-out

Ordering and shipping details

Category	21157 - 8501 XDO (DC)
Discount Schedule	CP2
GTIN	00785901819684
Nbr. of units in pkg.	1
Package weight(Lbs)	4.2000000000000002
Returnability	N
Country of origin	MX

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 1332 - Schneider Electric declaration of conformity  Schneider-Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Available
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Product Life Status : **Commercialised**