

Product data sheet

Characteristics

9422ATDN602


Operating mechanism, flange mounted, variable depth, 60A, 600 V, no fuse, switch mechanism, 6 inch handle, NEMA 4X



by Schneider Electric

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 941.38 USD

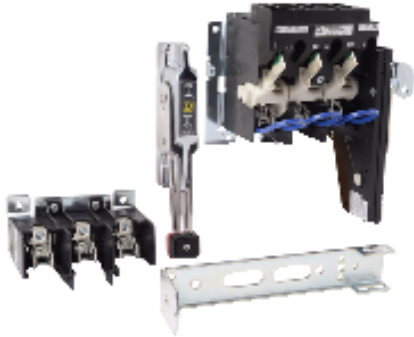

Main

Range of product	9422T
Product or component type	Disconnect Switch
Disconnect device type	Non-fusible disconnect switch

Complementary

Product mounting	Flange rod variable depth
Line Rated Current	60 A
Maximum Horse Power Rating	15 Hp 200 V AC 15 Hp 230 V AC 30 Hp 460 V AC 50 Hp 575 V AC 10 Hp 250 V DC
Provided equipment	6 in handle included NEMA 4/4X enclosures stainless steel

Environment

Product certifications	CSA UL Recognized
------------------------	----------------------

Ordering and shipping details

Category	21732 - 9422
Discount Schedule	CP1
GTIN	00785901316435
Returnability	No
Country of origin	MX

Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
PVC free	Yes

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status : **Commercialised**