

# Product data sheet


## Characteristics

# BCPMSCCT1

## BCPM 100A split-core CTs - set of 6 - 1.8m lead lengths

Product availability: Non-Stock - Not normally stocked in distribution facility

Price\*: 613.00 USD

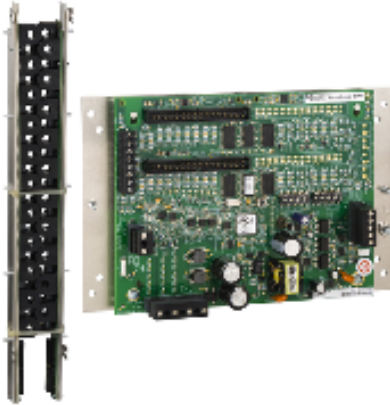

### Main

Range	PowerLogic
Range of product	PowerLogic
Product or component type	Current transformer
Output voltage	0.333 V
Electrical connection	Cable : 1.8 m 600 V
Line Rated Current	100 A

### Complementary

Product destination	BCPMSC
Current transformer type	Split core balance
Network frequency	50/60 Hz
Quantity per set	Set of 6
Width	Internal : 0.63 in (16 mm) External : 1.57 in (40 mm)
Depth	1.54 in (39 mm)
Height	Internal : 0.79 in (20 mm) External : 2.09 in (53 mm)

### Environment

Ambient air temperature for operation	32...140 °F (0...60 °C)
---------------------------------------	-------------------------

### Ordering and shipping details

Category	09793 - PLOGIC BRANCH CIRCUIT BCPM & MCM
Discount Schedule	PL1
GTIN	003606480344312
Nbr. of units in pkg.	1
Package weight(Lbs)	1.4000000000000001
Returnability	N
Country of origin	CN

Product Life Status : **Commercialised**