

# Product data sheet

## Characteristics


# HOM40L200RBI

## LOAD Center HOM RPLCMT INT ASSY 200A



by Schneider Electric

Price\*: 647.00 USD

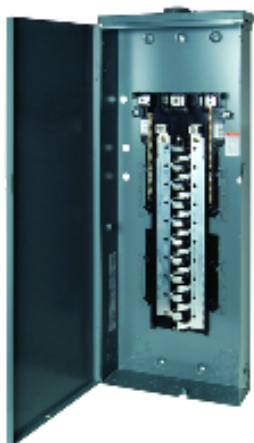

### Commercial status

This Product is Obsolete :

This Product is Obsolete

### Main

Product or component type	Load Center Interior Assembly
Range of product	Homeline
Load center type	Main lugs
Line Rated Current	200 A
Number of spaces	40
Short-circuit current	10 kA
Number of circuits	40
Number of tandem circuit breakers	0
Phase	1 phase
System Voltage	120/240 V AC

### Complementary

AWG gauge	AWG 4...250 kcmil (aluminium)
Device composition	Grounding bar (ordered separately)
Wiring configuration	3-wire
Material	Tin plated aluminium busbar
Product certifications	UL listed file E-6294

### Ordering and shipping details

Category	00185 - MISC. HOM LOAD CENTERS
Discount Schedule	DE3C
Nbr. of units in pkg.	1
Package weight(Lbs)	10
Returnability	N

### Offer Sustainability

RoHS (date code: YYWW)	Will be compliant on 3Q2014
REACH	Reference not containing SVHC above the threshold

Contractual warranty

---

Warranty period	Lifetime
-----------------	----------

---

Product Life Status : End of commercialisation