

Product data sheet

Characteristics

QO112M100C


QO LoadCenter, Main Breaker, 100A, 1PH-3W, 12SP, NEMA1, Comb. CV



by Schneider Electric

Product availability: Stock - Normally stocked in distribution facility

Price*: 351.00 USD

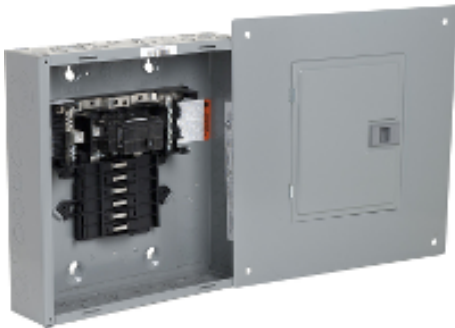

Main

Product or component type	Load Center
Range of product	QO
Load center type	Main breaker
Line Rated Current	100 A
Number of spaces	12
Short-circuit current	22 kA
Number of circuits	12
Number of tandem circuit breakers	0
Phase	1 phase
System Voltage	120/240 V AC

Complementary

AWG gauge	AWG 6...AWG 1 (aluminium/copper)
NEMA degree of protection	NEMA 1 indoor
Cover type	Combination flush/surface cover
Electrical connection	Lugs
Device composition	Grounding bar (ordered separately)
Electrical connection	Lugs
Wiring configuration	3-wire
Material	Tin plated copper busbar
Enclosure material	Welded sheet steel
Surface finish	Baked enamel grey
Box number	5
Product certifications	UL listed
Height	14.92 in (379 mm)
Width	14.25 in (362 mm)

Ordering and shipping details

Category	00001 - QO 1PH LC,12-42 CKT,NEMA1
Discount Schedule	DE3A
GTIN	00785901841272
Nbr. of units in pkg.	1
Package weight(Lbs)	16.129999999999999
Returnability	Y
Country of origin	US

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1248 - Schneider Electric declaration of conformity Schneider-Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product end of life instructions	Need no specific recycling operations
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------

Product Life Status : **Commercialised**