

# Product data sheet

## Characteristics

# QO12436L200TFT


## LOAD Center QO 240V 200A 1PH NEMA 1 FT



by Schneider Electric

Product availability: Stock - Normally stocked in distribution facility

Price\*: 732.00 USD

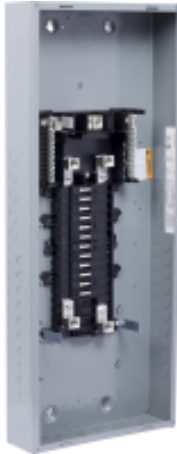

### Main

Product or component type	Load Center
Range of product	QO
Load center type	Main lugs
Line Rated Current	200 A
Number of spaces	24
Short-circuit current	65 kA
Number of circuits	36
Number of tandem circuit breakers	12
Phase	1 phase
System Voltage	120/240 V AC

### Complementary

AWG gauge	AWG 6...250 kcmil (aluminium/copper)
NEMA degree of protection	NEMA 1 indoor
Cover type	Order separately
Electrical connection	Feed-thru lugs
Device composition	Grounding bar (factory installed)
Electrical connection	Feed-thru lugs load side Lugs line side
Wiring configuration	3-wire
Material	Tin plated copper busbar
Enclosure material	Welded sheet steel
Surface finish	Baked enamel grey
Box number	10
Product certifications	UL listed
Height	858 mm
Width	14.25 in (362 mm)

## Ordering and shipping details

Category	00001 - QO 1PH LC,12-42 CKT,NEMA1
Discount Schedule	DE3A
GTIN	00785901046615
Nbr. of units in pkg.	1
Package weight(Lbs)	18.59
Returnability	Y
Country of origin	US

## Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1248 - Schneider Electric declaration of conformity <a href="#">Schneider-Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold
Product end of life instructions	Need no specific recycling operations
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

## Contractual warranty

Warranty period	18 months
-----------------	-----------

Product Life Status : **Commercialised**