

# Product data sheet

## Characteristics


# QO1816M150FTRBI

## LOAD CENTER QO REPLACEMENT INTERIOR



by Schneider Electric

Price\*: 755.00 USD

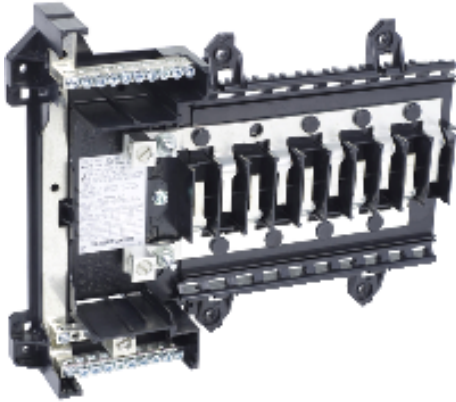

### Main

Product or component type	Load Center Interior
Range of product	QO
Load center type	Main breaker
Line Rated Current	150 A
Number of spaces	8
Short-circuit current	22 KA
Number of circuits	16
Number of tandem circuit breakers	8
Phase	1 phase
[Ue] rated operational voltage	120/240 V AC

### Complementary

Device composition	Grounding bar (ordered separately)
Material	Tin plated copper busbar
Product certifications	UL Listed

### Environment

Ambient air temperature for operation	23 °F (-5 °C) 104 °F (40 °C)
---------------------------------------	---------------------------------

### Ordering and shipping details

Category	00199-DE5 MISC. SERVICE PARTS
Discount Schedule	DE5
Package weight(Lbs)	10.00 Lb(US) (4.536 kg)
Returnability	Yes

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds which is known to the State of California to cause Carcinogen & Reproductive-harm. For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>
EU RoHS Directive	Will be compliant – Date to be confirmed

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status :	Commercialised
-----------------------	----------------