

Product data sheet

Characteristics

QO342M225110


QO LoadCenter, Main Breaker, 225A, 110A MB,
3PH, 42 SP, NEMA 1



by Schneider Electric

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 2027.00 USD

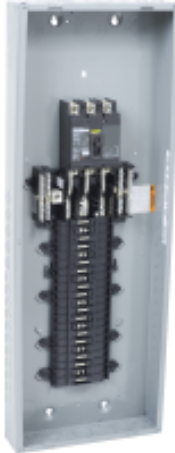

Main

Product or component type	Load Center
Range of product	QO
Load center type	Main breaker
Line Rated Current	110 A
Number of spaces	42
Short-circuit current	25 kA
Number of circuits	42
Number of tandem circuit breakers	0
Phase	3 phases
System Voltage	208Y/120 V AC 240/120 V delta AC 240 V delta AC

Complementary

AWG gauge	AWG 4...300 kcmil (aluminium/copper)
NEMA degree of protection	NEMA 1 indoor
Cover type	Order separately
Electrical connection	Lugs
Device composition	Grounding bar (ordered separately)
Electrical connection	Lugs
Wiring configuration	3-wire 4-wire
Material	Tin plated copper busbar
Enclosure material	Welded sheet steel
Surface finish	Baked enamel grey
Box number	12 14R
Product certifications	UL listed

Height	39.37 in (1000 mm)
Width	14.25 in (362 mm)

Ordering and shipping details

Category	00011 - QO 3PH LOAD CENTER,INDOOR
Discount Schedule	DE3
Nbr. of units in pkg.	1
Package weight(Lbs)	27.539999999999999
Returnability	N

Contractual warranty

Warranty period	18 months
-----------------	-----------

Product Life Status : **Commercialised**