

Product data sheet


Characteristics

QON130L200I

OEM mounting base, 30 spaces, 200 A, with neutral

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 417.00 USD

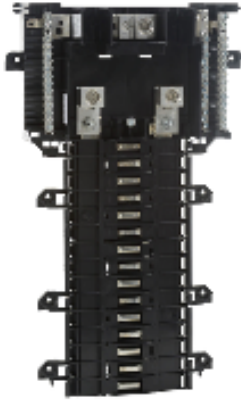

Commercial status

This Product is Obsolete :

This Product is Obsolete

Main

Range of product	QO
Line Rated Current	200 A
[Ue] rated operational voltage	240 V AC

Complementary

Number of spaces required	30
AWG gauge	AWG 4...250 kcmil copper or aluminium
Phase	Single phase

Environment

Product certifications	UR
------------------------	----

Ordering and shipping details

Category	00909 - MOUNTING BASES, S/N
Discount Schedule	DE3A
GTIN	00785901397083
Package weight(Lbs)	3.95 Lb(US) (1.79 kg)
Returnability	No
Country of origin	US

Offer Sustainability

REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------

Product Life Status : **End of commercialisation**

QON130L200I may be replaced by any of the following products:



QON130L200PI

Mounting base, QO load center, OEM, 200A, 120/240 V, 1 phase, 30 spaces

Qty 1

Reason for Substitution: End of life | Substitution date: 02 Apr 2020 |



QON130L200PI

Mounting base, QO load center, OEM, 200A, 120/240 V, 1 phase, 30 spaces

Qty 1

Reason for Substitution: End of life | Substitution date: 02 Apr 2020 |