
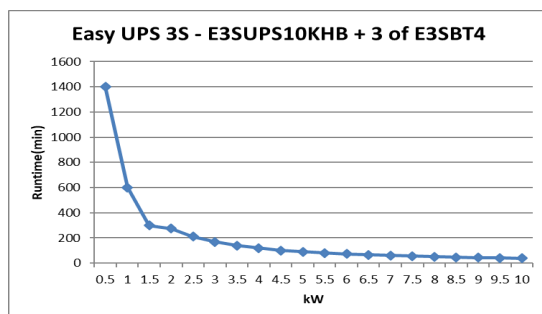
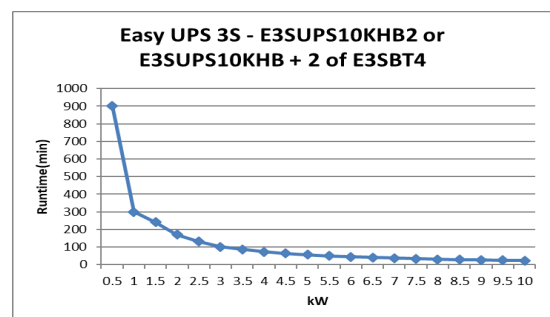


# Easy UPS 3S - 10kVA – Runtime Table

UPS with battery of E3SBT4




Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS10KHB1/ E3SUPS10K3IB1 or E3SUPS10KHB/ E3SUPS10K3IB + 1 of E3SBT4	E3SUPS10KHB2/ E3SUPS10K3IB2 or E3SUPS10KHB/ E3SUPS10K3IB + 2 of E3SBT4	E3SUPS10KHB2/ E3SUPS10K3IB2 + 1 of E3SBT4 or E3SUPS10KHB/ E3SUPS10K3IB + 3 of E3SBT4
5%	0.5	0.5	300	900	1400
10%	1	1	170	300	600
15%	1.5	1.5	100	240	300
20%	2	2	73	170	275
25%	2.5	2.5	55	130	210
30%	3	3	44	100	170
35%	3.5	3.5	36	86.5	140
40%	4	4	30.5	73	120
45%	4.5	4.5	26	63	100
50%	5	5	22.5	55.5	91.5
55%	5.5	5.5	20	49	81.5
60%	6	6	17.5	44	73
65%	6.5	6.5	15.5	39.5	66
70%	7	7	14	36	60
75%	7.5	7.5	13	33	55
80%	8	8	11.5	30	51
85%	8.5	8.5	10.5	28	47
90%	9	9	9.9	26	44
95%	9.5	9.5	9.1	24	40.5
100%	10	10	8.4	22.5	38.5

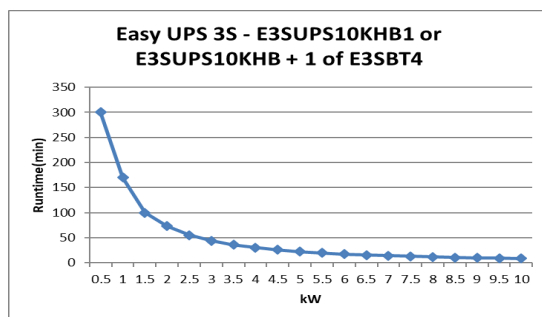

# Easy UPS 3S - 15kVA – Runtime Table

## UPS with battery of E3SBT4



Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS15KHB1/ E3SUPS15K3IB1 or E3SUPS15KHB/ E3SUPS15K3IB + 1 of E3SBT4	E3SUPS15KHB2/ E3SUPS15K3IB2 or E3SUPS15KHB/ E3SUPS15K3IB + 2 of E3SBT4	E3SUPS15KHB2/ E3SUPS15K3IB2 + 1 of E3SBT4 or E3SUPS15KHB/ E3SUPS15K3IB + 3 of E3SBT4
5%	0.75	0.75	240	500	900
10%	1.5	1.5	100	240	300
15%	2.25	2.25	63	145	240
20%	3	3	44	100	170
25%	3.75	3.75	33	79	130
30%	4.5	4.5	26	63	100
35%	5.25	5.25	21	52	86
40%	6	6	17.5	44	73
45%	6.75	6.75	15	38	63
50%	7.5	7.5	13	33	55
55%	8.25	8.25	11	29	49
60%	9	9	9.9	26	44
65%	9.75	9.75	8.8	23.5	39.5
70%	10.5	10.5	7.8	21	36
75%	11.3	11.3	7	19	33
80%	12	12	6.3	17.5	30.5
85%	12.8	12.8	5.6	16	28
90%	13.5	13.5	5.1	15	26
95%	14.3	14.3		13.5	24
100%	15	15		12.5	22.5

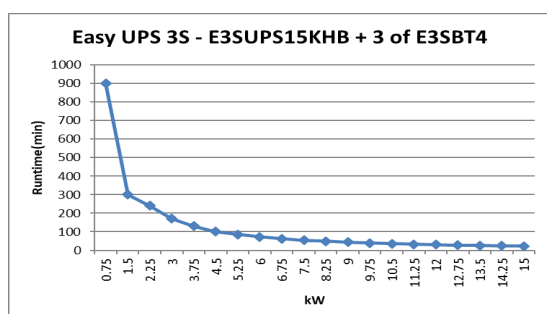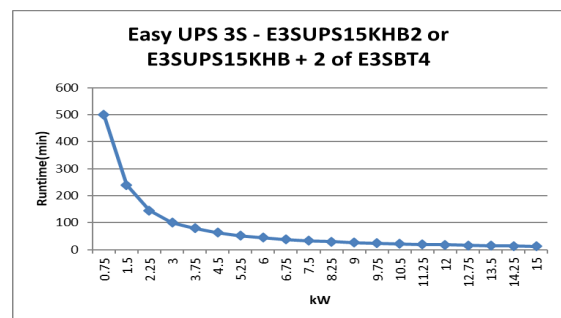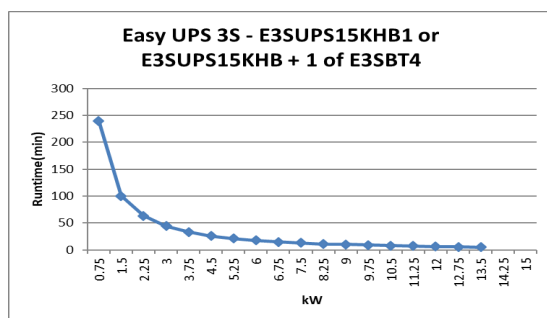

# Easy UPS 3S - 20kVA – Runtime Table

UPS with battery of E3SBT4




Runtime estimation in minutes				
% of load	kVA	kW	E3SUPS20KHB1/ E3SUPS20K3IB1 or E3SUPS20KHB/ E3SUPS20K3IB + 2 of E3SBT4	E3SUPS20KHB2/ E3SUPS20K3IB2 or E3SUPS20KHB/ E3SUPS20K3IB + 3 of E3SBT4
5%	1	1	300	600
10%	2	2	170	275
15%	3	3	100	170
20%	4	4	73	120
25%	5	5	55.5	91.5
30%	6	6	44	73
35%	7	7	36	60
40%	8	8	30	51
45%	9	9	26	44
50%	10	10	22.5	38.5
55%	11	11	20	34
60%	12	12	17.5	30.5
65%	13	13	15.5	27
70%	14	14	14	24.5
75%	15	15	12.5	22.5
80%	16	16	11.5	20.5
85%	17	17	10.5	19
90%	18	18	9.9	17.5
95%	19	19	9.1	16.5
100%	20	20	8.4	15

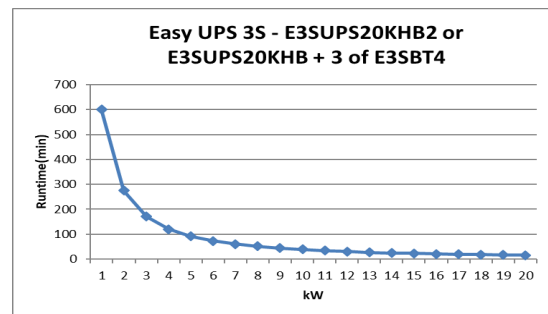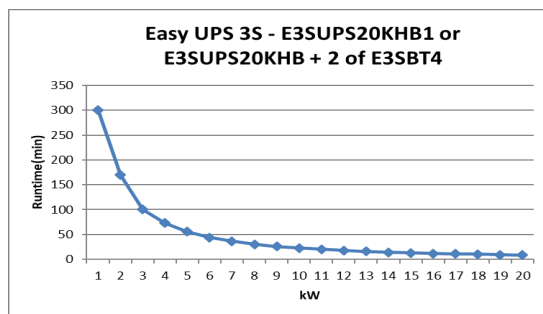

# Easy UPS 3S - 30kVA – Runtime Table

UPS with battery of E3SBT4

Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS30KHB1/ E3SUPS30K3IB1 or E3SUPS30KHB/ E3SUPS30K3IB + 2 of E3SBT4	E3SUPS30KHB1/ E3SUPS30K3IB1 + 1 of E3SBT4 or E3SUPS30KHB/ E3SUPS30K3IB + 3 of E3SBT4	E3SUPS30KHB2/ E3SUPS30K3IB2 or E3SUPS30KHB/ E3SUPS30K3IB + 4 of E3SBT4
5%	1.5	1.5	240	300	500
10%	3	3	100	170	240
15%	4.5	4.5	63	100	145
20%	6	6	44	73	100
25%	7.5	7.5	33	55	79
30%	9	9	26	44	63
35%	10.5	10.5	21	36	52
40%	12	12	17.5	30.5	44
45%	13.5	13.5	15	26	37.5
50%	15	15	12.5	22.5	33
55%	16.5	16.5	11	19.5	29
60%	18	18	9.9	17.5	26
65%	19.5	19.5	8.8	15.5	23.5
70%	21	21	7.8	14	21
75%	22.5	22.5	7	13	19
80%	24	24	6.3	11.5	17.5
85%	25.5	25.5	5.6	10.5	16
90%	27	27	5.1	9.9	15
95%	28.5	28.5		9.1	13.5
100%	30	30		8.4	13

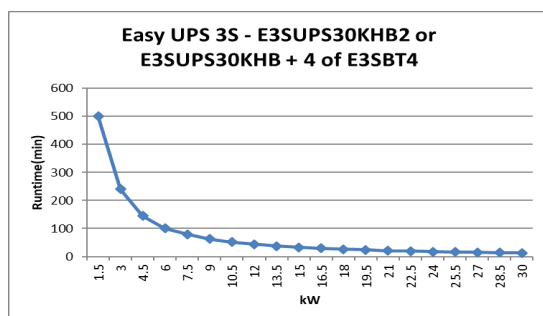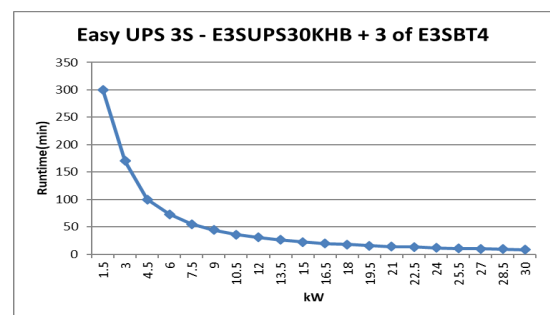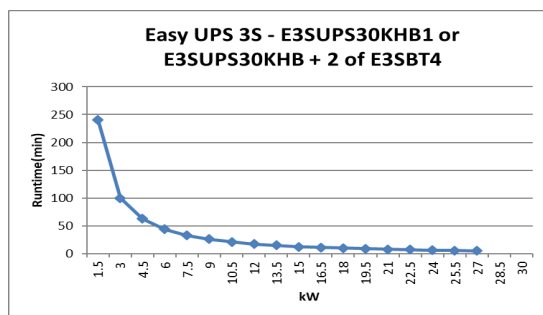

# Easy UPS 3S - 40kVA – Runtime Table

UPS with battery of E3SBT4

Runtime estimation in minutes				
% of load	kVA	kW	E3SUPS40KHB1 or E3SUPS40KHB + 3 of E3SBT4	E3SUPS40KHB2 or E3SUPS40KHB + 4 of E3SBT4
5%	2	2	275	300
10%	4	4	120	170
15%	6	6	73	100
20%	8	8	51	73
25%	10	10	38.5	55
30%	12	12	30.5	44
35%	14	14	24.5	36
40%	16	16	20.5	30.5
45%	18	18	17.5	26
50%	20	20	15	22.5
55%	22	22	13	20
60%	24	24	11.5	17.5
65%	26	26	10.5	15.5
70%	28	28	9.4	14
75%	30	30	8.4	13
80%	32	32	7.6	11.5
85%	34	34	6.9	10.5
90%	36	36	6.3	9.9
95%	38	38	5.7	9.1
100%	40	40	5.2	8.4

