
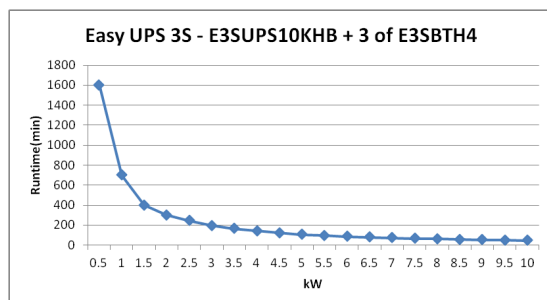
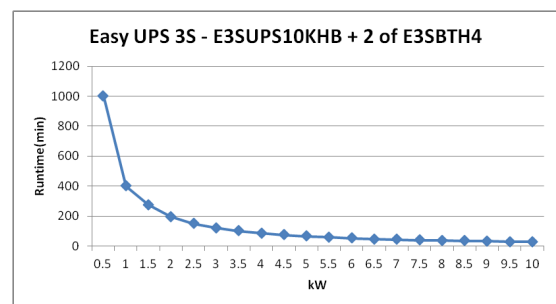


Easy UPS 3S - 10kVA – Runtime Table

UPS with battery of E3SBTH4




Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS10KHB/ E3SUPS10K3IB +		
			1 of E3SBTH4	2 of E3SBTH4	3 of E3SBTH4
5%	0.5	0.5	400	1000	1600
10%	1	1	195	400	700
15%	1.5	1.5	120	275	400
20%	2	2	85.5	195	300
25%	2.5	2.5	65	150	245
30%	3	3	52.5	120	195
35%	3.5	3.5	43	100	165
40%	4	4	36.5	86	140
45%	4.5	4.5	31.5	74.5	120
50%	5	5	27.5	65.5	105
55%	5.5	5.5	24	58	95.5
60%	6	6	21.5	52	86
65%	6.5	6.5	19.5	47	78
70%	7	7	17.5	43	71
75%	7.5	7.5	16	39.5	65.5
80%	8	8	14.5	36.5	60.5
85%	8.5	8.5	13.5	34	56
90%	9	9	12.5	31.5	52
95%	9.5	9.5	11.5	29	48.5
100%	10	10	10.5	27.5	45.5

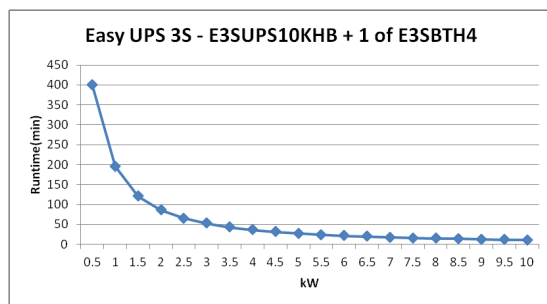

Easy UPS 3S - 15kVA – Runtime Table

UPS with battery of E3SBTH4




Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS15KHB/ E3SUPS15K3IB +		
			1 of E3SBTH4	2 of E3SBTH4	3 of E3SBTH4
5%	0.75	0.75	280	600	1000
10%	1.5	1.5	120	275	400
15%	2.25	2.25	74.5	170	280
20%	3	3	52.5	120	195
25%	3.75	3.75	39.5	93	150
30%	4.5	4.5	31.5	74.5	120
35%	5.25	5.25	25.5	61.5	100
40%	6	6	21.5	52	86
45%	6.75	6.75	18.5	45	74.5
50%	7.5	7.5	16	39.5	65.5
55%	8.25	8.25	14	35	58
60%	9	9	12.5	31.5	52
65%	9.75	9.75	11	28.5	47.5
70%	10.5	10.5	10	26	43
75%	11.3	11.3	9.2	23.5	39.5
80%	12	12	8.4	21.5	36.5
85%	12.8	12.8	7.7	20	33.5
90%	13.5	13.5	7	18.5	31.5
95%	14.3	14.3	6.4	17	29
100%	15	15	5.9	16	27.5

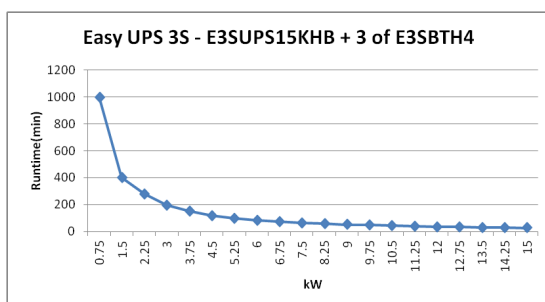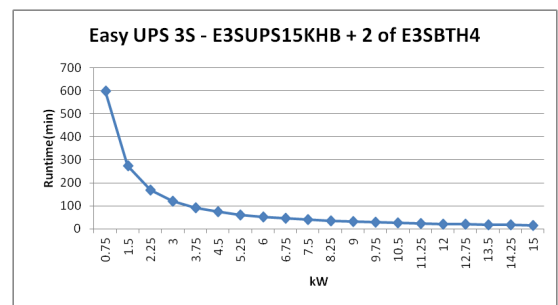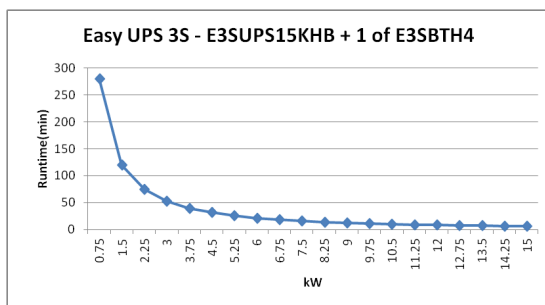

Easy UPS 3S - 20kVA – Runtime Table

UPS with battery of E3SBTH4





Runtime estimation in minutes					
% of load	kVA	kW	E3SUPS20KHB/ E3SUPS20K3IB +		
			1 of E3SBTH4	2 of E3SBTH4	3 of E3SBTH4
5%	1	1	195	400	700
10%	2	2	85.5	195	300
15%	3	3	52.5	120	195
20%	4	4	36.5	86	140
25%	5	5	27.5	65.5	105
30%	6	6	21.5	52	86
35%	7	7	17.5	43	71
40%	8	8	14.5	36.5	60.5
45%	9	9	12.5	31.5	52
50%	10	10	10.5	27.5	45.5
55%	11	11	9.6	24.5	41
60%	12	12	8.4	21.5	36.5
65%	13	13	7.4	19.5	33
70%	14	14	6.7	17.5	30
75%	15	15	5.9	16	27.5
80%	16	16	5.4	14.5	25.5
85%	17	17		13.5	23.5
90%	18	18		12.5	21.5
95%	19	19		11.5	20
100%	20	20		10.5	19

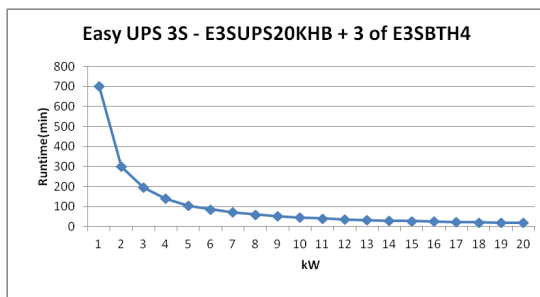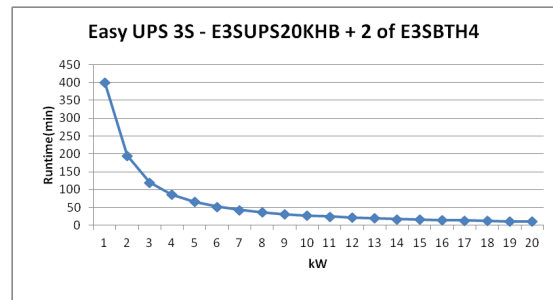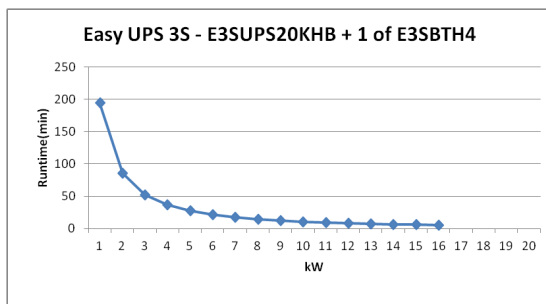

Easy UPS 3S - 30kVA – Runtime Table

UPS with battery of E3SBTH4

Runtime estimation in minutes						
% of load	kVA	kW	E3SUPS30KHB/ E3SUPS30K3IB +			
			1 of E3SBTH4	2 of E3SBTH4	3 of E3SBTH4	4 of E3SBTH4
5%	1.5	1.5	120	275	400	600
10%	3	3	52.5	120	195	280
15%	4.5	4.5	31.5	74.5	120	170
20%	6	6	21.5	52	86	120
25%	7.5	7.5	16	39.5	65.5	93
30%	9	9	12.5	31.5	52	74.5
35%	10.5	10.5	10	26	43	61.5
40%	12	12	8.4	21.5	36.5	52
45%	13.5	13.5	7	18.5	31.5	45
50%	15	15	5.9	16	27.5	39.5
55%	16.5	16.5	5.1	14	24	35
60%	18	18		12.5	21.5	31.5
65%	19.5	19.5		11	19.5	28.5
70%	21	21		10	17.5	26
75%	22.5	22.5		9.2	16	23.5
80%	24	24		8.4	14.5	21.5
85%	25.5	25.5		7.7	13.5	20
90%	27	27		7	12.5	18.5
95%	28.5	28.5		6.4	11.5	17
100%	30	30		6	11	16

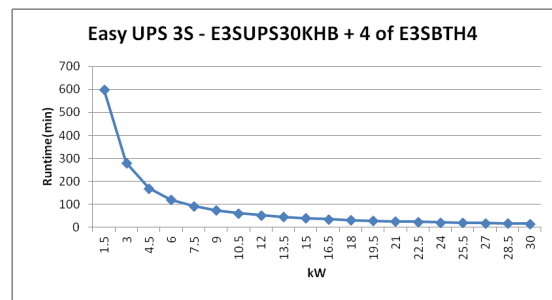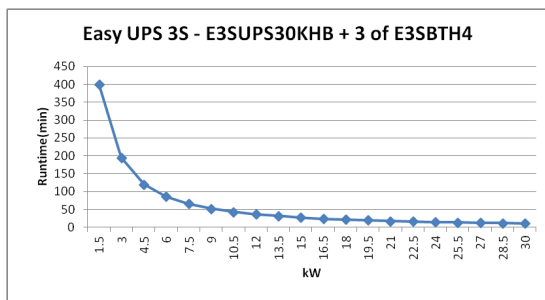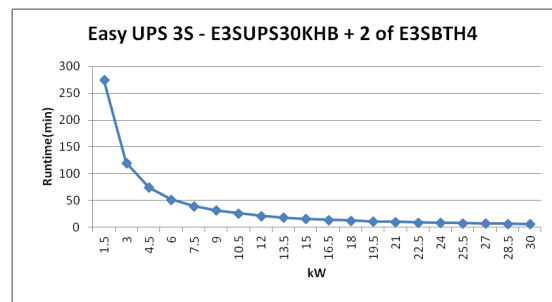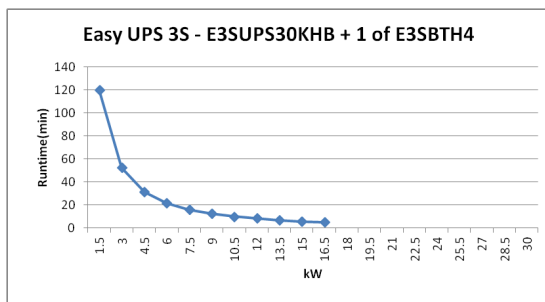

Easy UPS 3S - 40kVA – Runtime Table

UPS with battery of E3SBTH4

Runtime estimation in minutes						
% of load	kVA	kW	E3SUPS40KHB +			
			1 of E3SBTH4	2 of E3SBTH4	3 of E3SBTH4	4 of E3SBTH4
5%	2	2	85.5	195	300	400
10%	4	4	36.5	86	140	195
15%	6	6	21.5	52	86	120
20%	8	8	14.5	36.5	60.5	86
25%	10	10	10.5	27.5	45.5	65
30%	12	12	8.4	21.5	36.5	52
35%	14	14	6.7	17.5	30	43
40%	16	16	5.4	14.5	25.5	36.5
45%	18	18		12.5	21.5	31.5
50%	20	20		10.5	19	27.5
55%	22	22		9.5	16.5	24
60%	24	24		8.4	14.5	21.5
65%	26	26		7.5	13	19.5
70%	28	28		6.7	12	17.5
75%	30	30		6	11	16
80%	32	32		5.3	10	14.5
85%	34	34			9.1	13.5
90%	36	36			8.4	12.5
95%	38	38			7.8	11.5
100%	40	40			7.2	11

