

PacT Series

# ComPacT NS

Substitution and Technical Guide

**Catalog 2022**

Molded Case Circuit Breakers  
and Switch-Disconnectors  
from 630b to 3200 A



[se.com](http://se.com)

Life Is On

**Schneider**  
Electric



# Green Premium™



More than 75% of our product sales offer superior transparency on the material content, regulatory information and environmental impact of our products:

- RoHS compliance
- REACH substance information
- Industry leading # of PEP's\*
- Circularity instructions



Discover what we mean by green  
**Check your products!**

The Green Premium program stands for our commitment to deliver customer valued sustainable performance. It has been upgraded with recognized environmental claims and extended to cover all offers including Products, Services and Solutions.

#### CO<sub>2</sub> and P&L impact through... Resource Performance

Green Premium brings improved resource efficiency throughout an asset's lifecycle. This includes efficient use of energy and natural resources, along with the minimization of CO<sub>2</sub> emissions.

#### Cost of ownership optimization through... Circular Performance

We're helping our customers optimize the total cost of ownership of their assets. To do this, we provide IoT-enabled solutions, as well as upgrade, repair, retrofit, and remanufacture services.

#### Peace of mind through... Well-being Performance

Green Premium products are RoHS and REACH compliant. We're going beyond regulatory compliance with step-by-step substitution of certain materials and substances from our products.

#### Improved sales through... Differentiation

Green Premium delivers strong value propositions through third-party labels and services. By collaborating with third-party organizations we can support our customers in meeting their sustainability goals such as green building certifications.

\*PEP: Product Environmental Profile (i.e. Environmental Product Declaration)



Life Is On



# Meet the New Face of Connected Breaker Technology

## 70 Years of Innovative and Reliable Protection

The Schneider Electric™ ComPact™ range is built on 70 years of expertise and leadership in industrial circuit breakers.

Today Schneider Electric is launching its new generation of ComPact molded case circuit breakers.

The comprehensive, optimized ComPact range covers your protection and has been redesigned with a superior customer experience in mind.

The range combines wireless intelligent metering and monitoring, along with advanced protective functions.

This range can be connected to Schneider Electric's open, interoperable, IoT-enabled EcoStruxure™ Power architecture. Through this platform we deliver enhanced value in terms of safety, reliability, efficiency, sustainability, and connectivity.

We leverage technologies in IoT, mobility, sensing, cloud, analytics, and cybersecurity to deliver Innovation at Every Level. This includes connected products, edge control, apps, analytics and services.



1952

Compact NW



ComPact C

1974

ComPact C



1994

ComPact NS



2008

Compact NSX



2017

Compact NSXm



2018

ComPact NSX & NSXm with MicroLogic Vigi




2021

ComPact NSX & NSXm New Generation



Discover the New Generation of ComPact

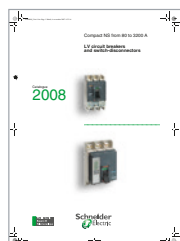

2008

Compact NS



2020

ComPact NS



2022


ComPact NS New Generation

[se.com/compact-ns](https://se.com/compact-ns)


# Protection of Distribution Systems Overview of Solutions

Protection of distribution systems means protection of:


- Systems supplied by a transformer
- Systems supplied by an engine generator set
- Long cables in IT and TN systems.

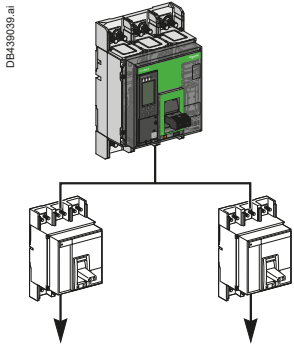


DB439040

 

DB439046

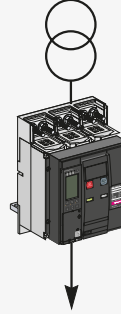

DB439042

 

## Power Distribution

Selection of Circuit Breakers from 630 to 3200 A

Rated current (A)	630	800	1000	1250	1600
ComPacT	NS630b	NS800	NS1000	NS1250	NS1600

CO80N35EFM



PB10483\_ME\_1



Breaking capacity (kA rms) 380/415 V	N	50	50	50	50
	H	70	70	70	70
	L	150	150	150	-
	LB [1]	200	200	-	-

Rated current (A)	1600	2000	2500	3200
ComPacT	NS1600b	NS2000	NS2500	NS3200

C250N3FM



Breaking capacity (kA rms) 380/415 V	N	70	70	70
	H	85	85	85

## Associated Control Units up to 3200 A

MicroLogic electronic control units may be used on all ComPacT NS630b to NS3200 circuit breakers and can be changed by Schneider Electric qualified personnel.

[1] Only for manually operated version.





## The ComPacT NS Range Covers all Ratings from 630 to 3200 A

### ComPacT NS630b to 1600

- ComPacT NS from 630 to 1600 A, fixed or withdrawable, front or rear connection, manual operating mechanism or motor mechanism. A 200 kA breaking performance completes the ComPacT NS range

### ComPacT NS1600b to 3200


- ComPacT NS from 1600 to 3200 A, fixed, front connection, with manual operating mechanism

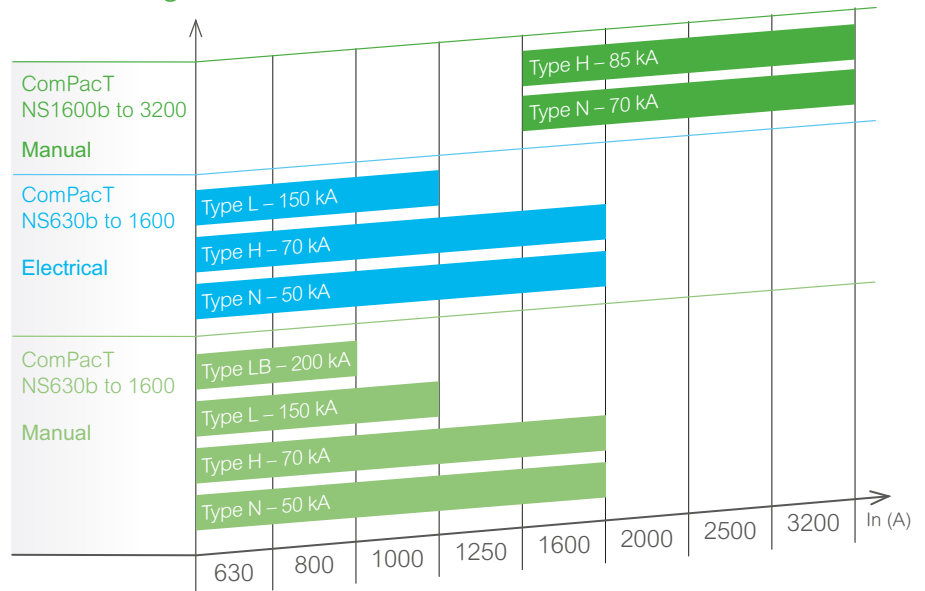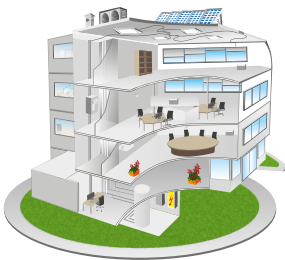


The MasterPact and ComPacT range circuit breakers, switch-disconnectors and source changeover are the best choice for all standards and specific applications.

## Optimize Your Solution


- Minimum distances** (safety clearance) between 2 circuit breakers are reduced thanks to the arc chute filters.
- A solution for all your applications:**
  - Generator protection
  - Motor protection up to 750 kW with coordination between breakers and contactors (coordination type 1 and type 2)
  - Source-changeover.
- Best combination** of size (small depth), performance with no derating up to 65 °C (vertical connection) and flexible mounting options.
- Ensure continuity of service:**
  - Total control of selectivity for the whole Schneider Electric circuit breakers range from molded circuit breaker to air circuit breaker
  - High withstand of the devices to various environmental stresses.
- Bring flexibility to your installation:** Interchangeable trip units, standardized accessories, adjustable rating and scalable indication and control functions.

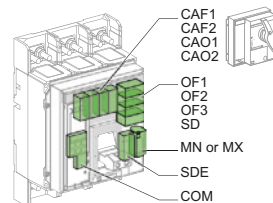

Manually operated device

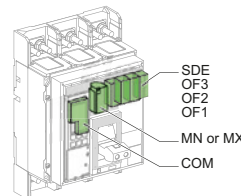


Electrically operated device

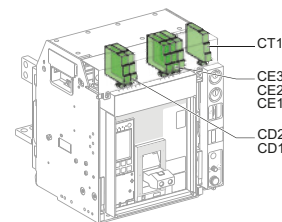

Withdrawable device

## Installation

### Fixed Device

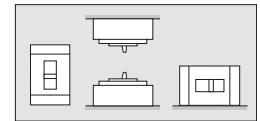

### Withdrawable Device



### > MasterPact MTZ



LVPED216026EN

### > ComPacT NSX/NSXm ComPacT INS/INV



LVPED217032EN

### > Source-changeover Systems



LVPED216028EN

### > Complementary Technical Information



LVPED318033EN

Schneider Electric is proud to introduce the new generation of ComPacT MCCBs. These breakers talk to you, wherever you are, in all transparency. New design complements new wireless connectivity capabilities with our latest wireless indication auxiliary.

New

## ComPacT Design



### New signature design

- Schneider Electric green signature style for the entire ComPacT range
- Estimated 40% reduction of wiring time for panel builders
- Experience easier installation thanks to a new ergonomic front-plate design
- Gain the confidence that all auxiliaries are on the right spot, and simply double check that you have the right coil rating
- Ergonomic new toggle for easier breaker manual operation

New

## Wireless Indication Auxiliary



### Wireless breaker status

- Plug & play technology for clear connection status (0 or 1, no half-way wired)
- Placed in the same position as the wired version, its LED light will give you direct indication in case of a tripping
- If you are away, your ComPacT will send you an immediate notification via EcoStruxure Facility Expert for instance
- Wireless auxiliary accelerates overall wiring time: status communication is done very simply and commissioned wirelessly
- Communication architecture is fully EcoStruxure Power validated, with any application

### Ready to meet the new face of ComPacT?




In 2022 you will meet the new generation of ComPacT™ circuit breakers with semi-transparent faceplate, screwless auxiliaries and remote monitoring features.

Learn about the benefits of the ComPacT range here:  
[se.com/compact-ns](http://se.com/compact-ns)



# New Generation of ComPacT NS

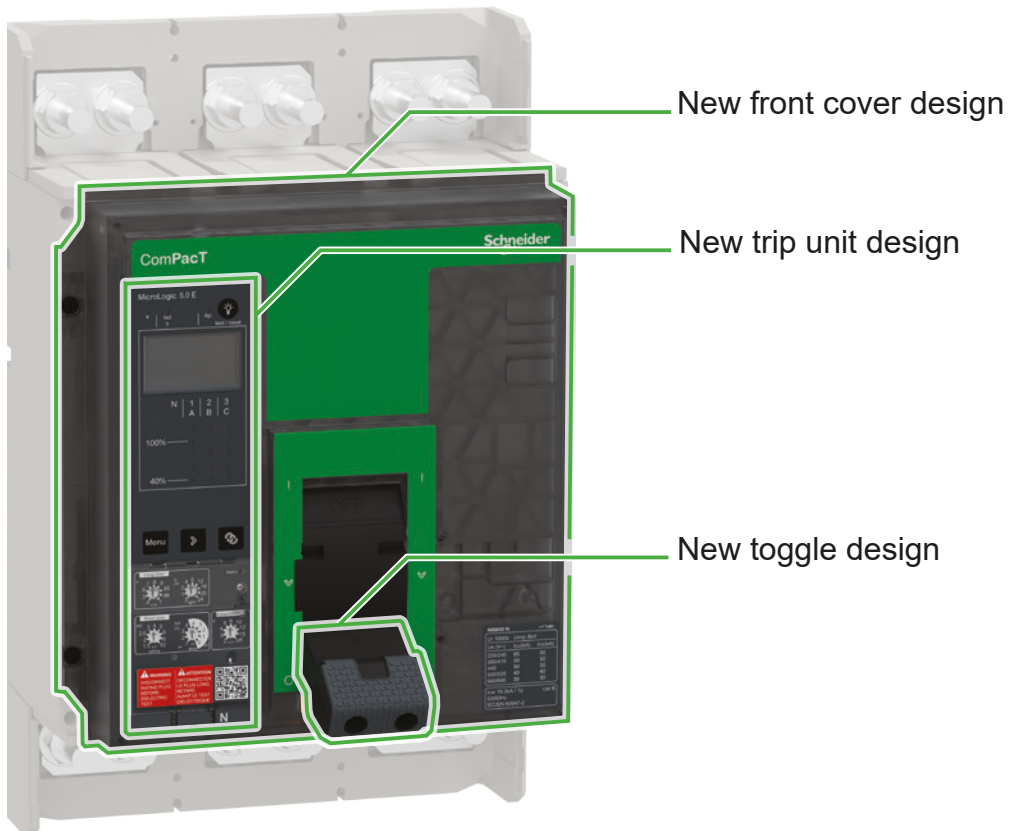

C12N3P20FM ————— New commercial reference

## Customer Benefit

- Seamless offer selection thanks to the new meaningful commercial references
- Easy access to the circuit breaker configuration
- Sustainability enhancement

# Contribute to a Better World. Enhance Sustainability with ComPacT Range

## Achieve Green Building Certification with Green Premium Ecolabel

In compliance with ISO 14025 PEP ecopassport program, we publish a comprehensive Life Cycle Analysis of our product, providing the environmental data you need to achieve Green Building certifications.

For example, ComPacT NS contribute to 3 LEED™ points in the Building Product Disclosure and Optimization section:

- Environmental Product Declaration
- Material Ingredients



ComPacT range is now enriched with the new ComPacT NS, designed according to the EcoDesign Way™ by Schneider. It now features new space saving frame size for reduced resource consumption, and more.





## Simpler Names for our Offers

We are making it easier for you to navigate across the wide range of our world-class digital offerings and select with confidence the offers that are right for you and your needs.

### EcoStruxure Architecture

To enable brand consistency, relevance and impact, we are reinforcing our EcoStruxure™ architecture and digital customer lifecycle tools to ensure a seamless experience from the CAPEX to OPEX phases of each project, bridging our entire ecosystem of partners, services providers and end users.

EcoStruxure is our IoT-enabled open and interoperable system architecture and platform. EcoStruxure delivers enhanced values around safety, reliability, efficiency, sustainability and connectivity for our customers. EcoStruxure leverages advancements in IoT, mobility, sensing, cloud, analytics, and cybersecurity technologies to deliver Innovation At Every Level from Connected Products; Edge Control; and Apps, Analytics & Services: our IoT technology Levels.

Old names	New names
Ecodial	EcoStruxure Power Design
Ecoreal	EcoStruxure Power Build
Ecoreach	EcoStruxure Power Commission
Masterpact MTZ mobile App	EcoStruxure Power Device App

### PacT Series

Future-proof your installation with Schneider Electric's low and medium voltage **PacT** Series. Built on legendary Schneider Electric innovation, the **PacT** Series comprises world-class circuit breakers, switches, residual current devices and fuses, for all standard and specific applications. Experience robust performance with this comprehensive range of EcoStruxure- ready switchgear, for all applications from 16 to 6300 A.

Old names	New names
Compact	Com <b>PacT</b>
Masterpact	Master <b>PacT</b>
Micrologic	MicroLogic
Transferpact	Transfer <b>PacT</b>
Fupact	Fu <b>PacT</b>
Vigirex	Vigi <b>PacT</b>

This guide is intended to:

- > Provide the information you need to replace a device from the Com**Pact** NS630 A to 3200 A range by a device from the new generation of Com**Pact** NS630 A to 3200 A range.
- > Help you understand the meaningful commercial reference coding rules.

For more information, see:

- > Com**Pact** NS Catalog 2022 LVPED221008EN
- > Com**Pact** NS Instruction Sheets and User Guides



# What is Changing...



Manual Operated Circuit Breaker  
ComPact NS 630b to 1600 A



Manual Operated Circuit Breaker  
ComPacT NS 630b to 1600 A



Manual Operated Switch Disconnecter  
ComPact NS 630b to 1600 A



Manual Operated Switch Disconnecter  
ComPacT NS 630b to 1600 A



Manual Operated Circuit Breaker  
ComPact NS 1600b to 3200 A



Manual Operated Circuit Breaker  
ComPacT NS 1600b to 3200 A



Manual Operated Switch Disconnecter  
ComPact NS 1600b to 3200 A



Manual Operated Switch Disconnecter  
ComPacT NS 1600b to 3200 A

# What Does Not Change for the Moment...



ComPact NS with a direct rotary handle.



ComPact NS with a direct rotary handle.



ComPact NS with an extended rotary handle.



ComPact NS with an extended rotary handle.



Electrical Operated Circuit Breaker  
ComPact NS 630b to 1600 A



Electrical Operated Circuit Breaker  
ComPact NS 630b to 1600 A

# General contents

<b>Protection of Distribution Systems</b>	
ComPacT NS Circuit Breakers from 630b up to 3200 A.....	2
<b>MicroLogic Control Units</b>	
Overview of Functions.....	6
<b>Electrical and Mechanical Accessories.....</b>	<b>8</b>
ComPacT NS630b to 1600 (Fixed Version).....	8
ComPacT NS1600b to 3200 (Fixed Version).....	9
<b>New Generation, Simpler Commercial References.....</b>	<b>11</b>
<b>ComPacT NS630b to NS1600</b>	
<b>Fixed Manually Operated</b>	
Complete Device .....	12
Device Based on Separate Components.....	17
<b>ComPacT NS1600b to NS3200</b>	
<b>Fixed Manually Operated</b>	
Device Based on Separate Components.....	19
<b>ComPacT NS630b to NS1600</b>	
<b>Withdrawable Manually Operated</b>	
Device Based on Separate Components.....	20
<b>ComPacT NS630b to NS1600</b>	
<b>Fixed Electrically Operated</b>	
Device Based on Separate Components.....	22
<b>ComPacT NS630b to NS1600</b>	
<b>Withdrawable Electrically Operated</b>	
Device Based on Separate Components.....	25
<b>ComPacT NS630b to NS3200</b>	
<b>Accessories &amp; Spare Parts.....</b>	<b>28</b>

# Protection of Distribution Systems

## ComPacT NS Circuit Breakers from 630b up to 3200 A

C090NS8EFM.pdf



ComPacT NS800N manually operated

PB104831\_ME.eps



ComPacT NS1600H electrically operated

C250NSFM.pdf



ComPacT NS1600b N manually operated

[1] 65 °C with vertical connections. See the temperature derating tables for other types of connections.

### ComPacT Circuit Breakers

Number of poles		
Control	manual	toggle
	direct or extended rotary handle	
	electric	

### Type of Circuit Breaker

Connections	fixed	front connection
		rear connection
		front connection with bare cables
	withdrawable (on chassis)	front connection
		rear connection

### Electrical characteristics as per IEC/EN 60947-2

Rated current (A)	<b>In</b>	50 °C
		65 °C [1]
Rated insulation voltage (V)	<b>Ui</b>	
Rated impulse withstand voltage (kV)	<b>Uimp</b>	
Rated operational voltage (V)	<b>Ue</b>	AC 50/60 Hz

### Type of Circuit Breaker

Ultimate breaking capacity (kA rms)	Manual	<b>Icu</b>	AC 50/60 Hz	220/240 V
				380/415 V
				440 V
				500/525 V
				660/690 V
		<b>Ics</b>	AC 50/60 Hz	220/240 V
				380/415 V
				440 V
				500/525 V
				660/690 V
	Electrical	<b>Icu</b>	AC 50/60 Hz	220/240 V
				380/415 V
				440 V
				500/525 V
				660/690 V
		<b>Ics</b>	AC 50/60 Hz	220/240 V
				380/415 V
				440 V
				500/525 V
				660/690 V

Short-time withstand current (kA rms)	<b>Icw</b>	AC 50/60 Hz	1 s
			3 s

Integrated instantaneous protection kA peak ± 10 %

Suitability for isolation

Utilization category

Durability (C-O cycles)	mechanical	440 V	In/2
			In
			690 V
	electrical	690 V	In/2
			In

Pollution degree



# Protection of Distribution Systems

## ComPacT NS Circuit Breakers from 630b up to 3200 A

NS630b			NS800		NS1000			NS1250		NS1600		NS1600b		NS2000		NS2500		NS3200				
3, 4					3, 4			3, 4		3, 4		3, 4		3, 4		3, 4		3, 4				
●					●			●		●		●		●		●		●				
●					●			●		●		-		-		-		-				
● (except LB)					●			●		●		-		-		-		-				
N	H	L	LB	N	H	L	N	H	N	H	N	H	N	H	N	H	N	H				
●	●	●	-	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
●	●	●	●	●	●	●	●	●	●	●	-	-	-	-	-	-	-	-				
●	●	-	-	●	●	-	●	●	-	-	-	-	-	-	-	-	-	-				
●	●	●	●	●	●	●	●	●	●	●	-	-	-	-	-	-	-	-				
●	●	●	●	●	●	●	●	●	●	●	-	-	-	-	-	-	-	-				
630	800			1000			1250			1600			1600			2000			2500			3200
630	800			1000			1250			1510			1550			1900			2500			2970
1000				1000			1000			1000			800			800			800			800
8				8			8			8			8			8			8			8
690				690			690			690			690			690			690			690
N	H	L	LB	N	H	L	N	H	N	H	N	H	N	H	N	H	N	H				
85	85	150	200	85	85	150	85	85	85	85	85	125	85	125	85	125	85	125				
50	70	150	200	50	70	150	50	70	50	70	70	85	70	85	70	85	70	85				
50	65	130	200	50	65	130	50	65	50	65	65	85	65	85	65	85	65	85				
40	50	100	100	40	50	100	40	50	40	50	65	-	65	-	65	-	65	-				
30	42	-	75	30	42	-	30	42	30	42	65	-	65	-	65	-	65	-				
50	50	150	200	50	50	150	50	50	37	37	64	94	64	94	64	94	64	94				
50	50	150	200	50	50	150	50	50	37	37	52	64	52	64	52	64	52	64				
50	50	130	200	50	50	130	50	50	37	37	65	64	65	64	65	64	65	64				
40	40	100	100	40	40	100	40	40	30	30	65	-	65	-	65	-	65	-				
30	30	-	75	30	30	-	30	30	22	22	65	-	65	-	65	-	65	-				
50	70	150	-	50	70	150	50	70	50	70	-	-	-	-	-	-	-	-				
50	70	150	-	50	70	150	50	70	50	70	-	-	-	-	-	-	-	-				
50	65	130	-	50	65	130	50	65	50	65	-	-	-	-	-	-	-	-				
40	50	100	-	40	50	100	40	50	40	50	-	-	-	-	-	-	-	-				
30	42	-	-	30	42	-	30	42	30	42	-	-	-	-	-	-	-	-				
37	37	150	-	37	37	150	37	37	37	37	-	-	-	-	-	-	-	-				
37	37	150	-	37	37	150	37	37	37	37	-	-	-	-	-	-	-	-				
37	37	130	-	37	37	130	37	37	37	37	-	-	-	-	-	-	-	-				
30	30	100	-	30	30	100	30	30	30	30	-	-	-	-	-	-	-	-				
22	22	-	-	22	22	-	22	22	22	22	-	-	-	-	-	-	-	-				
19.2	19.2	-	-	19.2	19.2	-	19.2	19.2	19.2	19.2	-	-	-	-	-	-	-	-				
-	-	-	-	-	-	-	-	-	-	-	32	32	32	32	32	32	32	32				
40	40	-	-	40	40	-	40	40	40	40	130	130	130	130	130	130	130	130				
●		●		●			●		●		●		●		●		●					
B	B	A	A	B	B	A	B	B	B	B	B	B	B	B	B	B	B	B				
10000				10000			10000			10000			5000			5000			5000			5000
6000	6000	4000	4000	6000	6000	4000	5000	5000	5000	5000	3000	3000	3000	3000	3000	3000	3000	3000				
5000	5000	3000	3000	5000	5000	3000	4000	4000	2000	2000	2000	2000	2000	2000	2000	2000	2000	2000				
4000	4000	3000	3000	4000	4000	3000	3000	3000	2000	2000	2000	2000	2000	2000	2000	2000	2000	2000				
2000	2000	2000	2000	2000	2000	2000	2000	2000	1000	1000	1000	1000	1000	1000	1000	1000	1000	1000				
3				3			3		3		3		3		3		3		3			3

# Protection of Distribution Systems

## ComPacT NS Circuit Breakers from 630b up to 3200 A

C380NSSEFM.psd



ComPacT NS800N manually operated

PB10483\_ME.ppt



ComPacT NS1600H electrically operated

C250NGFM.psd



ComPacT NS1600b N manually operated

### ComPacT Circuit Breakers

#### Protection and Measurements

Interchangeable control units

Overload protection long time **I<sub>r</sub>** (I<sub>n</sub> x ...)

Short-circuit protection short time **I<sub>sd</sub>** (I<sub>r</sub> x ...)  
instantaneous **I<sub>i</sub>** (I<sub>n</sub> x ...)

Earth-fault protection **I<sub>g</sub>** (I<sub>n</sub> x ...)

Residual earth-leakage protection **IΔn**

Zone selective interlocking **ZSI**

Protection of the fourth pole

Current measurements

Power measurements

Advanced protection

Quick view

#### Remote Communication by Bus

Device-status indication

Device remote operation [2]

Transmission of settings

Indication and identification of protection devices and alarms

Transmission of measured current values

### ComPacT Circuit Breakers

#### Additional indication and control auxiliaries

Indication contacts

Voltage releases MX shunt release/MN undervoltage release

#### Installation

Accessories terminal extensions and spreaders  
terminal shields and interphase barriers  
escutcheons

Dimensions fixed devices, front connections (mm) 3P

H x W x D 4P

Weight fixed devices, front connections (kg) 3P

4P

#### Source changeover system (see section on "source changeover systems")

Manual, remote-operated and automatic source changeover systems

[1] Except 1600b-3200.

[2] With NS630b...NS1600, remote operation is possible with electrically operated device. With NS1600...NS3200, remote operation is not possible.

# Protection of Distribution Systems

## ComPacT NS Circuit Breakers from 630b up to 3200 A

NS630b NS800 NS1000 NS1250 NS1600 NS1600b NS2000 NS2500 NS3200													
MicroLogic													
2.0	5.0	6.0	2.0A	5.0A	6.0A	7.0A	2.0E	5.0E	6.0E	5.0P <sup>[1]</sup>	6.0P <sup>[1]</sup>	7.0P <sup>[1]</sup>	
○	○	○	○	○	○	○	○	○	○	○	○	○	
-	○	○	-	○	○	○	-	○	○	○	○	○	
○	○	○	○	○	○	○	○	○	○	○	○	○	
-	-	○	-	-	○	-	-	-	○	-	○	-	
-	-	-	-	-	-	○	-	-	-	-	-	○	
-	-	-	○	○	○	○	○	○	○	○	○	○	
○	○	○	○	○	○	○	○	○	○	○	○	○	
-	-	-	○	○	○	○	○	○	○	○	○	○	
-	-	-	-	-	-	-	○	○	○	○	○	○	
-	-	-	-	-	-	-	-	-	-	○	○	○	
-	-	-	-	-	-	-	○	○	○	-	-	-	
○	○	○	○	○	○	○	○	○	○	○	○	○	
○	○	○	○	○	○	○	○	○	○	○	○	○	
-	-	-	○	○	○	○	○	○	○	○	○	○	
-	-	-	○	○	○	○	○	○	○	○	○	○	
-	-	-	○	○	○	○	○	○	○	○	○	○	
NS630b	NS800	NS1000	NS1250	NS1600	NS1600b	NS2000	NS2500	NS3200					
○						○							
○						○							
○						-							
○						○							
○						○							
327 x 210 x 147						350 x 420 x 160							
327 x 280 x 147						350 x 535 x 160							
14						24							
18						36							
○						-							

# MicroLogic Control Units

## Overview of Functions

All ComPacT circuit breakers are equipped with a MicroLogic control unit that can be changed on site. Control units are designed to protect Power circuits and loads. Alarms may be programmed for remote indications. Measurements of current, voltage, frequency, power and power quality optimize continuity of service and energy management.

### MicroLogic Name Codes

**2.0 E**  
X Y Z

- X: type of protection
- 2 for basic protection
  - 5 for selective protection
  - 6 for selective + earth-fault protection
  - 7 for selective + earth-leakage protection.

Y: control-unit generation  
Identification of the control-unit generation.  
"0" signifies the first generation.

- Z: type of measurement
- No letter: no measurements
  - A for "ammeter"
  - E for "energy"
  - P for "power meter"



### Dependability

Integration of protection functions in an ASIC electronic component used in all MicroLogic control units ensures a high degree of reliability and immunity to conducted or radiated disturbances.

On MicroLogic A, E and P control units, advanced functions are managed by an independent microprocessor.


### Accessories

Certain functions require the addition of MicroLogic control unit accessories, described on page A-30.

The rules governing the various possible combinations can be found in the documentation accessible via the Products and services menu of the www.se.com web site.


### Current Protection

#### MicroLogic 2: basic protection

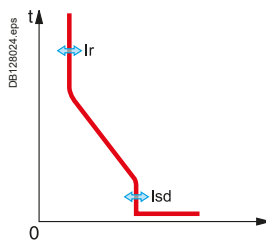



- Protection:
- Long time (L)
  - Instantaneous (I)

#### MicroLogic 5: selective protection

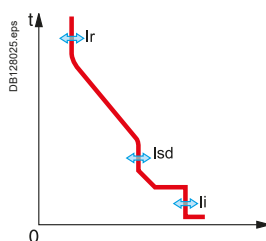



- Protection:
- Long time (L)
  - Short time (S)
  - Instantaneous (I)

#### MicroLogic 6: selective + earth-fault protection

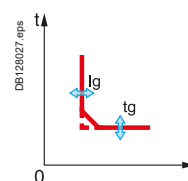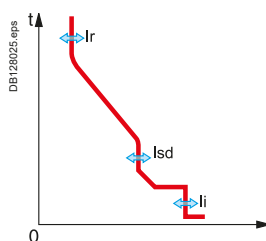

- Protection:
- Long time (L)
  - Short time (S)
  - Instantaneous (I)
  - Earth fault (G)

#### MicroLogic 7: selective + earth-leakage protection

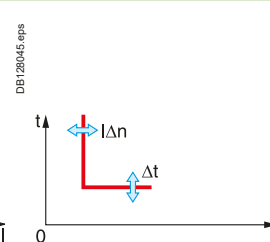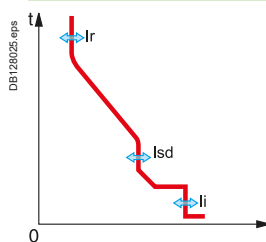

- Protection:
- Long time (L)
  - Short time (S)
  - Instantaneous (I)
  - Earth leakage up to 3200A (R)



#### MicroLogic without Measurement

#### Measurements and Programmable Protection

##### A: Ammeter

- $I_1, I_2, I_3, I_N, I_{\text{earth-fault}}, I_{\text{earth-leakage}}$  and maximeter for these measurements
- Fault indications
- Settings in amperes and in seconds.

##### E: Energy

Incorporates all the rms measurements of MicroLogic A, plus voltage, power factor, power and energy metering measurements.

- Calculates the current demand value
- "Quickview" function for the automatic cyclical display of the most useful values (as standard or by selection).

##### P: A + Power meter + programmable protection


- Measurements of V, A, W, VAR, VA, Wh, VARh, VAh, Hz,  $V_{\text{peak}}, A_{\text{peak}}$ , power factor and maximeters and minimeters
- IDMTL long-time protection, minimum and maximum voltage and frequency, voltage and current imbalance, phase sequence, reverse power
- Load shedding and reconnection depending on power or current
- Measurements of interrupted currents, differentiated fault indications, maintenance indications, event histories and time-stamping, etc.

Without measurement	MicroLogic A	MicroLogic E	MicroLogic P
---------------------	--------------	--------------	--------------



# Electrical and Mechanical Accessories ComPacT NS630b to 1600 (Fixed Version)


DB459119.ai

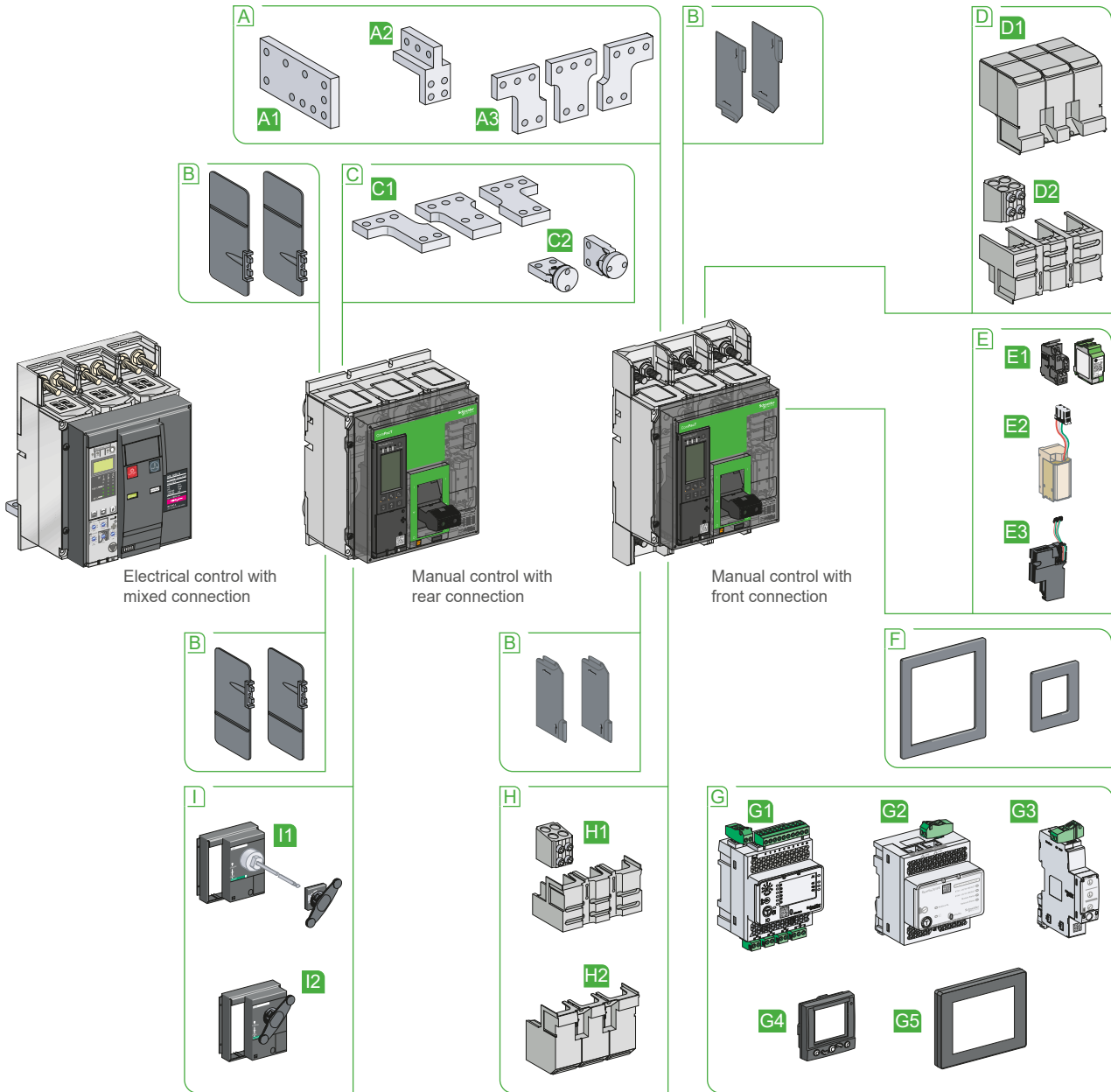

- |  |  |  |
|--|--|--|
| <p><b>A</b> <b>A1</b> Terminal extension for cables with lugs<br/><b>A2</b> Vertical connection adapter<br/><b>A3</b> Spreader</p> <p><b>B</b> Interphase barriers</p> <p><b>C</b> <b>C1</b> Spreader<br/><b>C2</b> Rear connectors</p> <p><b>D</b> <b>D1</b> Sealable terminal shield<br/><b>D2</b> Connection kit for connectors</p> | <p><b>E</b> <b>E1</b> Auxiliary contact<br/><b>E2</b> Voltage release<br/><b>E3</b> BCM ULP Communication module</p> <p><b>F</b> Escutcheon</p> <p><b>G</b> <b>G1</b> I/O (Input/Output) application module for LV circuit breaker<br/><b>G2</b> IFE Ethernet interface for LV circuit breaker<br/><b>G3</b> IFM Ethernet interface for LV circuit breaker<br/><b>G4</b> FDM121: Front Display Module<br/><b>G5</b> FDM128: Front Display Module</p> | <p><b>H</b> <b>H1</b> Connection kit for connectors<br/><b>H2</b> Sealable terminal shield</p> <p><b>I</b> <b>I1</b> Extended rotary handle<br/><b>I2</b> Direct rotary handle</p> |
|--|--|--|

# Electrical and Mechanical Accessories ComPacT NS1600b to 3200 (Fixed Version)

DE439104.ai

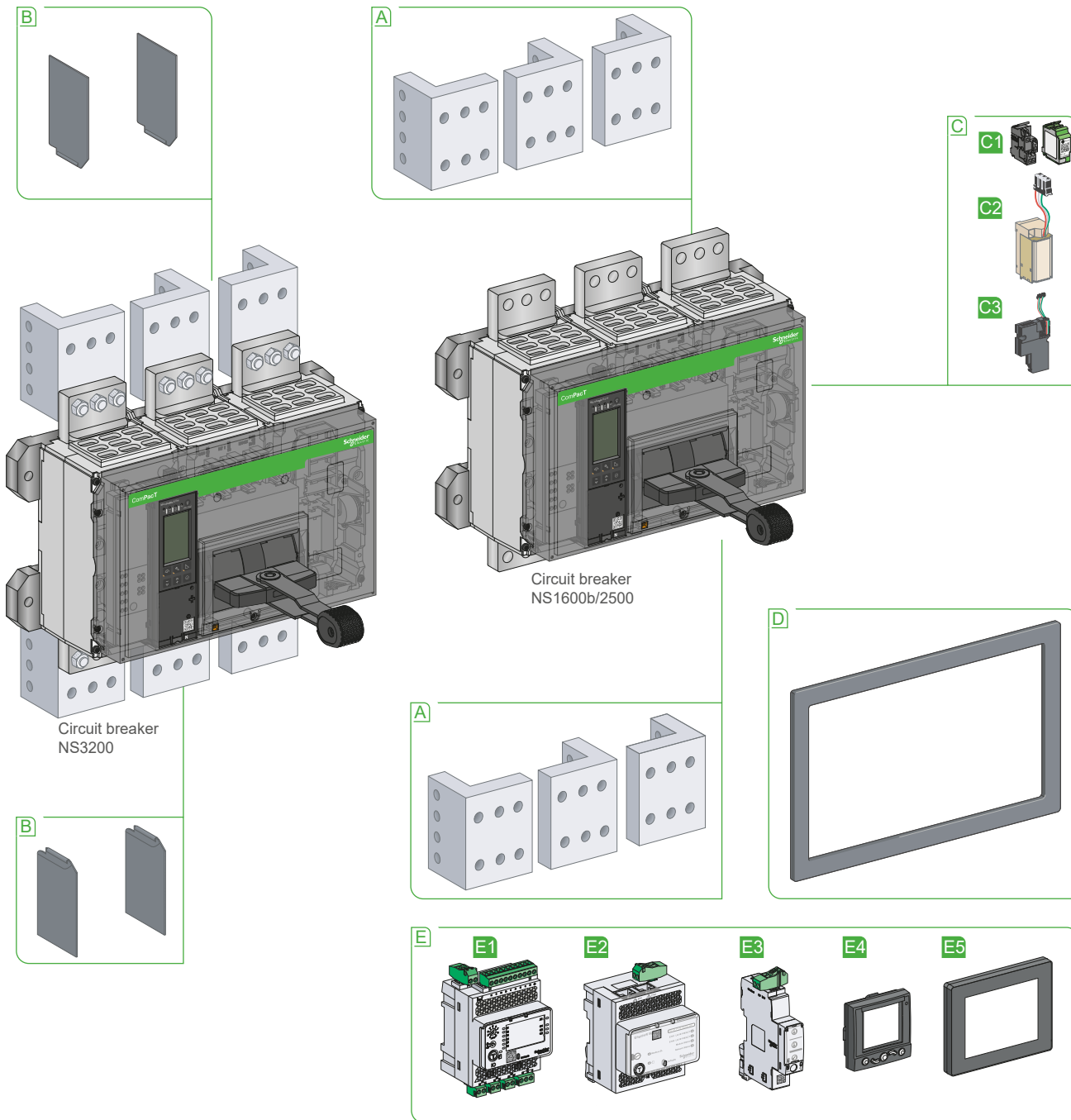

- A** Vertical-connection adapters
- B** Interphase barriers
- C**
  - C1** Auxiliary contact
  - C2** Voltage release
  - C3** Communications module
- D** Escutcheon

- E**
  - E1** I/O (Input/Output) application module for LV circuit breaker
  - E2** IFE Ethernet interface for LV circuit breaker
  - E3** IFM Modbus interface for LV circuit breaker
  - E4** FDM121: Front Display Module
  - E5** FDM128: Front Display Module

# Electrical and Mechanical Accessories

## ComPacT NS1600b to 3200

All the auxiliary contacts opposite are also available in "low-level" versions capable of switching very low loads (e.g. for the control of PLCs or electronic circuits).



294450.eps

Screwless type: OF, SD and SDE changeover contacts



054549-18.eps

Screw type: OF, SD and SDE changeover contacts



LV425454.eps



LV425453.eps

Wireless type: OF, SD and SDE changeover contacts

### Indication Contacts

#### Contacts Installed in the Device

Changeover contacts are used to remote circuit breaker status information and can thus be used for indications, electrical locking, relaying, etc. They comply with the IEC 60947-5-1 international recommendation.

#### Functions

- OF (ON/OFF) - indicates the position of the main circuit breaker contacts
- SD (trip indication) - indicates that the circuit breaker has tripped due to:
  - An overload
  - A short-circuit
  - An earth-leakage fault
  - Operation of a voltage release
  - Operation of the "push to trip" button
- Returns to de-energized state when the circuit breaker is reset.
- SDE (fault indication) - indicates that the circuit breaker has tripped due to:
  - An overload
  - A short-circuit
  - An earth-leakage fault.

Returns to de-energized state when the circuit breaker is reset.

#### Installation

- OF, SD and SDE functions - a single type of contact provides all these different indication functions, depending on the position where it is inserted in the device. The contacts clip into slots behind the front cover of the circuit breaker.

#### Electrical characteristics of the OF/SD/SDE auxiliary contacts

Contacts	Standard contact with spring terminals				Low-level contact with screw terminals				
	AC12	AC15	DC12	DC14	AC12	AC15	DC12	DC14	
Rated thermal current (A)	5				5				
Minimum load	100 mA at 24 V				1 mA at 4 V				
Utilization cat. (IEC 60947-5-1)	AC12	AC15	DC12	DC14	AC12	AC15	DC12	DC14	
Operational current (A)	24 V	5	5	5	1	5	3	5	1
	48 V	5	5	2.5	0.2	5	3	2.5	0.2
	110 V	5	5	0.6	0.05	5	2.5	0.6	0.05
	220/240 V	5	4	-	-	5	2	-	-
	250 V	-	-	0.3	0.03	5	-	0.3	0.03
	380/440 V	5	2	-	-	5	1.5	-	-
480 V	5	1.5	-	-	5	1	-	-	
660/690 V	5	0.1	-	-	-	-	-	-	



# New Generation, Simpler Commercial References New Meaningful References To Make Your Life Easier

We know any change in commercial references will be an adjustment, but in the long run we believe this change is needed, and will make your life easier.

ComPacT type	Frame rating	Breaking capacity	Number of poles	MicroLogic trip unit	Mounting	Control	Suffix	
NS = C	NS630 = 063	N = N	3P = 3	2.0 = 20	Fixed = F	Manually operated = M	Extended rotary handle = E	
	NS800 = 080	H = H	4P = 4	5.0 = 50	Withdrawable = W		Direct rotary handle = D	
	NS1000 = 100	L = L		6.0 = 60			No handle = no suffix	
	NS1250 = 125	LB = B		2.0A = 2A				
	NS1600 = 160	NA = S		5.0A = 5A				
	NS1600b = 16b			6.0A = 6A				
	NS2000 = 200			7.0A = 7A				
	NS2500 = 250			2.0E = 2E				
	NS3200 = 320			5.0E = 5E				
				6.0E = 6E				
				5.0P = 5P				
				6.0P = 6P				
				7.0P = 7P				
		NA = NA						

For example, C080N32EFM is ComPacT breaker NS800 N 50kA 3P MicroLogic 2.0E Fixed Manually Operated.

### Scan QR code for breaker updates

Each breaker is equipped with a QR code that allows you to get the latest information on your breaker.



# ComPacT NS630b to NS1600 Fixed Manually Operated Complete Device

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33460	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0	C063N320FM	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33466	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0	C080N320FM	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33472	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0	C100N320FM	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33478	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0	C125N320FM	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33482	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0	C160N320FM	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33461	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0	C063H320FM	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33467	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0	C080H320FM	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33473	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0	C100H320FM	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33479	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0	C125H320FM	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33483	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0	C160H320FM	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33462	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 2.0	C063L320FM	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33468	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 2.0	C080L320FM	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33474	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 2.0	C100L320FM	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33463	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 2.0	C063N420FM	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33469	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 2.0	C080N420FM	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33475	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 2.0	C100N420FM	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33480	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 2.0	C125N420FM	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33484	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 2.0	C160N420FM	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33464	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0	C063H420FM	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33470	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0	C080H420FM	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33476	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0	C100H420FM	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33481	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0	C125H420FM	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33485	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0	C160H420FM	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33465	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 2.0	C063L420FM	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33471	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 2.0	C080L420FM	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33477	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 2.0	C100L420FM	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 2.0	Yes	Yes
33546	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0	C063N350FM	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33552	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0	C080N350FM	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33558	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0	C100N350FM	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33564	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0	C125N350FM	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33568	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0	C160N350FM	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33547	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0	C063H350FM	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33553	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0	C080H350FM	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33559	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0	C100H350FM	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33565	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0	C125H350FM	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33569	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0	C160H350FM	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0	Yes	Yes

# ComPacT NS630b to NS1600 Fixed Manually Operated Complete Device

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33548	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 5.0	C063L350FM	ComPacT NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33554	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 5.0	C080L350FM	ComPacT NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33560	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 5.0	C100L350FM	ComPacT NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33549	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0	C063N450FM	ComPacT NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33555	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0	C080N450FM	ComPacT NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33561	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0	C100N450FM	ComPacT NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33566	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0	C125N450FM	ComPacT NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33570	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0	C160N450FM	ComPacT NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33550	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0	C063H450FM	ComPacT NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33556	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0	C080H450FM	ComPacT NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33562	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0	C100H450FM	ComPacT NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33567	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0	C125H450FM	ComPacT NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33571	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0	C160H450FM	ComPacT NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33551	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 5.0	C063L450FM	ComPacT NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33557	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 5.0	C080L450FM	ComPacT NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33563	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 5.0	C100L450FM	ComPacT NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 5.0	Yes	Yes
33886	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 6.0	C063N360FM	ComPacT NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33893	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 6.0	C080N360FM	ComPacT NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33909	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 6.0	C100N360FM	ComPacT NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33919	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 6.0	C125N360FM	ComPacT NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33925	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 6.0	C160N360FM	ComPacT NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33887	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 6.0	C063H360FM	ComPacT NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33894	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 6.0	C080H360FM	ComPacT NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33916	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 6.0	C100H360FM	ComPacT NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33922	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 6.0	C125H360FM	ComPacT NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33926	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 6.0	C160H360FM	ComPacT NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33888	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 6.0	C063N460FM	ComPacT NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33896	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 6.0	C080N460FM	ComPacT NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33917	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 6.0	C100N460FM	ComPacT NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33923	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 6.0	C125N460FM	ComPacT NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33927	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 6.0	C160N460FM	ComPacT NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33889	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 6.0	C063H460FM	ComPacT NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33901	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 6.0	C080H460FM	ComPacT NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33918	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 6.0	C100H460FM	ComPacT NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33924	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 6.0	C125H460FM	ComPacT NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 6.0	Yes	Yes
33928	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 6.0	C160H460FM	ComPacT NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 6.0	Yes	Yes

# ComPacT NS630b to NS1600 Fixed Manually Operated Complete Device

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33223	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0A	C063N32AFM	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33233	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0A	C080N32AFM	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33243	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	C100N32AFM	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33253	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0A	C125N32AFM	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33263	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0A	C160N32AFM	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33228	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0A	C063H32AFM	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33238	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0A	C080H32AFM	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33248	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	C100H32AFM	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33258	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0A	C125H32AFM	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33268	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0A	C160H32AFM	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33497	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 2.0A	C063L32AFM	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33498	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 2.0A	C080L32AFM	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33499	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	C100L32AFM	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33227	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 2.0A	C063N42AFM	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33237	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 2.0A	C080N42AFM	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33247	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	C100N42AFM	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33257	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 2.0A	C125N42AFM	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33267	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 2.0A	C160N42AFM	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33229	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0A	C063H42AFM	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33239	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0A	C080H42AFM	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33249	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	C100H42AFM	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33259	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0A	C125H42AFM	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33269	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0A	C160H42AFM	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33500	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 2.0A	C063L42AFM	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33501	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 2.0A	C080L42AFM	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33502	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	C100L42AFM	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 2.0A	Yes	Yes
33323	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0A	C063N35AFM	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33333	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0A	C080N35AFM	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33343	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	C100N35AFM	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33353	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0A	C125N35AFM	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33363	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0A	C160N35AFM	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33328	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0A	C063H35AFM	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33338	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0A	C080H35AFM	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33348	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	C100H35AFM	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33358	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0A	C125H35AFM	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33368	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0A	C160H35AFM	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0A	Yes	Yes



# ComPacT NS630b to NS1600 Fixed Manually Operated Complete Device

Old ComPacT NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPacT NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPacT NS
33516	ComPact NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 5.0A	C063L35AFM	ComPacT NS630bL 150kA 3P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33517	ComPact NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 5.0A	C080L35AFM	ComPacT NS800L 150kA 3P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33518	ComPact NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	C100L35AFM	ComPacT NS1000L 150kA 3P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33327	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0A	C063N45AFM	ComPacT NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33337	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0A	C080N45AFM	ComPacT NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33347	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	C100N45AFM	ComPacT NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33357	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0A	C125N45AFM	ComPacT NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33367	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0A	C160N45AFM	ComPacT NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33329	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0A	C063H45AFM	ComPacT NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33339	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0A	C080H45AFM	ComPacT NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33349	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	C100H45AFM	ComPacT NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33359	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0A	C125H45AFM	ComPacT NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33369	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0A	C160H45AFM	ComPacT NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33519	ComPact NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 5.0A	C063L45AFM	ComPacT NS630bL 150kA 4P 630A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33520	ComPact NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 5.0A	C080L45AFM	ComPacT NS800L 150kA 4P 800A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
33521	ComPact NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	C100L45AFM	ComPacT NS1000L 150kA 4P 1000A Fixed Front Connected MicroLogic 5.0A	Yes	Yes
34400	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0E	C063N32EFM	ComPacT NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34404	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0E	C080N32EFM	ComPacT NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34408	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	C100N32EFM	ComPacT NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34412	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	C125N32EFM	ComPacT NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34416	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	C160N32EFM	ComPacT NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34401	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0E	C063H32EFM	ComPacT NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34405	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0E	C080H32EFM	ComPacT NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34409	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	C100H32EFM	ComPacT NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34413	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	C125H32EFM	ComPacT NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34417	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	C160H32EFM	ComPacT NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34402	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0E	C063N42EFM	ComPacT NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34406	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0E	C080N42EFM	ComPacT NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34410	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	C100N42EFM	ComPacT NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34414	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	C125N42EFM	ComPacT NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34418	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	C160N42EFM	ComPacT NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34403	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0E	C063H42EFM	ComPacT NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34407	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0E	C080H42EFM	ComPacT NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34411	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0E	C100H42EFM	ComPacT NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34415	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0E	C125H42EFM	ComPacT NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 2.0E	Yes	Yes
34419	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0E	C160H42EFM	ComPacT NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 2.0E	Yes	Yes

# ComPacT NS630b to NS1600 Fixed Manually Operated Complete Device

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
34420	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0E	C063N35EFM	ComPact NS630bN 50kA 3P 630A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34424	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0E	C080N35EFM	ComPact NS800N 50kA 3P 800A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34428	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0E	C100N35EFM	ComPact NS1000N 50kA 3P 1000A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34432	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0E	C125N35EFM	ComPact NS1250N 50kA 3P 1250A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34436	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0E	C160N35EFM	ComPact NS1600N 50kA 3P 1600A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34421	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0E	C063H35EFM	ComPact NS630bH 70kA 3P 630A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34425	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0E	C080H35EFM	ComPact NS800H 70kA 3P 800A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34429	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0E	C100H35EFM	ComPact NS1000H 70kA 3P 1000A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34433	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0E	C125H35EFM	ComPact NS1250H 70kA 3P 1250A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34437	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0E	C160H35EFM	ComPact NS1600H 70kA 3P 1600A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34422	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0E	C063N45EFM	ComPact NS630bN 50kA 4P 630A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34426	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0E	C080N45EFM	ComPact NS800N 50kA 4P 800A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34430	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0E	C100N45EFM	ComPact NS1000N 50kA 4P 1000A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34434	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0E	C125N45EFM	ComPact NS1250N 50kA 4P 1250A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34438	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0E	C160N45EFM	ComPact NS1600N 50kA 4P 1600A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34423	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0E	C063H45EFM	ComPact NS630bH 70kA 4P 630A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34427	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0E	C080H45EFM	ComPact NS800H 70kA 4P 800A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34431	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0E	C100H45EFM	ComPact NS1000H 70kA 4P 1000A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34435	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0E	C125H45EFM	ComPact NS1250H 70kA 4P 1250A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
34439	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0E	C160H45EFM	ComPact NS1600H 70kA 4P 1600A Fixed Front Connected MicroLogic 5.0E	Yes	Yes
33486	ComPact NS630bNA 3P 630A Fixed Front Connected MicroLogic NA	C063S3NAFM	ComPact NS630bNA 3P 630A Fixed Front Connected MicroLogic NA	Yes	Yes
33487	ComPact NS800NA 3P 800A Fixed Front Connected MicroLogic NA	C080S3NAFM	ComPact NS800NA 3P 800A Fixed Front Connected MicroLogic NA	Yes	Yes
33488	ComPact NS1000NA 3P 1000A Fixed Front Connected MicroLogic NA	C100S3NAFM	ComPact NS1000NA 3P 1000A Fixed Front Connected MicroLogic NA	Yes	Yes
33489	ComPact NS1250NA 3P 1250A Fixed Front Connected MicroLogic NA	C125S3NAFM	ComPact NS1250NA 3P 1250A Fixed Front Connected MicroLogic NA	Yes	Yes
33490	ComPact NS1600NA 3P 1600A Fixed Front Connected MicroLogic NA	C160S3NAFM	ComPact NS1600NA 3P 1600A Fixed Front Connected MicroLogic NA	Yes	Yes
33491	ComPact NS630bNA 4P 630A Fixed Front Connected MicroLogic NA	C063S4NAFM	ComPact NS630bNA 4P 630A Fixed Front Connected MicroLogic NA	Yes	Yes
33492	ComPact NS800NA 4P 800A Fixed Front Connected MicroLogic NA	C080S4NAFM	ComPact NS800NA 4P 800A Fixed Front Connected MicroLogic NA	Yes	Yes
33493	ComPact NS1000NA 4P 1000A Fixed Front Connected MicroLogic NA	C100S4NAFM	ComPact NS1000NA 4P 1000A Fixed Front Connected MicroLogic NA	Yes	Yes
33494	ComPact NS1250NA 4P 1250A Fixed Front Connected MicroLogic NA	C125S4NAFM	ComPact NS1250NA 4P 1250A Fixed Front Connected MicroLogic NA	Yes	Yes
33495	ComPact NS1600NA 4P 1600A Fixed Front Connected MicroLogic NA	C160S4NAFM	ComPact NS1600NA 4P 1600A Fixed Front Connected MicroLogic NA	Yes	Yes

# ComPacT NS630b to NS1600 Fixed Manually Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33220	ComPact NS630bN 3P Basic Frame Fixed Manual	C063N3FM	ComPacT NS630bN 3P Basic Frame Fixed Manual	Yes	Yes
33230	ComPact NS800N 3P Basic Frame Fixed Manual	C080N3FM	ComPacT NS800N 3P Basic Frame Fixed Manual	Yes	Yes
33240	ComPact NS1000N 3P Basic Frame Fixed Manual	C100N3FM	ComPacT NS1000N 3P Basic Frame Fixed Manual	Yes	Yes
33250	ComPact NS1250N 3P Basic Frame Fixed Manual	C125N3FM	ComPacT NS1250N 3P Basic Frame Fixed Manual	Yes	Yes
33260	ComPact NS1600N 3P Basic Frame Fixed Manual	C160N3FM	ComPacT NS1600N 3P Basic Frame Fixed Manual	Yes	Yes
33224	ComPact NS630bN 4P Basic Frame Fixed Manual	C063N4FM	ComPacT NS630bN 4P Basic Frame Fixed Manual	Yes	Yes
33234	ComPact NS800N 4P Basic Frame Fixed Manual	C080N4FM	ComPacT NS800N 4P Basic Frame Fixed Manual	Yes	Yes
33244	ComPact NS1000N 4P Basic Frame Fixed Manual	C100N4FM	ComPacT NS1000N 4P Basic Frame Fixed Manual	Yes	Yes
33254	ComPact NS1250N 4P Basic Frame Fixed Manual	C125N4FM	ComPacT NS1250N 4P Basic Frame Fixed Manual	Yes	Yes
33264	ComPact NS1600N 4P Basic Frame Fixed Manual	C160N4FM	ComPacT NS1600N 4P Basic Frame Fixed Manual	Yes	Yes
33221	ComPact NS630bH 3P Basic Frame Fixed Manual	C063H3FM	ComPacT NS630bH 3P Basic Frame Fixed Manual	Yes	Yes
33231	ComPact NS800H 3P Basic Frame Fixed Manual	C080H3FM	ComPacT NS800H 3P Basic Frame Fixed Manual	Yes	Yes
33241	ComPact NS1000H 3P Basic Frame Fixed Manual	C100H3FM	ComPacT NS1000H 3P Basic Frame Fixed Manual	Yes	Yes
33251	ComPact NS1250H 3P Basic Frame Fixed Manual	C125H3FM	ComPacT NS1250H 3P Basic Frame Fixed Manual	Yes	Yes
33261	ComPact NS1600H 3P Basic Frame Fixed Manual	C160H3FM	ComPacT NS1600H 3P Basic Frame Fixed Manual	Yes	Yes
33225	ComPact NS630bH 4P Basic Frame Fixed Manual	C063H4FM	ComPacT NS630bH 4P Basic Frame Fixed Manual	Yes	Yes
33235	ComPact NS800H 4P Basic Frame Fixed Manual	C080H4FM	ComPacT NS800H 4P Basic Frame Fixed Manual	Yes	Yes
33245	ComPact NS1000H 4P Basic Frame Fixed Manual	C100H4FM	ComPacT NS1000H 4P Basic Frame Fixed Manual	Yes	Yes
33255	ComPact NS1250H 4P Basic Frame Fixed Manual	C125H4FM	ComPacT NS1250H 4P Basic Frame Fixed Manual	Yes	Yes
33265	ComPact NS1600H 4P Basic Frame Fixed Manual	C160H4FM	ComPacT NS1600H 4P Basic Frame Fixed Manual	Yes	Yes
33222	ComPact NS630bL 3P Basic Frame Fixed Manual	C063L3FM	ComPacT NS630bL 3P Basic Frame Fixed Manual	Yes	Yes
33232	ComPact NS800L 3P Basic Frame Fixed Manual	C080L3FM	ComPacT NS800L 3P Basic Frame Fixed Manual	Yes	Yes
33242	ComPact NS1000L 3P Basic Frame Fixed Manual	C100L3FM	ComPacT NS1000L 3P Basic Frame Fixed Manual	Yes	Yes
33226	ComPact NS630bL 4P Basic Frame Fixed Manual	C063L4FM	ComPacT NS630bL 4P Basic Frame Fixed Manual	Yes	Yes
33236	ComPact NS800L 4P Basic Frame Fixed Manual	C080L4FM	ComPacT NS800L 4P Basic Frame Fixed Manual	Yes	Yes
33246	ComPact NS1000L 4P Basic Frame Fixed Manual	C100L4FM	ComPacT NS1000L 4P Basic Frame Fixed Manual	Yes	Yes
48952	ComPact NS630bLB 3P Basic Frame Fixed Manual	C063B3FM	ComPacT NS630bLB 3P Basic Frame Fixed Manual	Yes	Yes
48953	ComPact NS800LB 3P Basic Frame Fixed Manual	C080B3FM	ComPacT NS800LB 3P Basic Frame Fixed Manual	Yes	Yes
48955	ComPact NS630bLB 4P Basic Frame Fixed Manual	C063B4FM	ComPacT NS630bLB 4P Basic Frame Fixed Manual	Yes	Yes
48956	ComPact NS800LB 4P Basic Frame Fixed Manual	C080B4FM	ComPacT NS800LB 4P Basic Frame Fixed Manual	Yes	Yes
33504	Trip unit Micrologic 2.0	C20FM	Trip unit MicroLogic 2.0	Yes	Yes
33511	Trip unit Micrologic 5.0	C50FM	Trip unit MicroLogic 5.0	Yes	Yes
33515	Trip unit Micrologic 6.0	C60FM	Trip unit MicroLogic 6.0	Yes	Yes
33505	Trip unit Micrologic 2.0 A	C2AFM	Trip unit MicroLogic 2.0 A	Yes	Yes
33512	Trip unit Micrologic 5.0 A	C5AFM	Trip unit MicroLogic 5.0 A	Yes	Yes
33513	Trip unit Micrologic 6.0 A	C6AFM	Trip unit MicroLogic 6.0 A	Yes	Yes
33514	Trip unit Micrologic 7.0 A	C7AFM	Trip unit MicroLogic 7.0 A	Yes	Yes
33535	Trip unit Micrologic 2.0 E	C2EFM	Trip unit MicroLogic 2.0 E	Yes	Yes
33537	Trip unit Micrologic 5.0 E	C5EFM	Trip unit MicroLogic 5.0 E	Yes	Yes
33539	Trip unit Micrologic 6.0 E	C6EFM	Trip unit MicroLogic 6.0 E	Yes	Yes

# ComPacT NS630b to NS1600 Fixed Manually Operated Device Based on Separate Components

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
65290	Trip unit Micrologic 5.0 P	C5PFM	Trip unit MicroLogic 5.0 P	Yes	Yes
65291	Trip unit Micrologic 6.0 P	C6PFM	Trip unit MicroLogic 6.0 P	Yes	Yes
65292	Trip unit Micrologic 7.0 P	C7PFM	Trip unit MicroLogic 7.0 P	Yes	Yes
33420	ComPact NS630bNA 3P Basic Frame Fixed Manual	C063S3FM	ComPact NS630bNA 3P Basic Frame Fixed Manual	Yes	Yes
33422	ComPact NS800NA 3P Basic Frame Fixed Manual	C080S3FM	ComPact NS800NA 3P Basic Frame Fixed Manual	Yes	Yes
33424	ComPact NS1000NA 3P Basic Frame Fixed Manual	C100S3FM	ComPact NS1000NA 3P Basic Frame Fixed Manual	Yes	Yes
33426	ComPact NS1250NA 3P Basic Frame Fixed Manual	C125S3FM	ComPact NS1250NA 3P Basic Frame Fixed Manual	Yes	Yes
33428	ComPact NS1600NA 3P Basic Frame Fixed Manual	C160S3FM	ComPact NS1600NA 3P Basic Frame Fixed Manual	Yes	Yes
33421	ComPact NS630bNA 4P Basic Frame Fixed Manual	C063S4FM	ComPact NS630bNA 4P Basic Frame Fixed Manual	Yes	Yes
33423	ComPact NS800NA 4P Basic Frame Fixed Manual	C080S4FM	ComPact NS800NA 4P Basic Frame Fixed Manual	Yes	Yes
33425	ComPact NS1000NA 4P Basic Frame Fixed Manual	C100S4FM	ComPact NS1000NA 4P Basic Frame Fixed Manual	Yes	Yes
33427	ComPact NS1250NA 4P Basic Frame Fixed Manual	C125S4FM	ComPact NS1250NA 4P Basic Frame Fixed Manual	Yes	Yes
33429	ComPact NS1600NA 4P Basic Frame Fixed Manual	C160S4FM	ComPact NS1600NA 4P Basic Frame Fixed Manual	Yes	Yes
33598	ComPact NS Top Front Connections 630 A to 1000 A Fixed 3P		No Change	Yes	
33599	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 3P		No Change	Yes	
33600	ComPact NS Top Front Connections 630 A to 1250 A Fixed 3P		No Change	Yes	
33601	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 3P		No Change	Yes	
33602	ComPact NS Top Front Connections 1600 A Fixed 3P		No Change	Yes	
33603	ComPact NS Bottom Front Connections 1600 A Fixed 3P		No Change	Yes	
33608	ComPact NS Top Front Connections 630 A to 1000 A Fixed 4P		No Change	Yes	
33609	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 4P		No Change	Yes	
33610	ComPact NS Top Front Connections 630A to 1250A Fixed 4P		No Change	Yes	
33611	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 4P		No Change	Yes	
33612	ComPact NS Top Front Connections 1600 A Fixed 4P		No Change	Yes	
33613	ComPact NS Bottom Front Connections 1600 A Fixed 4P		No Change	Yes	
33604	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Fixed 3P		No Change	Yes	
33605	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Fixed 3P		No Change	Yes	
33606	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Fixed 3P		No Change	Yes	
33607	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Fixed 3P		No Change	Yes	
33614	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Fixed 4P		No Change	Yes	
33615	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Fixed 4P		No Change	Yes	
33616	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Fixed 4P		No Change	Yes	
33617	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Fixed 4P		No Change	Yes	



# ComPacT NS1600b to NS3200 Fixed Manually Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
34000	ComPact NS1600bN 3P Basic Frame Fixed Manual	C16bN3FM	ComPacT NS1600bN 3P Basic Frame Fixed Manual	Yes	Yes
34006	ComPact NS2000N 3P Basic Frame Fixed Manual	C200N3FM	ComPacT NS2000N 3P Basic Frame Fixed Manual	Yes	Yes
34012	ComPact NS2500N 3P Basic Frame Fixed Manual	C250N3FM	ComPacT NS2500N 3P Basic Frame Fixed Manual	Yes	Yes
34018	ComPact NS3200N 3P Basic Frame Fixed Manual	C320N3FM	ComPacT NS3200N 3P Basic Frame Fixed Manual	Yes	Yes
34001	ComPact NS1600bH 3P Basic Frame Fixed Manual	C16bH3FM	ComPacT NS1600bH 3P Basic Frame Fixed Manual	Yes	Yes
34007	ComPact NS2000H 3P Basic Frame Fixed Manual	C200H3FM	ComPacT NS2000H 3P Basic Frame Fixed Manual	Yes	Yes
34013	ComPact NS2500H 3P Basic Frame Fixed Manual	C250H3FM	ComPacT NS2500H 3P Basic Frame Fixed Manual	Yes	Yes
34019	ComPact NS3200H 3P Basic Frame Fixed Manual	C320H3FM	ComPacT NS3200H 3P Basic Frame Fixed Manual	Yes	Yes
34003	ComPact NS1600bN 4P Basic Frame Fixed Manual	C16bN4FM	ComPacT NS1600bN 4P Basic Frame Fixed Manual	Yes	Yes
34009	ComPact NS2000N 4P Basic Frame Fixed Manual	C200N4FM	ComPacT NS2000N 4P Basic Frame Fixed Manual	Yes	Yes
34015	ComPact NS2500N 4P Basic Frame Fixed Manual	C250N4FM	ComPacT NS2500N 4P Basic Frame Fixed Manual	Yes	Yes
34021	ComPact NS3200N 4P Basic Frame Fixed Manual	C320N4FM	ComPacT NS3200N 4P Basic Frame Fixed Manual	Yes	Yes
34004	ComPact NS1600bH 4P Basic Frame Fixed Manual	C16bH4FM	ComPacT NS1600bH 4P Basic Frame Fixed Manual	Yes	Yes
34010	ComPact NS2000H 4P Basic Frame Fixed Manual	C200H4FM	ComPacT NS2000H 4P Basic Frame Fixed Manual	Yes	Yes
34016	ComPact NS2500H 4P Basic Frame Fixed Manual	C250H4FM	ComPacT NS2500H 4P Basic Frame Fixed Manual	Yes	Yes
34022	ComPact NS3200H 4P Basic Frame Fixed Manual	C320H4FM	ComPacT NS3200H 4P Basic Frame Fixed Manual	Yes	Yes
33504	Trip unit Micrologic 2.0	C20FM	Trip unit MicroLogic 2.0	Yes	Yes
33511	Trip unit Micrologic 5.0	C50FM	Trip unit MicroLogic 5.0	Yes	Yes
33515	Trip unit Micrologic 6.0	C60FM	Trip unit MicroLogic 6.0	Yes	Yes
33505	Trip unit Micrologic 2.0 A	C2AFM	Trip unit MicroLogic 2.0 A	Yes	Yes
33512	Trip unit Micrologic 5.0 A	C5AFM	Trip unit MicroLogic 5.0 A	Yes	Yes
33513	Trip unit Micrologic 6.0 A	C6AFM	Trip unit MicroLogic 6.0 A	Yes	Yes
33514	Trip unit Micrologic 7.0 A	C7AFM	Trip unit MicroLogic 7.0 A	Yes	Yes
33535	Trip unit Micrologic 2.0 E	C2EFM	Trip unit MicroLogic 2.0 E	Yes	Yes
33537	Trip unit Micrologic 5.0 E	C5EFM	Trip unit MicroLogic 5.0 E	Yes	Yes
33539	Trip unit Micrologic 6.0 E	C6EFM	Trip unit MicroLogic 6.0 E	Yes	Yes
34024	ComPact NS1600bNA 3P Basic Frame Fixed Manual	C16bS3FM	ComPacT NS1600bNA 3P Basic Frame Fixed Manual	Yes	Yes
34027	ComPact NS2000NA 3P Basic Frame Fixed Manual	C200S3FM	ComPacT NS2000NA 3P Basic Frame Fixed Manual	Yes	Yes
34030	ComPact NS2500NA 3P Basic Frame Fixed Manual	C250S3FM	ComPacT NS2500NA 3P Basic Frame Fixed Manual	Yes	Yes
34033	ComPact NS3200NA 3P Basic Frame Fixed Manual	C320S3FM	ComPacT NS3200NA 3P Basic Frame Fixed Manual	Yes	Yes
34025	ComPact NS1600bNA 4P Basic Frame Fixed Manual	C16bS4FM	ComPacT NS1600bNA 4P Basic Frame Fixed Manual	Yes	Yes
34028	ComPact NS2000NA 4P Basic Frame Fixed Manual	C200S4FM	ComPacT NS2000NA 4P Basic Frame Fixed Manual	Yes	Yes
34031	ComPact NS2500NA 4P Basic Frame Fixed Manual	C250S4FM	ComPacT NS2500NA 4P Basic Frame Fixed Manual	Yes	Yes
34034	ComPact NS3200NA 4P Basic Frame Fixed Manual	C320S4FM	ComPacT NS3200NA 4P Basic Frame Fixed Manual	Yes	Yes



# ComPacT NS630b to NS1600 Withdrawable Manually Operated

## Device Based on Separate Components

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33320	ComPact NS630bN 3P Basic Frame Withdrawable Manual	C063N3WM	ComPact NS630bN 3P Basic Frame Withdrawable Manual	Yes	Yes
33330	ComPact NS800N 3P Basic Frame Withdrawable Manual	C080N3WM	ComPact NS800N 3P Basic Frame Withdrawable Manual	Yes	Yes
33340	ComPact NS1000N 3P Basic Frame Withdrawable Manual	C100N3WM	ComPact NS1000N 3P Basic Frame Withdrawable Manual	Yes	Yes
33350	ComPact NS1250N 3P Basic Frame Withdrawable Manual	C125N3WM	ComPact NS1250N 3P Basic Frame Withdrawable Manual	Yes	Yes
33360	ComPact NS1600N 3P Basic Frame Withdrawable Manual	C160N3WM	ComPact NS1600N 3P Basic Frame Withdrawable Manual	Yes	Yes
33324	ComPact NS630bN 4P Basic Frame Withdrawable Manual	C063N4WM	ComPact NS630bN 4P Basic Frame Withdrawable Manual	Yes	Yes
33334	ComPact NS800N 4P Basic Frame Withdrawable Manual	C080N4WM	ComPact NS800N 4P Basic Frame Withdrawable Manual	Yes	Yes
33344	ComPact NS1000N 4P Basic Frame Withdrawable Manual	C100N4WM	ComPact NS1000N 4P Basic Frame Withdrawable Manual	Yes	Yes
33354	ComPact NS1250N 4P Basic Frame Withdrawable Manual	C125N4WM	ComPact NS1250N 4P Basic Frame Withdrawable Manual	Yes	Yes
33364	ComPact NS1600N 4P Basic Frame Withdrawable Manual	C160N4WM	ComPact NS1600N 4P Basic Frame Withdrawable Manual	Yes	Yes
33321	ComPact NS630bH 3P Basic Frame Withdrawable Manual	C063H3WM	ComPact NS630bH 3P Basic Frame Withdrawable Manual	Yes	Yes
33331	ComPact NS800H 3P Basic Frame Withdrawable Manual	C080H3WM	ComPact NS800H 3P Basic Frame Withdrawable Manual	Yes	Yes
33341	ComPact NS1000H 3P Basic Frame Withdrawable Manual	C100H3WM	ComPact NS1000H 3P Basic Frame Withdrawable Manual	Yes	Yes
33351	ComPact NS1250H 3P Basic Frame Withdrawable Manual	C125H3WM	ComPact NS1250H 3P Basic Frame Withdrawable Manual	Yes	Yes
33361	ComPact NS1600H 3P Basic Frame Withdrawable Manual	C160H3WM	ComPact NS1600H 3P Basic Frame Withdrawable Manual	Yes	Yes
33325	ComPact NS630bH 4P Basic Frame Withdrawable Manual	C063H4WM	ComPact NS630bH 4P Basic Frame Withdrawable Manual	Yes	Yes
33335	ComPact NS800H 4P Basic Frame Withdrawable Manual	C080H4WM	ComPact NS800H 4P Basic Frame Withdrawable Manual	Yes	Yes
33345	ComPact NS1000H 4P Basic Frame Withdrawable Manual	C100H4WM	ComPact NS1000H 4P Basic Frame Withdrawable Manual	Yes	Yes
33355	ComPact NS1250H 4P Basic Frame Withdrawable Manual	C125H4WM	ComPact NS1250H 4P Basic Frame Withdrawable Manual	Yes	Yes
33365	ComPact NS1600H 4P Basic Frame Withdrawable Manual	C160H4WM	ComPact NS1600H 4P Basic Frame Withdrawable Manual	Yes	Yes
33322	ComPact NS630bL 3P Basic Frame Withdrawable Manual	C063L3WM	ComPact NS630bL 3P Basic Frame Withdrawable Manual	Yes	Yes
33332	ComPact NS800L 3P Basic Frame Withdrawable Manual	C080L3WM	ComPact NS800L 3P Basic Frame Withdrawable Manual	Yes	Yes
33342	ComPact NS1000L 3P Basic Frame Withdrawable Manual	C100L3WM	ComPact NS1000L 3P Basic Frame Withdrawable Manual	Yes	Yes
33326	ComPact NS630bL 4P Basic Frame Withdrawable Manual	C063L4WM	ComPact NS630bL 4P Basic Frame Withdrawable Manual	Yes	Yes
33336	ComPact NS800L 4P Basic Frame Withdrawable Manual	C080L4WM	ComPact NS800L 4P Basic Frame Withdrawable Manual	Yes	Yes
33346	ComPact NS1000L 4P Basic Frame Withdrawable Manual	C100L4WM	ComPact NS1000L 4P Basic Frame Withdrawable Manual	Yes	Yes
48967	ComPact NS630bLB 3P Basic Frame Withdrawable Manual	C063B3WM	ComPact NS630bLB 3P Basic Frame Withdrawable Manual	Yes	Yes
48968	ComPact NS800LB 3P Basic Frame Withdrawable Manual	C080B3WM	ComPact NS800LB 3P Basic Frame Withdrawable Manual	Yes	Yes
48971	ComPact NS630bLB 4P Basic Frame Withdrawable Manual	C063B4WM	ComPact NS630bLB 4P Basic Frame Withdrawable Manual	Yes	Yes
48972	ComPact NS800LB 4P Basic Frame Withdrawable Manual	C080B4WM	ComPact NS800LB 4P Basic Frame Withdrawable Manual	Yes	Yes
33504	Trip unit Micrologic 2.0	C20WM	Trip unit MicroLogic 2.0	Yes	Yes
33511	Trip unit Micrologic 5.0	C50WM	Trip unit MicroLogic 5.0	Yes	Yes
33515	Trip unit Micrologic 6.0	C60WM	Trip unit MicroLogic 6.0	Yes	Yes
33505	Trip unit Micrologic 2.0 A	C2AWM	Trip unit MicroLogic 2.0 A	Yes	Yes
33512	Trip unit Micrologic 5.0 A	C5AWM	Trip unit MicroLogic 5.0 A	Yes	Yes
33513	Trip unit Micrologic 6.0 A	C6AWM	Trip unit MicroLogic 6.0 A	Yes	Yes
33514	Trip unit Micrologic 7.0 A	C7AWM	Trip unit MicroLogic 7.0 A	Yes	Yes
33535	Trip unit Micrologic 2.0 E	C2EWM	Trip unit MicroLogic 2.0 E	Yes	Yes

# ComPacT NS630b to NS1600 Withdrawable Manually Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33537	Trip unit Micrologic 5.0 E	C5EWM	Trip unit MicroLogic 5.0 E	Yes	Yes
33539	Trip unit Micrologic 6.0 E	C6EWM	Trip unit MicroLogic 6.0 E	Yes	Yes
65290	Trip unit Micrologic 5.0 P	C5PWM	Trip unit MicroLogic 5.0 P	Yes	Yes
65291	Trip unit Micrologic 6.0 P	C6PWM	Trip unit MicroLogic 6.0 P	Yes	Yes
65292	Trip unit Micrologic 7.0 P	C7PWM	Trip unit MicroLogic 7.0 P	Yes	Yes
33430	ComPact NS630bNA 3P Basic Frame Withdrawable Manual	C063S3WM	ComPacT NS630bNA 3P Basic Frame Withdrawable Manual	Yes	Yes
33432	ComPact NS800NA 3P Basic Frame Withdrawable Manual	C080S3WM	ComPacT NS800NA 3P Basic Frame Withdrawable Manual	Yes	Yes
33434	ComPact NS1000NA 3P Basic Frame Withdrawable Manual	C100S3WM	ComPacT NS1000NA 3P Basic Frame Withdrawable Manual	Yes	Yes
33436	ComPact NS1250NA 3P Basic Frame Withdrawable Manual	C125S3WM	ComPacT NS1250NA 3P Basic Frame Withdrawable Manual	Yes	Yes
33438	ComPact NS1600NA 3P Basic Frame Withdrawable Manual	C160S3WM	ComPacT NS1600NA 3P Basic Frame Withdrawable Manual	Yes	Yes
33431	ComPact NS630bNA 4P Basic Frame Withdrawable Manual	C063S4WM	ComPacT NS630bNA 4P Basic Frame Withdrawable Manual	Yes	Yes
33433	ComPact NS800NA 4P Basic Frame Withdrawable Manual	C080S4WM	ComPacT NS800NA 4P Basic Frame Withdrawable Manual	Yes	Yes
33435	ComPact NS1000NA 4P Basic Frame Withdrawable Manual	C100S4WM	ComPacT NS1000NA 4P Basic Frame Withdrawable Manual	Yes	Yes
33437	ComPact NS1250NA 4P Basic Frame Withdrawable Manual	C125S4WM	ComPacT NS1250NA 4P Basic Frame Withdrawable Manual	Yes	Yes
33439	ComPact NS1600NA 4P Basic Frame Withdrawable Manual	C160S4WM	ComPacT NS1600NA 4P Basic Frame Withdrawable Manual	Yes	Yes
33722	Chassis ComPact NS630b to NS1250 Drawout 3P		No Change	Yes	Yes
33723	Chassis ComPact NS1600 Drawout 3P		No Change	Yes	
33725	Chassis ComPact NS630b to NS1250 Drawout 4P		No Change	Yes	
33726	Chassis ComPact NS1600 Drawout 4P		No Change	Yes	
33727	ComPact NS Top Front Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33728	ComPact NS Bottom Front Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33729	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33730	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33731	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33732	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33733	ComPact NS Top Front Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33734	ComPact NS Bottom Front Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33735	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33736	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33737	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33738	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	

# ComPact NS630b to NS1600 Fixed Electrically Operated Device Based on Separate Components

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33270	ComPact NS630bN 3P Basic Frame Fixed Electrical		No change	Yes	
33280	ComPact NS800N 3P Basic Frame Fixed Electrical		No change	Yes	
33290	ComPact NS1000N 3P Basic Frame Fixed Electrical		No change	Yes	
33300	ComPact NS1250N 3P Basic Frame Fixed Electrical		No change	Yes	
33310	ComPact NS1600N 3P Basic Frame Fixed Electrical		No change	Yes	
33274	ComPact NS630bN 4P Basic Frame Fixed Electrical		No change	Yes	
33284	ComPact NS800N 4P Basic Frame Fixed Electrical		No change	Yes	
33294	ComPact NS1000N 4P Basic Frame Fixed Electrical		No change	Yes	
33304	ComPact NS1250N 4P Basic Frame Fixed Electrical		No change	Yes	
33314	ComPact NS1600N 4P Basic Frame Fixed Electrical		No change	Yes	
33271	ComPact NS630bH 3P Basic Frame Fixed Electrical		No change	Yes	
33281	ComPact NS800H 3P Basic Frame Fixed Electrical		No change	Yes	
33291	ComPact NS1000H 3P Basic Frame Fixed Electrical		No change	Yes	
33301	ComPact NS1250H 3P Basic Frame Fixed Electrical		No change	Yes	
33311	ComPact NS1600H 3P Basic Frame Fixed Electrical		No change	Yes	
33275	ComPact NS630bH 4P Basic Frame Fixed Electrical		No change	Yes	
33285	ComPact NS800H 4P Basic Frame Fixed Electrical		No change	Yes	
33295	ComPact NS1000H 4P Basic Frame Fixed Electrical		No change	Yes	
33305	ComPact NS1250H 4P Basic Frame Fixed Electrical		No change	Yes	
33315	ComPact NS1600H 4P Basic Frame Fixed Electrical		No change	Yes	
33272	ComPact NS630bL 3P Basic Frame Fixed Electrical		No change	Yes	
33282	ComPact NS800L 3P Basic Frame Fixed Electrical		No change	Yes	
33292	ComPact NS1000L 3P Basic Frame Fixed Electrical		No change	Yes	
33276	ComPact NS630bL 4P Basic Frame Fixed Electrical		No change	Yes	
33286	ComPact NS800L 4P Basic Frame Fixed Electrical		No change	Yes	
33296	ComPact NS1000L 4P Basic Frame Fixed Electrical		No change	Yes	
33504	Trip unit Micrologic 2.0		No change	Yes	
33511	Trip unit Micrologic 5.0		No change	Yes	
33515	Trip unit Micrologic 6.0		No change	Yes	
33505	Trip unit Micrologic 2.0 A		No change	Yes	
33512	Trip unit Micrologic 5.0 A		No change	Yes	
33513	Trip unit Micrologic 6.0 A		No change	Yes	
33514	Trip unit Micrologic 7.0 A		No change	Yes	
33535	Trip unit Micrologic 2.0 E		No change	Yes	
33537	Trip unit Micrologic 5.0 E		No change	Yes	
33539	Trip unit Micrologic 6.0 E		No change	Yes	
65290	Trip unit Micrologic 5.0 P		No change	Yes	
65291	Trip unit Micrologic 6.0 P		No change	Yes	
65292	Trip unit Micrologic 7.0 P		No change	Yes	
33440	ComPact NS630bNA 3P Basic Frame Fixed Electrical		No change	Yes	

# ComPacT NS630b to NS1600 Fixed Electrically Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33442	ComPact NS800NA 3P Basic Frame Fixed Electrical		No change	Yes	
33444	ComPact NS1000NA 3P Basic Frame Fixed Electrical		No change	Yes	
33446	ComPact NS1250NA 3P Basic Frame Fixed Electrical		No change	Yes	
33448	ComPact NS1600NA 3P Basic Frame Fixed Electrical		No change	Yes	
33441	ComPact NS630bNA 4P Basic Frame Fixed Electrical		No change	Yes	
33443	ComPact NS800NA 4P Basic Frame Fixed Electrical		No change	Yes	
33445	ComPact NS1000NA 4P Basic Frame Fixed Electrical		No change	Yes	
33447	ComPact NS1250NA 4P Basic Frame Fixed Electrical		No change	Yes	
33449	ComPact NS1600NA 4P Basic Frame Fixed Electrical		No change	Yes	
33598	ComPact NS Top Front Connections 630 A to 1000 A Fixed 3P		No change	Yes	
33599	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 3P		No change	Yes	
33600	ComPact NS Top Front Connections 630 A to 1250 A Fixed 3P		No change	Yes	
33601	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 3P		No change	Yes	
33602	ComPact NS Top Front Connections 1600 A Fixed 3P		No change	Yes	
33603	ComPact NS Bottom Front Connections 1600 A Fixed 3P		No change	Yes	
33608	ComPact NS Top Front Connections 630 A to 1000 A Fixed 4P		No change	Yes	
33609	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 4P		No change	Yes	
33610	ComPact NS Top Front Connections 630 A to 1250 A Fixed 4P		No change	Yes	
33611	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 4P		No change	Yes	
33612	ComPact NS Top Front Connections 1600 A Fixed 4P		No change	Yes	
33613	ComPact NS Bottom Front Connections 1600 A Fixed 4P		No change	Yes	
33604	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Fixed 3P		No change	Yes	
33605	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Fixed 3P		No change	Yes	
33606	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Fixed 3P		No change	Yes	
33607	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Fixed 3P		No change	Yes	
33614	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Fixed 4P		No change	Yes	
33615	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Fixed 4P		No change	Yes	
33616	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Fixed 4P		No change	Yes	
33617	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Fixed 4P		No change	Yes	
33691	ComPact NS630b to NS1600 standard motor mechanism 48/60 VDC, 48 VAC 50/60 Hz		No change	Yes	
33687	ComPact NS630b to NS1600 standard motor mechanism 100/130 VAC 50/60 Hz		No change	Yes	
33688	ComPact NS630b to NS1600 standard motor mechanism 220/240 VAC 50/60 Hz		No change	Yes	
33689	ComPact NS630b to NS1600 communicating motor mechanism 48/60 VDC, 48 VAC 50/60 Hz		No change	Yes	
33694	ComPact NS630b to NS1600 communicating motor mechanism 100/130 VAC 50/60 Hz		No change	Yes	
33695	ComPact NS630b to NS1600 communicating motor mechanism 220/240 VAC 50/60 Hz		No change	Yes	
33696	ComPact NS630b to NS1600 communicating motor mechanism 380/415 VAC 50/60 Hz		No change	Yes	

# ComPacT NS630b to NS1600 Fixed Electrically Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33690	ComPact NS630b to NS1600 standard motor mechanism 24/30 VDC		No change	Yes	
33691	ComPact NS630b to NS1600 standard motor mechanism 48/60 VDC, 48 VAC 50/60 Hz		No change	Yes	
33692	ComPact NS630b to NS1600 standard motor mechanism 100/130 VDC		No change	Yes	
33693	ComPact NS630b to NS1600 standard motor mechanism 200/250 VDC		No change	Yes	
33697	ComPact NS630b to NS1600 communicating motor mechanism 24/30 VDC		No change	Yes	
33698	ComPact NS630b to NS1600 communicating motor mechanism 48/60 VDC, 48 VAC 50/60 Hz		No change	Yes	
33699	ComPact NS630b to NS1600 communicating motor mechanism 100/130 VDC		No change	Yes	
33700	ComPact NS630b to NS1600 communicating motor mechanism 200/250 VDC		No change	Yes	



# ComPacT NS630b to NS1600 Withdrawable Electrically Operated Device Based on Separate Components

Old ComPacT NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPacT NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPacT NS
33370	ComPact NS630bN 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33380	ComPact NS800N 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33390	ComPact NS1000N 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33400	ComPact NS1250N 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33410	ComPact NS1600N 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33374	ComPact NS630bN 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33384	ComPact NS800N 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33394	ComPact NS1000N 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33404	ComPact NS1250N 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33414	ComPact NS1600N 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33371	ComPact NS630bH 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33381	ComPact NS800H 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33391	ComPact NS1000H 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33401	ComPact NS1250H 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33411	ComPact NS1600H 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33375	ComPact NS630bH 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33385	ComPact NS800H 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33395	ComPact NS1000H 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33405	ComPact NS1250H 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33415	ComPact NS1600H 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33372	ComPact NS630bL 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33382	ComPact NS800L 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33392	ComPact NS1000L 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33376	ComPact NS630bL 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33386	ComPact NS800L 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33396	ComPact NS1000L 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33504	Trip unit Micrologic 2.0		No Change	Yes	
33511	Trip unit Micrologic 5.0		No Change	Yes	
33515	Trip unit Micrologic 6.0		No Change	Yes	
33525	Trip unit Micrologic 2.0 A Drawout		No Change	Yes	
33532	Trip unit Micrologic 5.0 A Drawout		No Change	Yes	
33533	Trip unit Micrologic 6.0 A Drawout		No Change	Yes	
33534	Trip unit Micrologic 7.0 A Drawout		No Change	Yes	
33536	Trip unit Micrologic 2.0 E Drawout		No Change	Yes	
33538	Trip unit Micrologic 5.0 E Drawout		No Change	Yes	
33540	Trip unit Micrologic 6.0 E Drawout		No Change	Yes	
65293	Trip unit Micrologic 5.0 P Drawout		No Change	Yes	
65294	Trip unit Micrologic 6.0 P Drawout		No Change	Yes	
65295	Trip unit Micrologic 7.0 P Drawout		No Change	Yes	
33450	ComPact NS630bNA 3P Basic Frame Withdrawable Electrical		No Change	Yes	

# ComPacT NS630b to NS1600 Withdrawable Electrically Operated

## Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33452	ComPact NS800NA 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33454	ComPact NS1000NA 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33456	ComPact NS1250NA 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33458	ComPact NS1600NA 3P Basic Frame Withdrawable Electrical		No Change	Yes	
33451	ComPact NS630bNA 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33453	ComPact NS800NA 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33455	ComPact NS1000NA 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33457	ComPact NS1250NA 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33459	ComPact NS1600NA 4P Basic Frame Withdrawable Electrical		No Change	Yes	
33722	Chassis ComPact NS630b to NS1250 Drawout 3P		No Change	Yes	
33723	Chassis ComPact NS1600 Drawout 3P		No Change	Yes	
33725	Chassis ComPact NS630b to NS1250 Drawout 4P		No Change	Yes	
33726	Chassis ComPact NS1600 Drawout 4P		No Change	Yes	
33727	ComPact NS Top Front Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33728	ComPact NS Bottom Front Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33729	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33730	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33731	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33732	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Drawout 3P		No Change	Yes	
33733	ComPact NS Top Front Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33734	ComPact NS Bottom Front Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33735	ComPact NS Top Vertical Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33736	ComPact NS Bottom Vertical Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33737	ComPact NS Top Horizontal Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33738	ComPact NS Bottom Horizontal Rear Connections 630 A to 1600 A Drawout 4P		No Change	Yes	
33831	ComPact NS630b to NS1600 standard motor mechanism 48/60 VDC, 48 VAC 50/60 Hz Drawout		No Change	Yes	
33827	ComPact NS630b to NS1600 standard motor mechanism 100/130 VAC 50/60 Hz Drawout		No Change	Yes	
33828	ComPact NS630b to NS1600 standard motor mechanism 220/240 VAC 50/60 Hz Drawout		No Change	Yes	
33829	ComPact NS630b to NS1600 standard motor mechanism 380/415 VAC 50/60 Hz Drawout		No Change	Yes	
33838	ComPact NS630b to NS1600 communicating motor mechanism 48/60 VDC, 48 VAC 50/60 Hz Drawout		No Change	Yes	
33834	ComPact NS630b to NS1600 communicating motor mechanism 100/130 VAC 50/60 Hz Drawout		No Change	Yes	
33835	ComPact NS630b to NS1600 communicating motor mechanism 220/240 VAC 50/60 Hz Drawout		No Change	Yes	
33836	ComPact NS630b to NS1600 communicating motor mechanism 380/415 VAC 50/60 Hz Drawout		No Change	Yes	
33830	ComPact NS630b to NS1600 standard motor mechanism 24/30 VDC Drawout		No Change	Yes	

# ComPacT NS630b to NS1600 Withdrawable Electrically Operated Device Based on Separate Components

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33831	ComPact NS630b to NS1600 standard motor mechanism 48/60 VDC, 48 VAC 50/60 Hz Drawout		No Change	Yes	
33832	ComPact NS630b to NS1600 standard motor mechanism 100/130 VDC Drawout		No Change	Yes	
33833	ComPact NS630b to NS1600 standard motor mechanism 200/250 VDC Drawout		No Change	Yes	
33837	ComPact NS630b to NS1600 communicating motor mechanism 24/30 VDC Drawout		No Change	Yes	
33838	ComPact NS630b to NS1600 communicating motor mechanism 48/60 VDC, 48 VAC 50/60 Hz Drawout		No Change	Yes	
33839	ComPact NS630b to NS1600 communicating motor mechanism 100/130 VDC Drawout		No Change	Yes	
33840	ComPact NS630b to NS1600 communicating motor mechanism 200/250 VDC Drawout		No Change	Yes	

## ComPact NS630b to NS3200 Accessories &amp; Spare Parts

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33598	ComPact NS Top Front Connections 630 A to 1000 A Fixed 3P		No Change	Yes	
33599	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 3P		No Change	Yes	
33600	ComPact NS Top Front Connections 630 A to 1250 A Fixed 3P		No Change	Yes	
33601	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 3P		No Change	Yes	
33602	ComPact NS Top Front Connections 1600 A Fixed 3P		No Change	Yes	
33603	ComPact NS Bottom Front Connections 1600 A Fixed 3P		No Change	Yes	
33584	Vertical and Horizontal Rear Connections 630 A to 1600 A Fixed 3P		No Change	Yes	
33608	ComPact NS Top Front Connections 630 A to 1000 A Fixed 4P		No Change	Yes	
33609	ComPact NS Bottom Front Connections 630 A to 1000 A Fixed 4P		No Change	Yes	
33610	ComPact NS Top Front Connections 630 A to 1250 A Fixed 4P		No Change	Yes	
33611	ComPact NS Bottom Front Connections 630 A to 1250 A Fixed 4P		No Change	Yes	
33612	ComPact NS Top Front Connections 1600 A Fixed 4P		No Change	Yes	
33613	ComPact NS Bottom Front Connections 1600 A Fixed 4P		No Change	Yes	
33585	Vertical and Horizontal Rear Connections 630 A to 1600 A Fixed 4P		No Change	Yes	
33640	ComPact NS Front Connections 630 A to 1600 A Fixed 3P 240 mm <sup>2</sup> bar		No Change	Yes	
33641	ComPact NS Front Connections 630 A to 1600 A Fixed 4P 240 mm <sup>2</sup> bar		No Change	Yes	
33628	ComPact NS Terminal Shield 630 A to 1600 A Fixed 3P		No Change	Yes	
33629	ComPact NS Terminal Shield 630 A to 1600 A Fixed 4P		No Change	Yes	
33642	ComPact NS Vertical Connection Adapter 1600 A to 3200 A Fixed 3P		No Change	Yes	
33643	ComPact NS Vertical Connection Adapter 1600 A to 3200 A Fixed 4P		No Change	Yes	
33644	3 Cable Lug Adapters 3P		No Change	Yes	
33645	4 Cable Lug Adapters 4P		No Change	Yes	
33646	3 Interphase Barriers Top/Bottom Front Connections Fixed 3/4P		No Change	Yes	
33648	4 Interphase Barriers Top/Bottom Rear Connections Fixed 3/4P		No Change	Yes	
64907	ComPact NS Arc Chute Insulating 630 A to 1600 A 3P		No Change	Yes	
33597	ComPact NS Arc Chute Insulating 630 A to 1600 A 4P		No Change	Yes	
64908	2 ComPact NS Support Brackets 630 A to 1600 A Fixed 4P		No Change	Yes	
33622	3 Spreaders 3P 630 A to 1600 A 70 to 95 mm <sup>2</sup>		No Change	Yes	
33623	4 Spreaders 4P 630 A to 1600 A 70 to 95 mm <sup>2</sup>		No Change	Yes	
33148	User Manual For ComPact NS 630A to 1600A		No Change	Yes	
33013	6 Crip Lugs Set 240mm <sup>2</sup> 3P		No Change	Yes	
33014	8 Crip Lugs Set 240mm <sup>2</sup> 4P		No Change	Yes	
33015	6 Crip Lugs Set 300MM <sup>2</sup> 3P		No Change	Yes	
33016	8 Crip Lugs Set 300MM <sup>2</sup> 4P		No Change	Yes	
29450	Auxiliary contact OF/SD/SDE/SDV Screwless		No Change	Yes	
33804	Low Level Auxiliary Contact OF		No Change	Yes	
33803	Low Level Auxiliary Contact SD		No Change	Yes	
33802	Low Level Auxiliary Contact SDE		No Change	Yes	
33658	MX Shunt Release 12 VDC Fixed		No Change	Yes	
33659	MX Shunt Release 24/30 VDC, 24 VAC 50/60 Hz Fixed		No Change	Yes	

## ComPacT NS630b to NS3200 Accessories &amp; Spare Parts

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPact NS
33660	MX Shunt Release 48/60 VDC, 48 VAC 50/60 Hz Fixed		No Change	Yes	
33661	MX Shunt Release 100/130 VDC, 100/130 VAC 50/60 Hz Fixed		No Change	Yes	
33662	MX Shunt Release 200/250 VDC, 200/250 VAC 50/60 Hz Fixed		No Change	Yes	
33663	MX Shunt Release 277 VAC 50/6 Hz Fixed		No Change	Yes	
33664	MX Shunt Release 380/480 VAC 50/60 Hz Fixed		No Change	Yes	
33668	MN Undervoltage Release 24/30 VDC, 24 VAC 50/60 Hz		No Change	Yes	
33669	MN Undervoltage Release 48/60 VDC, 48 VAC 50/60 Hz		No Change	Yes	
33670	MN Undervoltage Release 100/130 VDC, 100/130 VAC 50/60 Hz		No Change	Yes	
33671	MN Undervoltage Release 200/250 VDC, 200/250 VAC 50/60 H		No Change	Yes	
33673	MN Undervoltage Release 380/480 VAC 50/60 Hz		No Change	Yes	
33684	MN Non Adjustable Delay 100/130 VDC, 100/130 VAC 50/60 Hz		No Change	Yes	
33685	MN Non Adjustable Delay 200/250 VDC, 200/250 VAC 50/60 Hz		No Change	Yes	
33680	MN Adjustable Delay 200/250 VDC, 200/250 VAC 50/60 Hz		No Change	Yes	
33681	MN Adjustable Delay 100/130 VDC, 100/130 VAC 50/60 Hz		No Change	Yes	
33682	MN Adjustable Delay 200/250 VDC, 200/250 VAC 50/60 Hz		No Change	Yes	
33683	MN Adjustable Delay 380/480 VDC, 380/480 VAC 50/60 Hz		No Change	Yes	
33717	Door Frame for Fixed Manually Operated		No Change	Yes	
33718	Escutcheon for Fixed Electrically Operated		No Change	Yes	
33158	ComPact NS Front Cover 630 A to 1600 A Fixed	C33158	ComPacT NS Front Cover 630 A to 1600 A Fixed	Yes	Yes
33858	Door Blanking Plate For Manual Drawout		No Change	Yes	
46996	ComPact NS Toggle 630 A to 1600A	C46996	ComPacT NS Toggle 630 A to 1600A	Yes	Yes
33195	ComPact NS Additional Toggle Extension 630 A to 1600 A	C33195	ComPacT NS Additional Toggle Extension 630 A to 1600 A	Yes	Yes
33542	Standard Rating Pug 0.4 TO 1	C33542	LT Standard Rating Pug 0.4 to 1 x Ir	Yes	Yes
33543	Low-Setting Rating Plug 0.4 to 0.8 x In	C33543	LT Low-Setting Rating Plug 0.4 to 0.8 x Ir	Yes	Yes
33544	High-Setting Rating Plug 0.8 to 1 x In	C33544	High-Setting Rating Plug 0.8 to 1 x Ir	Yes	Yes
33545	Rating Plug OFF no long time protection	C33545	LT Rating Plug OFF no long time protection	Yes	Yes
33593	Spare Part Battery for Micrologic		No Change	Yes	
33592	Spare Part Cover for Micrologic A and E	C33592	Spare Part Cover for MicroLogic A and E	Yes	Yes
47067	Spare Part Cover for Micrologic P and H	C47067	Spare Part Cover for MicroLogic P and H	Yes	Yes
33576	External Sensor For Neutral and Earth 3P		No Change	Yes	
33573	Rectangular Sensor for Earth Leakage 280x115mm2		No Change	Yes	
33579	External Source Ground Return Protection		No Change	Yes	
48891	Spare Part Summing Module MDGF		No Change	Yes	
44936	Toggle Padlocking Device Removable		No Change	Yes	
2631	Toggle Padlocking Device Fixed		No Change	Yes	
33866	CNOMO Accessory for Direct Rotary Handle		No Change	Yes	
33870	OFF Position Locking For Rotary Handle		No Change	Yes	
33872	OFF/ON Position Locking For Rotary Handle		No Change	Yes	
33868	Locking Kit for Rotary Handle		No Change	Yes	
33869	OFF Position Locking For Rotary Handle		No Change	Yes	
33871	OFF/ON Position Locking For Rotary Handle		No Change	Yes	
33890	Interlocking Kit for 2 Breakers		No Change	Yes	
33897	Push Button Locking Device		No Change	Yes	
47514	OFF Position Locking Adapter		No Change	Yes	
33902	OFF Position Locking Kit 1 Profalux keylock 1 Key		No Change	Yes	
33904	OFF Position Locking Kit 2 Profalux keylock 1 Key		No Change	Yes	



# ComPacT NS630b to NS3200 Accessories & Spare Parts

Old ComPacT NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPacT NS to New Retrofit ComPacT NS	New Retrofit ComPacT NS to old ComPacT NS
33173	OFF Position Locking Kit 2 keys not identified		No Change	Yes	
33174	OFF Position Locking Kit 2 keys identified		No Change	Yes	
33175	OFF Position Locking Kit 2 keys identified		No Change	Yes	
33903	OFF Position Locking Kit 1 Ronis keylock 1 key		No Change	Yes	
33905	OFF Position Locking Kit 2 Ronis keylocks 1 key		No Change	Yes	
33189	OFF Position Locking Kit 2 keys not identified		No Change	Yes	
33190	OFF Position Locking Kit 2 keys identified		No Change	Yes	
33191	OFF Position Locking Kit 2 keys identified		No Change	Yes	
33192	OFF Position Locking Kit 2 keys identified		No Change	Yes	
33898	OFF Position Locking Kit without keylock Profalux		No Change	Yes	
33899	OFF Position Locking Kit without keylock Ronis		No Change	Yes	
47517	OFF Position Locking Kit without keylock Kirk		No Change	Yes	
47518	OFF Position Locking Kit without keylock Castell		No Change	Yes	
33895	Operation Counter - mechanical 5 digit display		No Change	Yes	
33910	Rod Type Interlocking for 2 Fixed Breakers		No Change	Yes	
33911	Cable Interlocking for 2 Fixed Breakers		No Change	Yes	
33915	Cable Interlocking for 1 Fixed Breaker and 1 Withdrawbale		No Change	Yes	
33588	Front Connection Kit 3P 6 Parts		No Change	Yes	
33586	Rear Connection Kit 3P 4 Parts		No Change	Yes	
33589	Front Connection Kit 4P 8 Parts		No Change	Yes	
33587	Rear Connection Kit 4P 6 Parts		No Change	Yes	
33768	Interphase Barrier for Chassis		No Change	Yes	
33763	Auxiliary Terminal Shield 3P for Chassis 3P		No Change	Yes	
33764	Auxiliary Terminal Shield 3P for Chassis 4P		No Change	Yes	
33765	Safety Shutters 3P		No Change	Yes	
33766	Safety Shutters 4P		No Change	Yes	
64906	1 Disconnecting Cluster for Chassis		No Change	Yes	
33801	Standard Auxiliary contact OF Withdrawable		No Change	Yes	
33800	Standard Auxiliary contact SD Withdrawable		No Change	Yes	
33799	Standard Auxiliary contact SDE Withdrawable		No Change	Yes	
33751	Standard Carriage Switch Chassis Connected		No Change	Yes	
33753	Standard Carriage Switch Chassis Disconnected		No Change	Yes	
33752	Standard Carriage Switch Chassis in Test Position		No Change	Yes	
33170	Standard Carriage Switch Chassis in CE/CT/CD Position		No Change	Yes	
33754	Low Level Carriage Switch Chassis in Connected Position		No Change	Yes	
33756	Low Level Carriage Switch Chassis in Disconnected Position		No Change	Yes	
33755	Low Level Carriage Switch Chassis in Test Position		No Change	Yes	
33171	Low Level Carriage Switch Chassis in CE/CT/CD Position		No Change	Yes	
33098	3-Wire Auxiliary Terminal Block for Chassis		No Change	Yes	
33099	6-Wire Auxiliary Terminal Block for Chassis		No Change	Yes	
47900	Micrologic X jumpers on chassis		No Change	Yes	
33857	Door Escutcheon		No Change	Yes	
33859	Transparent Cover for Door Frame		No Change	Yes	
		C33152	ComPacT NS Front Cover 630-1600 A withdrawable		Yes
		C35005	ComPacT NS Front Cover 1600-3200 A		Yes
64909	Profalux 1 lock 1 key and adaptation kit		No Change	Yes	
64910	Profalux 2 locks 1 key and adaptation kit		No Change	Yes	
64911	Profalux 2 locks 2 keys and adaptation kit		No Change	Yes	
64912	Ronis 1 lock 1 key and adaptation kit		No Change	Yes	
64913	Ronis 2 locks 1 key and adaptation kit		No Change	Yes	
64914	Ronis 2 locks 2 keys and adaptation kit		No Change	Yes	
33769	Profalux Chassis Locking Disconnected Position		No Change	Yes	

## ComPacT NS630b to NS3200 Accessories &amp; Spare Parts

Old ComPact NS		New ComPact NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New Retrofit ComPact NS	New Retrofit ComPact NS to old ComPact NS
33770	Ronis Chassis Locking Disconnected Position		No Change	Yes	
33771	Castell Chassis Locking Disconnected Position		No Change	Yes	
33772	Kirk Chassis Locking Disconnected Position		No Change	Yes	
33172	Door Interlock		No Change	Yes	
33788	Racking Interlock		No Change	Yes	
33767	Breaker Mismatch Protection		No Change	Yes	
33913	Rod-Type Interlocking for 2 Drawout Breakers		No Change	Yes	
33914	Cable Interlocking for 2 Drawout Breakers		No Change	Yes	
33975	Vertical Connection Adapter 3P		No Change	Yes	
33976	Vertical Connection Adapter 4P		No Change	Yes	
33108	Standard Auxiliary Contact OF		No Change	Yes	
33109	Low Level Auxiliary Contact OF		No Change	Yes	
33996	Toggle Locking Device Removable Adapter		No Change	Yes	
33929	Escutcheon for Toggle		No Change	Yes	
33998	Interphase Barrier Rear Connections 3 Parts		No Change	Yes	
33997	ComPact NS 1600 A to 3200 A Toggle Extension		No Change	Yes	
34036	External Sensor for Neutral with Earth 3P		No Change	Yes	
33574	Rectangular Sensor for ELP 470x160mm2		No Change	Yes	
33004	Standard Auxiliary Contact SD		No Change	Yes	
33011	Standard Auxiliary Contact SDE		No Change	Yes	
33008	Low Level Auxiliary Contact SD		No Change	Yes	
33012	Low Level Auxiliary Contact SDE		No Change	Yes	
33809	MX Opening Voltage Release 12VDC		No Change	Yes	
33810	MX Opening Voltage Release 24/30VDC 24VAC		No Change	Yes	
33811	MX Opening Voltage Release 48/60VDC 48VAC		No Change	Yes	
33812	MX Opening Voltage Release 100/130V AC/DC		No Change	Yes	
33813	MX Opening Voltage Release 200/250V AC/DC		No Change	Yes	
33814	MX Opening Voltage Release 277VAC		No Change	Yes	
33815	MX Opening Voltage Release 380/480VAC		No Change	Yes	
33819	MN Under Voltage Release 24/30VDC 24VAC		No Change	Yes	
33820	MN Under Voltage Release 48/60VDC 48VAC		No Change	Yes	
33821	MN Under Voltage Release 100/130V AC/DC		No Change	Yes	
33822	MN Under Voltage Release 380/480 VAC		No Change	Yes	
33824	MN Under Voltage Release 200/250 VDC 200/250 VAC		No Change	Yes	
47071	Chassis 3 Wire Terminal Block		No Change	Yes	
47072	Chassis 6 Wire Terminal Block		No Change	Yes	
33779	Chassis Locking Optional Adapter		No Change	Yes	
33786	Switchboard Door Interlock (Right)		No Change	Yes	
33787	Switchboard Door Interlock (Left)		No Change	Yes	
33863	ComPact NS 630-1600A Fixed Standard Black Direct Rotary Handle		No Change	Yes	
33864	ComPact NS 630-1600A Fixed Standard Red/Yellow Direct Rotary Handle		No Change	Yes	
33878	ComPact NS 630-1600A Fixed Extended Black Direct Rotary Handle		No Change	Yes	
33879	ComPact NS 630-1600A Fixed Extended Red/Yellow Direct Rotary Handle		No Change	Yes	
33880	ComPact NS 630-1600A Drawout Extended Black Direct Rotary Handle		No Change	Yes	
33882	Standard Early Break Contact for Fixed		No Change	Yes	
33883	Standard Early Break Contact for Withdrawable		No Change	Yes	
33884	Standard Early Make Contact for Fixed		No Change	Yes	
33885	Standard Early Make Contact for Withdrawable		No Change	Yes	
33702	MODBUS COM Module for Manual Fixed ComPact NS		No Change	Yes	
33703	ECO MODBUS COM Module For Manual Fixed ComPact NS		No Change	Yes	
33848	MODBUS COM Module for Electrical Drawout ComPact NS		No Change	Yes	
33713	ECO MODBUS COM Module For Electrical Drawout ComPact NS		No Change	Yes	

# ComPacT NS630b to NS3200 Accessories & Spare Parts

Old ComPact NS		New ComPacT NS		Compatibility	
Cat. No	Description	Cat. No	Description	Old ComPact NS to New ComPacT NS Retrofit	New Retrofit ComPacT NS to old ComPact NS
33842	MODBUS COM Module for Manual Drawout ComPact NS		No Change	Yes	
33714	ECO MODBUS COM Module For Manual Drawout ComPact NS		No Change	Yes	
65317	Kit to Neutral for Mic P on Fixed ComPact NS		No Change	Yes	
65316	Kit to Neutral for Mic P on Withdrawable ComPact NS		No Change	Yes	
33986	MODBUS COM Module for Manual Fixed ComPact NS 1600 A to 3200 A		No Change	Yes	
33988	ECO MODBUS COM Module For Manual Fixed ComPact NS 1600 A to 3200 A		No Change	Yes	



Life Is On | **Schneider**  
Electric

**Schneider Electric Industries SAS**

35, rue Joseph Monier  
CS 30323  
92506 Rueil Malmaison Cedex  
France

RCS Nanterre 954 503 439  
Capital social 928 298 512 €  
[www.se.com](http://www.se.com)

09-2022

© 2022 - Schneider Electric. All Rights Reserved.  
All trademarks are owned by Schneider Electric Industries SAS or its affiliated companies.  
Document reference: LVPED221007EN