



TOP POWER ENTRY 90mm DIA

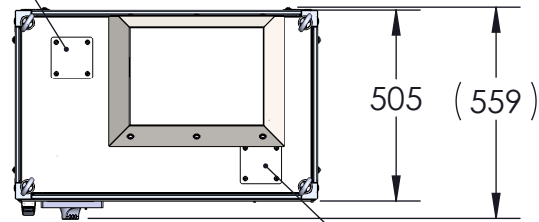

TOP COMMUNICATIONS & CT's 50x50mm OPENING ENTRY

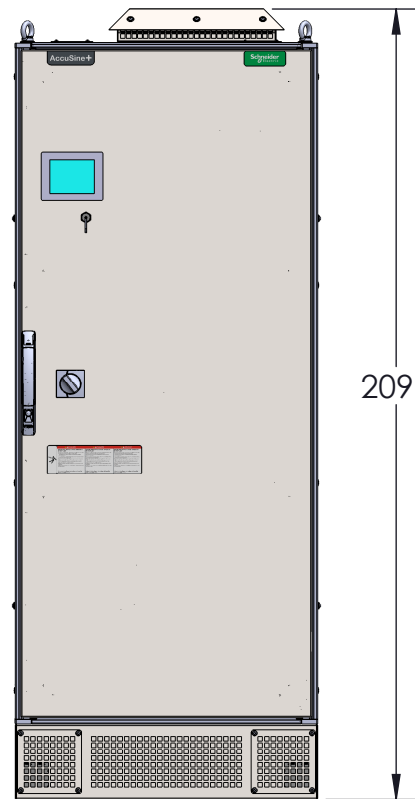


800

2091

NHA5990200 SMALL ENCLOSURE 480V IP31/N2		
PCSP060D5N2	AccuSine PCS+ 60A, 380-480 VAC N2	HRB37640
EVCP060D5N2	AccuSine PFV+ 60A, 380-480 VAC N2	HRB37641
PCSP060D5IP31	AccuSine PCS+ 60A, 380-480 VAC IP31	HRB37642
EVCP060D5IP31	AccuSine PFV+ 60A, 380-480 VAC IP31	HRB37643
PCSP120D5N2	AccuSine PCS+ 120A, 380-480 VAC N2	HRB44074
EVCP120D5N2	AccuSine PFV+ 120A, 380-480 VAC N2	HRB44075
PCSP120D5IP31	AccuSine PCS+ 120A, 380-480 VAC IP31	HRB44077
EVCP120D5IP31	AccuSine PFV+ 120A, 380-480 VAC IP31	HRB44078

BOTTOM ENTRY COMMUNICATIONS 50X50mm OPENING

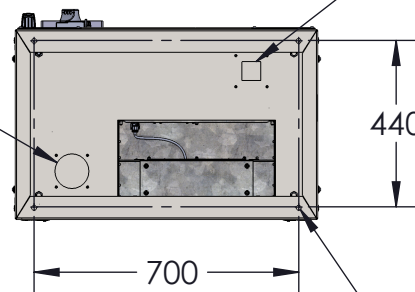

Ø 90 BOTTOM POWER ENTRY

440

700

Ø 13 FLOOR ANCHOR

	Scale: N/A	Tolerancing Standard: ISO8015	Units of Measure: mm
	SMALL ENCLOSURE 380-480V IP31/N2		
	SMALL ENCLOSURE 380-480V IP31/N2		
Number: NHA5990200		Revision: 00	Sheet: 1 OF 1

All information and data contained in this document are the exclusive property of Schneider Electric Industries SAS and may neither be used nor disclosed without its prior written consent.

State:

Released for Manufacturing
Printed on 2015/07/09