



Panel Mount

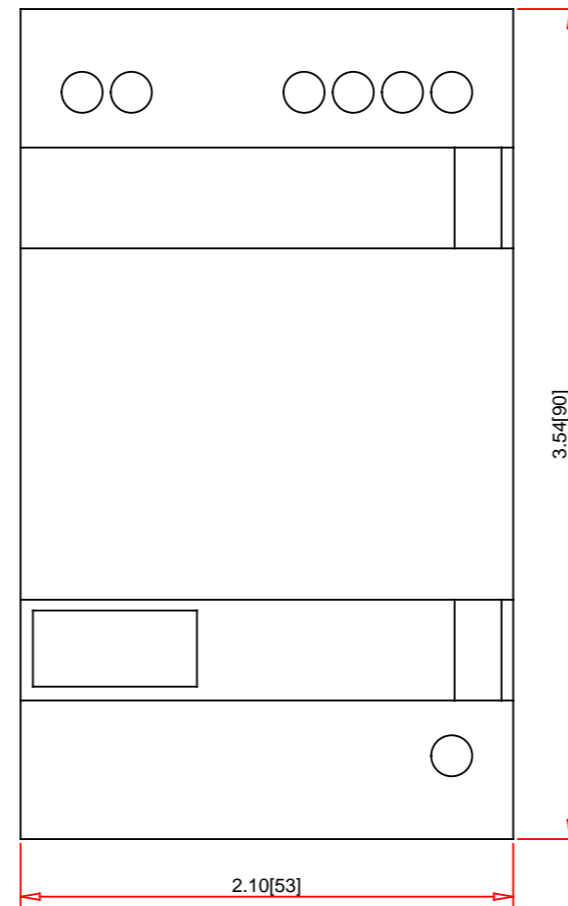


DIN Rail Mount

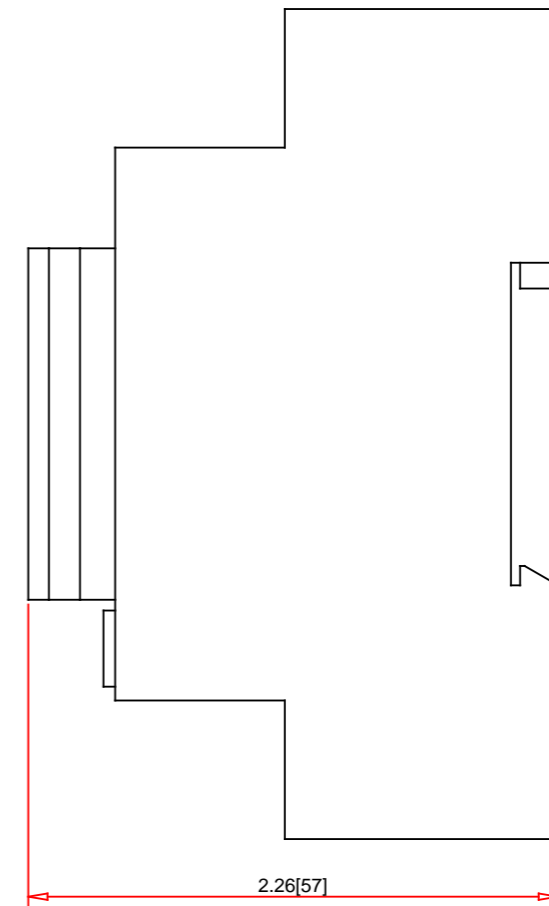

**Note:**  
 - Drawings Not To Scale  
 - Drawings Subject to Change Without Notice  
 - Dimensions are inches next to [Millimeters]

Part No.:

**ABL8MEM12020**

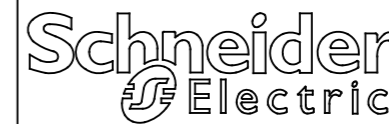

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Wire Range: #14 - #26  
 Tightening Torque: 5.3 lb-in (0.6 Nm)  
 Mounting: DIN Rail / Panel  
 Screw for Panel Mtg.: # 8-32  
 Weight: 0.43 lb (0.20 kg)  
 UL File: E164867 NMTR, E164867 NMTR7  
 CSA File: 204701 5311-07, 204701 5311-87  
 Conform to EN61000-3-2: N/A  
 CE: Yes  
 RoHS: Yes

**Specification:**

Description: Modular Power Supplies  
 Type: Power Supply 12Vdc 2 Amp  
 Input Voltage: 100-240 -15/+10% 50/60Hz, single phase  
 Output Voltage: 12Vdc  
 Nominal Power: 24 Watts  
 Nominal Current: 2 Amp  
 Reset: Automatic