


**Note:**

- Drawings Not To Scale
- Drawings Subject to Change Without Notice
- Dimensions are inches next to [Millimeters]

Part No.:

**ATSU01N222LT**

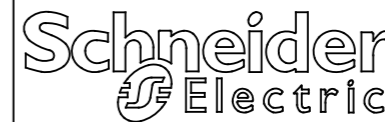

Schneider Electric United States  
 North American Division  
 Boston One Campus  
 800 Federal Street  
 Andover, MA 01810, USA  
 Phone: +1 8773425173  
 Email: CCC@us.schneider-electric.com

**Technical Information:**

Control Voltage: 24 VDC  
 Weight [lb]/[kg]: 1.08/0.49  
 UL File No.: E184727  
 CSA File: 224330  
 Other: IEC/EN 60947-4-2 CE,UL,CSA,C-Tick and CCC

**Specification:**

Description:  
 Family: Altistart 01  
 Product Line: Soft Starters  
 Application: Constant & Variable Torque  
 Output Ampere Rating: 22  
 hp rating 110V Single Phase: n/a  
 hp rating 208V Single Phase: n/a  
 kW rating 230V Single Phase: n/a  
 hp rating 230V Single Phase: n/a  
 kW rating 230V three Phase: 4 - 5.5 kW  
 hp rating 230V three Phase: 5 - 7.5 hp  
 kW Rating 400V three phase: 7.5 - 11 kW  
 hp rating 460V three phase: 10 - 15 hp  
 Enclosure Rating: IP20